

Non-Metallic Enclosures – Subpanels

| Subpanel Specifications | | |
|-------------------------|-----------------------------------|-------------------------------|
| Subpanel | Material | Finish |
| Carbon Steel | Carbon Steel | White polyester powder Finish |
| Aluminum | 3003H14 Aluminum | Mill Finish |
| Stainless Steel | 304 Stainless | 304 ANN 2 B Finish |
| Fiberglass | FRP (Fiberglass reinforced panel) | Gray Finish |



Carbon steel subpanels for all Premier and JIC non-metallic enclosures

| Subpanel Part Number | Price | Subpanel Size HxW | Enclosure Size HxW | BA | BB | BK | BL | BT | Panel Type | Number of Holes | Hole Diameter | Wt. |
|----------------------|-------|---------------------------|---------------------|-------------|-------------|-------------|-------------|-------------|------------|-----------------|---------------|--------|
| HW-MP604CS | <--> | 4.88 x 2.88 (124 x 73) | 6 x 4 (152 x 102) | 4.88 (124) | 2.88 (73) | 4.25 (108) | 2.25 (57) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 5 oz. |
| HW-MP606CS | <--> | 4.88 x 4.88 (124 x 124) | 6 x 6 (152 x 152) | 4.88 (124) | 4.88 (124) | 4.25 (108) | 4.25 (108) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 8 oz. |
| HW-MP706CS | <--> | 6.00 x 4.88 (152 x 124) | 7 x 6 (179 x 152) | 6.00 (152) | 4.88 (124) | 5.38 (137) | 4.25 (108) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 10 oz. |
| HW-MP806CS | <--> | 6.75 x 4.88 (152 x 124) | 8 x 6 (203 x 152) | 6.75 (152) | 4.88 (124) | 6.25 (159) | 4.25 (108) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 12 oz. |
| HW-MP808CS | <--> | 6.88 x 6.88 (175 x 175) | 8 x 8 (203 x 203) | 6.88 (175) | 6.88 (175) | 6.25 (159) | 6.25 (159) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 12 oz. |
| HW-MP906CS | <--> | 8.25 x 4.88 (175 x 124) | 9 x 6 (229 x 152) | 8.25 (210) | 4.88 (124) | 7.63 (194) | 4.25 (108) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 14 oz. |
| HW-MP1008CS | <--> | 8.75 x 6.88 (225 x 175) | 10 x 8 (254 x 203) | 8.75 (225) | 6.88 (175) | 8.25 (210) | 6.25 (159) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 21 oz. |
| HW-MP1210CS | <--> | 10.88 x 8.75 (276 x 225) | 12 x 10 (305 x 254) | 10.88 (276) | 8.75 (225) | 10.25 (260) | 8.25 (210) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 34 oz. |
| HW-MP1412CS | <--> | 12.88 x 10.88 (327 x 276) | 14 x 12 (356 x 305) | 12.88 (327) | 10.88 (276) | 12.25 (311) | 10.25 (260) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 48 oz. |
| HW-MP1614CS | <--> | 14.88 x 12.88 (378 x 327) | 16 x 14 (406 x 356) | 14.88 (378) | 12.88 (327) | 14.25 (362) | 12.25 (311) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 66 oz. |
| HW-MP1816CS | <--> | 16.88 x 14.88 (429 x 378) | 18 x 16 (457 x 406) | 16.88 (429) | 14.88 (378) | 16.25 (413) | 14.25 (362) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 87 oz. |
| HW-MP2016CS | <--> | 18.88 x 14.88 (479 x 378) | 20 x 16 (508 x 406) | 18.88 (479) | 14.88 (378) | 18.25 (464) | 14.25 (362) | 0.075 (1.9) | FLAT | 4 | .25 (6.35) | 97 oz. |

Note: Dimensions in inches (millimeters).

Fiberglass subpanels for all Premier and JIC non-metallic enclosures

| Subpanel Part Number | Price | Subpanel Size HxW | Enclosure Size HxW | BA | BB | BK | BL | BT | Panel Type | Number of Holes | Hole Diameter | Wt. |
|----------------------|-------|---------------------------|---------------------|-------------|-------------|-------------|-------------|-------------|------------|-----------------|---------------|--------|
| HW-MP604FG | <--> | 4.88 x 2.88 (124 x 73) | 6 x 4 (152 x 102) | 4.88 (124) | 2.88 (73) | 4.25 (108) | 2.25 (57) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 2 oz. |
| HW-MP606FG | <--> | 4.88 x 4.88 (124 x 124) | 6 x 6 (152 x 152) | 4.88 (124) | 4.88 (124) | 4.25 (108) | 4.25 (108) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 3 oz. |
| HW-MP806FG | <--> | 6.88 x 4.88 (175 x 124) | 8 x 6 (203 x 152) | 6.75 (152) | 4.88 (124) | 6.25 (159) | 4.25 (108) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 4 oz. |
| HW-MP808FG | <--> | 6.88 x 6.88 (175 x 175) | 8 x 8 (203 x 203) | 6.88 (175) | 6.88 (175) | 6.25 (159) | 6.25 (159) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 5 oz. |
| HW-MP1008FG | <--> | 8.88 x 6.88 (225 x 175) | 10 x 8 (254 x 203) | 8.75 (225) | 6.88 (175) | 8.25 (210) | 6.25 (159) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 8 oz. |
| HW-MP1210FG | <--> | 10.88 x 8.88 (276 x 225) | 12 x 10 (305 x 254) | 10.88 (276) | 8.75 (225) | 10.25 (260) | 8.25 (210) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 14 oz. |
| HW-MP1412FG | <--> | 12.88 x 10.88 (327 x 276) | 14 x 12 (356 x 305) | 12.88 (327) | 10.88 (276) | 12.25 (311) | 10.25 (260) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 16 oz. |
| HW-MP1614FG | <--> | 14.88 x 12.88 (378 x 327) | 16 x 14 (406 x 356) | 14.88 (378) | 12.88 (327) | 14.25 (362) | 12.25 (311) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 13 oz. |
| HW-MP1816FG | <--> | 16.88 x 14.88 (429 x 378) | 18 x 16 (457 x 406) | 16.88 (429) | 14.88 (378) | 16.25 (413) | 14.25 (362) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 32 oz. |
| HW-MP2016FG | <--> | 18.88 x 14.88 (479 x 378) | 20 x 16 (508 x 406) | 18.88 (479) | 14.88 (378) | 18.25 (464) | 14.25 (362) | 0.125 (3.2) | FLAT | 4 | .25 (6.35) | 36 oz. |

Note: Dimensions in inches (millimeters).

Non-Metallic Enclosures – Subpanels

Stainless steel subpanels for all Premier and JIC non-metallic enclosures

| Subpanel Part Number | Price | Subpanel Size HxW | Enclosure Size HxW | BA | BB | BK | BL | BT | Panel Type | Number of Holes | Hole Diameter | Wt. |
|----------------------|-------|---------------------------|---------------------|-------------|-------------|-------------|-------------|----------|------------|-----------------|---------------|--------|
| HW-MP604SS | <--> | 4.88 x 2.88 (124 x 73) | 6 x 4 (152 x 102) | 4.88 (124) | 2.88 (73) | 4.25 (108) | 2.25 (57) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 5 oz. |
| HW-MP606SS | <--> | 4.88 x 4.88 (124 x 124) | 6 x 6 (152 x 152) | 4.88 (124) | 4.88 (124) | 4.25 (108) | 4.25 (108) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 8 oz. |
| HW-MP806SS | <--> | 6.88 x 4.88 (175 x 124) | 8 x 6 (203 x 152) | 6.75 (152) | 4.88 (124) | 6.25 (159) | 4.25 (108) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 12 oz. |
| HW-MP808SS | <--> | 6.88 x 6.88 (175 x 175) | 8 x 8 (203 x 203) | 6.88 (175) | 6.88 (175) | 6.25 (159) | 6.25 (159) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 12 oz. |
| HW-MP1008SS | <--> | 8.88 x 6.88 (225 x 175) | 10 x 8 (254 x 203) | 8.75 (225) | 6.88 (175) | 8.25 (210) | 6.25 (159) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 19 oz. |
| HW-MP1210SS | <--> | 10.88 x 8.88 (276 x 225) | 12 x 10 (305 x 254) | 10.88 (276) | 8.75 (225) | 10.25 (260) | 8.25 (210) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 30 oz. |
| HW-MP1412SS | <--> | 12.88 x 10.88 (327 x 276) | 14 x 12 (356 x 305) | 12.88 (327) | 10.88 (276) | 12.25 (311) | 10.25 (260) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 45 oz. |
| HW-MP1614SS | <--> | 14.88 x 12.88 (378 x 327) | 16 x 14 (406 x 356) | 14.88 (378) | 12.88 (327) | 14.25 (362) | 12.25 (311) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 60 oz. |
| HW-MP1816SS | <--> | 16.88 x 14.88 (429 x 378) | 18 x 16 (457 x 406) | 16.88 (429) | 14.88 (378) | 16.25 (413) | 14.25 (362) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 96 oz. |
| HW-MP2016SS | <--> | 18.88 x 14.88 (479 x 378) | 20 x 16 (508 x 406) | 18.88 (479) | 14.88 (378) | 18.25 (464) | 14.25 (362) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 97 oz. |


Note: Dimensions in inches (millimeters).

Aluminum subpanels for all Premier and JIC non-metallic enclosures

| Subpanel Part Number | Price | Subpanel Size HxW | Enclosure Size HxW | BA | BB | BK | BL | BT | Panel Type | Number of Holes | Hole Diameter | Wt. |
|----------------------|-------|---------------------------|---------------------|-------------|-------------|-------------|-------------|----------|------------|-----------------|---------------|--------|
| HW-MP604A | <--> | 4.88 x 2.88 (124 x 73) | 6 x 4 (152 x 102) | 4.88 (124) | 2.88 (73) | 4.25 (108) | 2.25 (57) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 2 oz. |
| HW-MP606A | <--> | 4.88 x 4.88 (124 x 124) | 6 x 6 (152 x 152) | 4.88 (124) | 4.88 (124) | 4.25 (108) | 4.25 (108) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 3 oz. |
| HW-MP806A | <--> | 6.88 x 4.88 (175 x 124) | 8 x 6 (203 x 152) | 6.75 (152) | 4.88 (124) | 6.25 (159) | 4.25 (108) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 4 oz. |
| HW-MP1008A | <--> | 8.88 x 6.88 (225 x 175) | 10 x 8 (254 x 203) | 8.75 (225) | 6.88 (175) | 8.25 (210) | 6.25 (159) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 8 oz. |
| HW-MP1210A | <--> | 10.88 x 8.88 (276 x 225) | 12 x 10 (305 x 254) | 10.88 (276) | 8.75 (225) | 10.25 (260) | 8.25 (210) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 12 oz. |
| HW-MP1412A | <--> | 12.88 x 10.88 (327 x 276) | 14 x 12 (356 x 305) | 12.88 (327) | 10.88 (276) | 12.25 (311) | 10.25 (260) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 18 oz. |
| HW-MP1614A | <--> | 14.88 x 12.88 (378 x 327) | 16 x 14 (406 x 356) | 14.88 (378) | 12.88 (327) | 14.25 (362) | 12.25 (311) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 24 oz. |
| HW-MP1816A | <--> | 16.88 x 14.88 (429 x 378) | 18 x 16 (457 x 406) | 16.88 (429) | 14.88 (378) | 16.25 (413) | 14.25 (362) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 40 oz. |
| HW-MP2016A | <--> | 18.88 x 14.88 (479 x 378) | 20 x 16 (508 x 406) | 18.88 (479) | 14.88 (378) | 18.25 (464) | 14.25 (362) | 0.08 (2) | FLAT | 4 | .25 (6.35) | 39 oz. |

Note: Dimensions in inches (millimeters).

Subpanel Dimensions

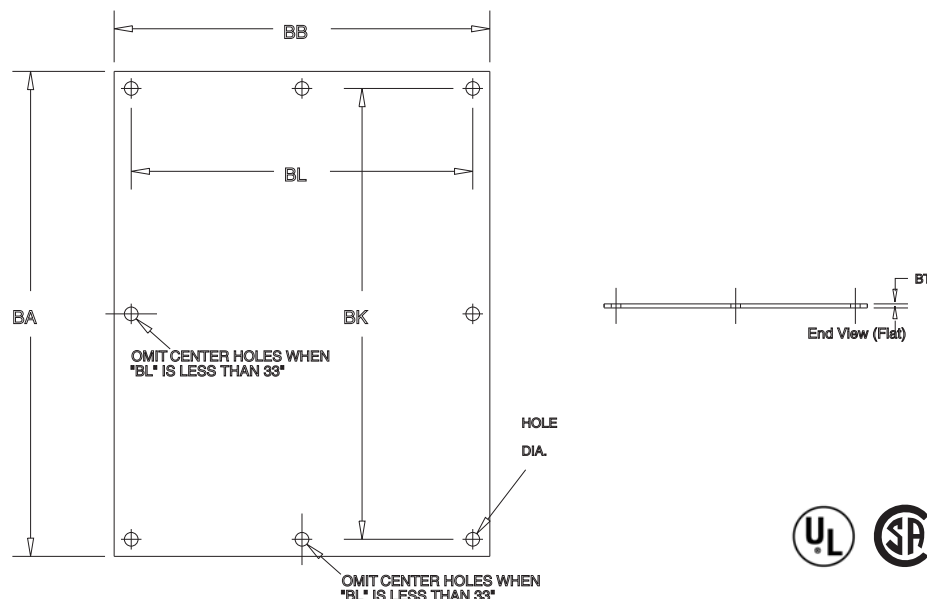

| Enclosure Shipping Schedule | | |
|--|------------|-------------|
| Same day | 1 - 7 days | 1 - 14 days |
| Color indicates shipping lead time in business days. | | |



Non-Metallic Enclosures – Control Series Subpanels

Carbon steel subpanels for Control Series non-metallic enclosures

| Subpanel Part Number | Price | Subpanel Size HxW | Enclosure Size HxW | BA | BB | BK | BL | BT | Panel Type | No. of Holes | Hole Dia. | Wt. |
|----------------------|-------|----------------------------|----------------------|--------------|-------------|--------------|-------------|----------|------------|--------------|-----------|-----------|
| HW-WM1610CS | <--> | 13.00 x 8.50 (330 x 216) | 16 x 10 (406 x 54) | 13.00 (330) | 8.50 (216) | 12.00 (305) | 7.50 (191) | 0.08 (2) | Flat | 4 | 0.31 (8) | 3.3 lbs. |
| HW-WM2016CS | <--> | 17.00 x 13.00 (432 x 330) | 20 x 16 (508 x 406) | 17.00 (432) | 13.00 (330) | 15.25 (387) | 11.25 (286) | 0.09 (2) | Formed | 4 | 0.31 (8) | 6.7 lbs. |
| HW-WM2412CS | <--> | 21.00 x 9.00 (533 x 229) | 24 x 12 (610 x 305) | 21.00 (533) | 9.00 (229) | 19.25 (489) | 7.25 (184) | 0.09 (2) | Formed | 4 | 0.50 (13) | 8.7 lbs. |
| HW-WM2420CS | <--> | 21.00 x 17.00 (533 x 432) | 24 x 20 (610 x 508) | 21.00 (533) | 17.00 (432) | 19.25 (489) | 15.25 (387) | 0.13 (3) | Flat | 4 | 0.50 (13) | 10.8 lbs |
| HW-WM2424CS | <--> | 21.00 x 21.00 (533 x 533) | 24 x 24 (610 x 610) | 21.00 (533) | 21.00 (533) | 19.25 (489) | 19.25 (489) | 0.13 (3) | Formed | 4 | 0.50 (13) | 13.4 lbs. |
| HW-WM3020CS | <--> | 27.00 x 17.00 (686 x 432) | 30 x 20 (763 x 508) | 27.00 (686) | 17.00 (432) | 25.25 (641) | 15.25 (387) | 0.13 (3) | Formed | 5 | 0.50 (13) | 14 lbs |
| HW-WM3024CS | <--> | 27.00 x 21.00 (686 x 533) | 30 x 24 (762 x 610) | 27.00 (686) | 21.00 (533) | 25.25 (641) | 19.25 (489) | 0.13 (3) | Flat | 4 | 0.50 (13) | 17 lbs. |
| HW-WM3630CS | <--> | 33.00 x 27.00 (838 x 686) | 36 x 30 (914 x 762) | 33.00 (838) | 27.00 (686) | 31.25 (794) | 25.25 (641) | 0.13 (3) | Flat | 4 | 0.50 (13) | 27 lbs |
| HW-WM4836CS | <--> | 33.00 x 45.00 (838 x 1143) | 48 x 36 (1219 x 914) | 45.00 (1143) | 33.00 (838) | 43.00 (1092) | 31.25 (794) | 0.13 (3) | Flat | 8 | 0.50 (13) | 41 lbs |
| HW-WM6036CS | <--> | 57.00 x 33.00 (1448 x 838) | 60 x 36 (1524 x 914) | 57.00 (1448) | 33.00 (838) | 55.25 (1403) | 31.25 (794) | 0.13 (3) | Formed | 8 | 0.50 (13) | 60 lbs |


Note: Dimensions in inches (millimeters).

Aluminum Subpanels for Control Series non-metallic enclosures

| Subpanel Part Number | Price | Subpanel Size HxW | Enclosure Size HxW | BA | BB | BK | BL | BT | Panel Type | No. of Holes | Hole Dia. | Wt. |
|----------------------|-------|----------------------------|----------------------|--------------|-------------|--------------|-------------|----------|------------|--------------|-----------|----------|
| HW-WM1610A | <--> | 13.00 x 8.50 (330 x 216) | 16 x 10 (406 x 54) | 13.00 (330) | 8.50 (216) | 12.00 (305) | 7.50 (191) | 0.08 (2) | Flat | 4 | 0.31 (8) | 1 lb. |
| HW-WM2016A | <--> | 17.00 x 13.00 (432 x 330) | 20 x 16 (508 x 406) | 17.00 (432) | 13.00 (330) | 15.25 (387) | 11.25 (286) | 0.09 (2) | Formed | 4 | 0.31 (8) | 2 lbs. |
| HW-WM2412A | <--> | 21.00 x 9.00 (533 x 229) | 24 x 12 (610 x 305) | 21.00 (533) | 9.00 (229) | 19.25 (489) | 7.25 (184) | 0.09 (2) | Formed | 4 | 0.50 (13) | 4.5 lbs. |
| HW-WM2420A | <--> | 21.00 x 17.00 (533 x 432) | 24 x 20 (610 x 508) | 21.00 (533) | 17.00 (432) | 19.25 (489) | 15.25 (387) | 0.13 (3) | Flat | 4 | 0.50 (13) | 4.5 lbs |
| HW-WM2424A | <--> | 21.00 x 21.00 (533 x 533) | 24 x 24 (610 x 610) | 21.00 (533) | 21.00 (533) | 19.25 (489) | 19.25 (489) | 0.13 (3) | Formed | 4 | 0.50 (13) | 5.5 lbs. |
| HW-WM3020A | <--> | 27.00 x 17.00 (686 x 432) | 30 x 20 (763 x 508) | 27.00 (686) | 17.00 (432) | 25.25 (641) | 15.25 (387) | 0.13 (3) | Formed | 5 | 0.50 (13) | 5.8 lbs |
| HW-WM3024A | <--> | 27.00 x 21.00 (686 x 533) | 30 x 24 (762 x 610) | 27.00 (686) | 21.00 (533) | 25.25 (641) | 19.25 (489) | 0.13 (3) | Flat | 4 | 0.50 (13) | 7 lbs. |
| HW-WM3630A | <--> | 33.00 x 27.00 (838 x 686) | 36 x 30 (914 x 762) | 33.00 (838) | 27.00 (686) | 31.25 (794) | 25.25 (641) | 0.13 (3) | Flat | 4 | 0.50 (13) | 11 lbs |
| HW-WM4836A | <--> | 33.00 x 45.00 (838 x 1143) | 48 x 36 (1219 x 914) | 45.00 (1143) | 33.00 (838) | 43.00 (1092) | 31.25 (794) | 0.13 (3) | Flat | 8 | 0.50 (13) | 22 lbs |
| HW-WM6036A | <--> | 57.00 x 33.00 (1448 x 838) | 60 x 36 (1524 x 914) | 57.00 (1448) | 33.00 (838) | 55.25 (1403) | 31.25 (794) | 0.13 (3) | Formed | 8 | 0.50 (13) | 23 lbs |

Note: Dimensions in inches (millimeters).

Dimensions

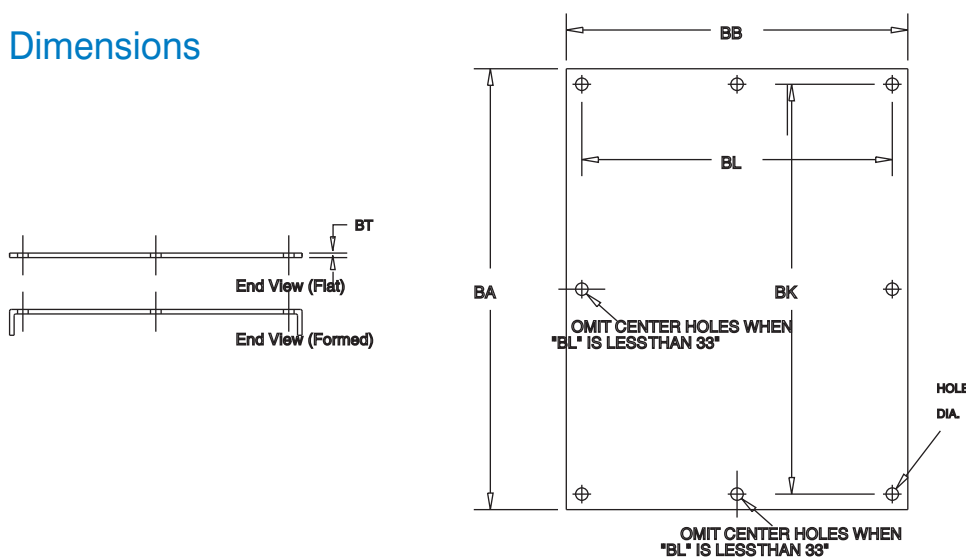

Note: Subpanels less than 33" wide do not have center holes as shown.