

# NEMA 3, 4, and 12 Two-Door Floor-Mount with 3-Point Handle



## Application

Designed to house electrical and electronic controls, components, and instruments in wet non-corrosive environments.

Typical applications for these enclosures include dairies, breweries and other food processing activities that may require hose down. Enclosures are also suitable for outdoor applications.



## Construction

- Bodies and doors fabricated from 10-gauge steel
- Continuously-welded seams ground smooth
- Body stiffeners added for extra strength
- Rolled lip around three sides of door and along top of enclosure's opening excludes liquids and contaminants from entering
- 3-point keylocking/padlocking combo handle
- Heavy gauge continuous hinges are provided to secure doors
- Pull hinge pin to remove doors
- Removable print pocket is provided
- Standard 12 in [305 mm] floor kits are welded to bottom of enclosure
- Heavy-duty removable lifting eyes
- Collar studs for mounting optional panels
- Easily Removable center post permits easy panel installations
- Doors are sealed with poured-in-place polyurethane gasket
- Grounding provisions provided
- Uses [WAL4 series handles](#) and [WAEMKA4 replacement key](#)

## Finish

- ANSI-61 gray polyester powder light texture inside and out over phosphatized surfaces

## Listings

- UL 508, 3, 4, and 12 [UL File E64791]
- NEMA/EEMAC 3, 4, and 12



Note: For current listings, please see [www.automationdirect.com](http://www.automationdirect.com)

## Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.

## NEMA 3, 4, and 12 Two-Door Floor-Mount Enclosure with 3-Point Handle


Part Number	Price	Enclosure Size HxWxD [not including 12 in [305 mm] legs]	Painted Steel Subpanel	Galvanized Subpanel
<a href="#">N4D6248103PT</a>	Retired	62.12 x 48.12 x 11.18 [1578 x 1222 x 284]	<a href="#">NPDD6048</a>	<a href="#">NPDD6048G</a>
<a href="#">N4D6260123PT</a>	Retired	62.12 x 60.12 x 13.29 [1578 x 1527 x 338]	<a href="#">NPDD6060</a>	<a href="#">NPDD6060G</a>
<a href="#">N4D7460123PT</a>	Retired	74.12 x 60.12 x 13.29 [1883 x 1527 x 338]	<a href="#">NPDD7260</a>	<a href="#">NPDD7260G</a>
<a href="#">N4D7472123PT</a>	Retired	74.12 x 72.12 x 13.29 [1883 x 1832 x 338]	<a href="#">NPDD7272</a>	—
<a href="#">N4D7472243PT</a>	Retired	74.12 x 72.12 x 25.29 [1883 x 1832 x 642]	<a href="#">NPDD7272</a>	—

Note: Dimensions in inches [millimeters].

# NEMA 3, 4, and 12 Two-Door Floor-Mount with 3-Point Handle



## Dimensions

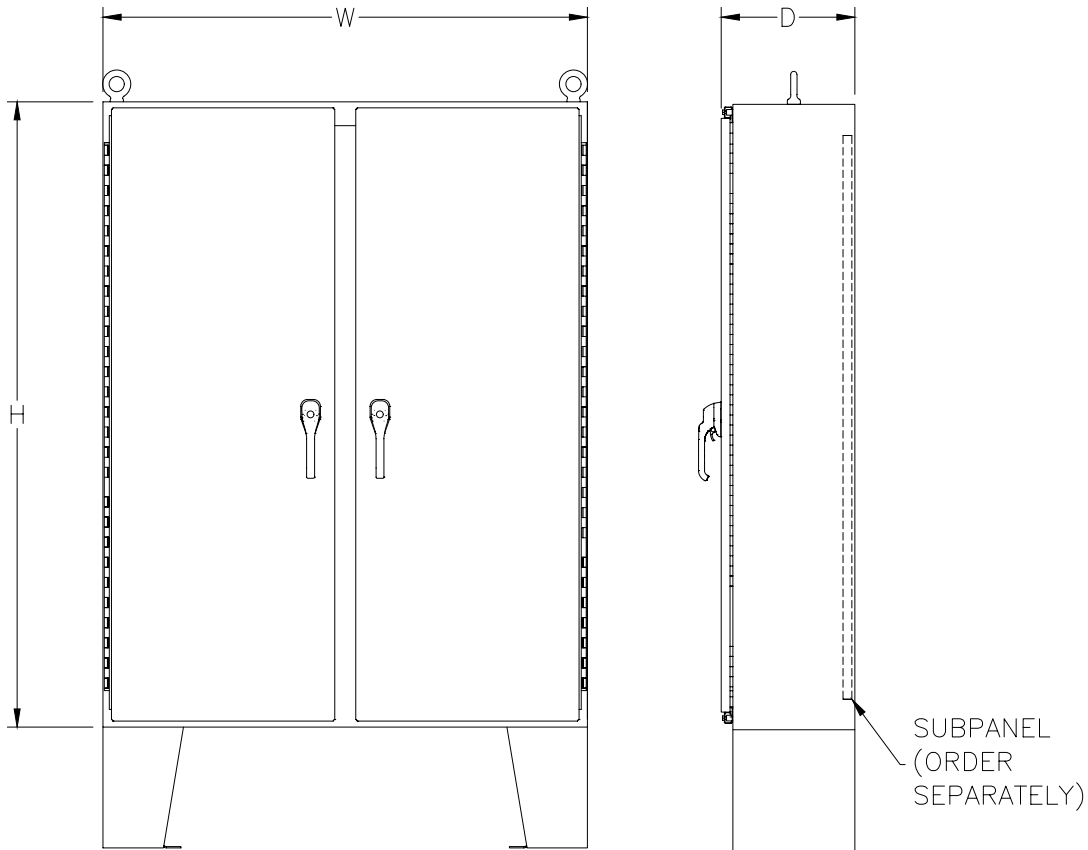

# Enclosure Subpanels



## Subpanels for Two-Door Floor-Mount Enclosures

- Subpanels are fabricated from 10-gauge carbon steel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Subpanels are used in NEMA 12 double-door floor-mount enclosures and some double-door wall-mount enclosures



Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Subpanels for Two-door Floor-Mount Enclosures					
Painted Steel	Price	Galvanized	Price	Nominal Enclosure Size HxW*	Subpanel Size AxB
<a href="#"><u>NPDD4242</u></a>	—	<a href="#"><u>NPDD4242G</u></a>	Retired	42 x 42	39.00 x 39.00 [991 x 991]
<a href="#"><u>NPDD4260</u></a>	Retired	<a href="#"><u>NPDD4260G</u></a>	Retired	42 x 60	38.00 x 56.00 [965 x 1422]
<a href="#"><u>NPDD4842</u></a>	—	<a href="#"><u>NPDD4842G</u></a>	Retired	48 x 42	45.00 x 39.00 [1143 x 991]
<a href="#"><u>NPDD4848</u></a>	—	<a href="#"><u>NPDD4848G</u></a>	Retired	48 x 48	44.00 x 44.00 [1118 x 1118]
<a href="#"><u>NPDD5442</u></a>	—	<a href="#"><u>NPDD5442G</u></a>	Retired	54 x 42	50.00 x 38.00 [1270 x 965]
<a href="#"><u>NPDD6048</u></a>	—	<a href="#"><u>NPDD6048G</u></a>	Retired	60 x 48	44.00 x 56.00 [1118 x 1422]
<a href="#"><u>NPDD6060</u></a>	—	<a href="#"><u>NPDD6060G</u></a>	Retired	60 x 60	56.00 x 56.00 [1422 x 1422]
<a href="#"><u>NPDD7260</u></a>	—	<a href="#"><u>NPDD7260G</u></a>	Retired	72 x 60	56.00 x 68.00 [1422 x 1727]
<a href="#"><u>NPDD7272</u></a>	—	—	—	72 x 72	68.00 x 68.00 [1727 x 1727]

Notes: Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawing.  
 \*Some floor-mount enclosures may be up to 2 in [51 mm] taller than height listed in this table.  
 Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions listed in this table.

## Dimensions

