


NITRA brass fittings are machined from quality brass bar stock or forgings. They work well with air, water, oil, oxygen, nitrogen and argon. Available in most popular styles and sizes, the fittings all have NPT threaded connections.

Features

- 10 different styles
- Machined from yellow brass bar stock or forging
- Work with water, oil, air and other gases
- Maximum pressure = up to 800 psi




BFMC-14N

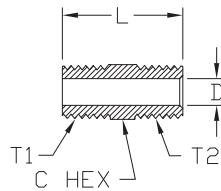

NITRA™ Male Brass Connectors									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	C Hex	L	Flow Dia. D
BFMC-18N	<-->	Male connector, 1/8 inch NPT to 1/8 inch NPT	5	0.1	1/8	1/8	7/16	0.97	0.22
BFMC-14N-18N	<-->	Male connector, 1/4 inch NPT to 1/8 inch NPT	5	0.1	1/4	1/8	9/16	1.19	0.22
BFMC-14N	<-->	Male connector, 1/4 inch NPT to 1/4 inch NPT	5	0.1	1/4	1/4	9/16	1.38	0.31
BFMC-38N-18N	<-->	Male connector, 3/8 inch NPT to 1/8 inch NPT	5	0.3	3/8	1/8	11/16	1.22	0.22
BFMC-38N-14N	<-->	Male connector, 3/8 inch NPT to 1/4 inch NPT	5	0.3	3/8	1/4	11/16	1.41	0.31
BFMC-38N	<-->	Male connector, 3/8 inch NPT to 3/8 inch NPT	5	0.3	3/8	3/8	11/16	1.41	0.44
BFMC-12N-14N	<-->	Male connector, 1/2 inch NPT to 1/4 inch NPT	2	0.3	1/2	1/4	7/8	1.62	0.31
BFMC-12N-38N	<-->	Male connector, 1/2 inch NPT to 3/8 inch NPT	2	0.2	1/2	3/8	7/8	1.62	0.44
BFMC-12N	<-->	Male connector, 1/2 inch NPT to 1/2 inch NPT	2	0.3	1/2	1/2	7/8	1.81	0.56




BFFC-12N-14N

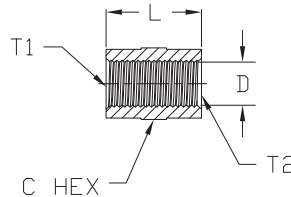

NITRA™ Female Brass Connectors									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	C Hex	L	Flow Dia. D
BFFC-18N	<-->	Female connector, 1/8 inch NPT to 1/8 inch NPT	5	0.1	1/8	1/8	9/16	0.75	0.34
BFFC-14N-18N	<-->	Female connector, 1/4 inch NPT to 1/8 inch NPT	5	0.1	1/4	1/8	3/4	0.97	0.34
BFFC-14N	<-->	Female connector, 1/4 inch NPT to 1/4 inch NPT	5	0.2	1/4	1/4	3/4	1.12	0.44
BFFC-38N-14N	<-->	Female connector, 3/8 inch NPT to 1/4 inch NPT	5	0.2	3/8	1/4	7/8	1.16	0.44
BFFC-38N	<-->	Female connector, 3/8 inch NPT to 3/8 inch NPT	5	0.3	3/8	3/8	7/8	1.12	0.52
BFFC-12N-14N	<-->	Female connector, 1/2 inch NPT to 1/4 inch NPT	2	0.4	1/2	1/4	1-1/16	1.28	0.44
BFFC-12N-38N	<-->	Female connector, 1/2 inch NPT to 3/8 inch NPT	2	0.2	1/2	3/8	15/16	1.32	0.52
BFFC-12N	<-->	Female connector, 1/2 inch NPT to 1/2 inch NPT	2	0.4	1/2	1/2	1-1/16	1.50	0.70




BFMFR-38N-14N

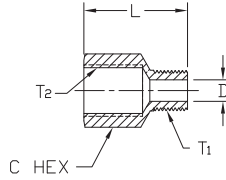

NITRA™ Male to Female Brass Connectors									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	C Hex	L	Flow Dia. D
BFMFR-14N-18N	<-->	Male to female connector, 1/4 inch NPT male to 1/8 inch NPT female	5	0.1	1/4	1/8	3/4	1.06	0.22
BFMFR-38N-18N	<-->	Male to female connector, 3/8 inch NPT male to 1/8 inch NPT female	5	0.1	3/8	1/8	7/8	1.1	0.22
BFMFR-38N-14N	<-->	Male to female connector, 3/8 inch NPT male to 1/4 inch NPT female	5	0.1	3/8	1/4	7/8	1.25	0.314
BFMFR-12N-38N	<-->	Male to female connector, 1/2 inch NPT male to 3/8 inch NPT female	5	0.4	1/2	3/8	1-1/16	1.47	0.44




BFHB-12N-14N

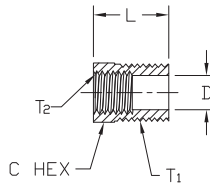

NITRA™ Brass Hex Bushing									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	C Hex	L	Flow Dia. D
BFHB-14N-18N	<-->	Hex bushing, 1/4 inch NPT male to 1/8 inch NPT female	5	0.3	1/4	1/8	9/16	0.75	0.34
BFHB-38N-18N	<-->	Hex bushing, 3/8 inch NPT male to 1/8 inch NPT female	5	0.3	3/8	1/8	11/16	0.75	0.34
BFHB-38N-14N	<-->	Hex bushing, 3/8 inch NPT male to 1/4 inch NPT female	5	0.3	3/8	1/4	3/4	0.75	0.44
BFHB-12N-18N	<-->	Hex bushing, 1/2 inch NPT male to 1/8 inch NPT female	2	0.3	1/2	1/8	7/8	1.0	0.34
BFHB-12N-14N	<-->	Hex bushing, 1/2 inch NPT male to 1/4 inch NPT female	2	0.3	1/2	1/4	7/8	1.0	0.44
BFHB-12N-38N	<-->	Hex bushing, 1/2 inch NPT male to 3/8 inch NPT female	2	0.2	1/2	3/8	7/8	1.0	0.57




BFEE-14N

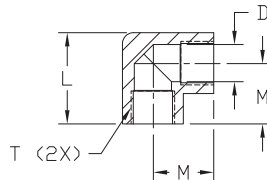

NITRA™ Brass Female Elbow								
Inch Sizes - dimensions in inches								
Part No.	Price	Description	Parts Per Pkg	Weight	T	M	Flow Dia. D	L
BFEE-18N	<-->	Female elbow, 1/8 inch NPT female	2	0.2	1/8	0.55	0.339	0.83
BFEE-14N	<-->	Female elbow, 1/4 inch NPT female	2	0.2	1/4	0.78	0.441	1.06
BFEE-38N	<-->	Female elbow, 3/8 inch NPT female	2	0.4	3/8	0.84	0.571	1.30



BFSE-38N

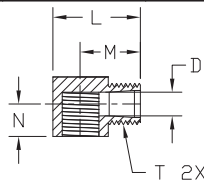


NITRA™ Female to Male Brass Street Elbow									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T	M	N	Flow Dia. D	L
BFSE-18N	<-->	Street elbow, 1/8 inch NPT female to 1/8 male	2	0.2	1/8	0.66	0.35	0.22	0.81
BFSE-14N	<-->	Street elbow, 1/4 inch NPT female to 1/4 male	2	0.2	1/4	0.91	0.47	0.34	1.25
BFSE-38N	<-->	Street elbow, 3/8 inch NPT female to 3/8 male	2	0.3	3/8	0.97	0.49	0.41	1.42
BFSE-12N	<-->	Street elbow, 1/2 inch NPT female to 1/2 male	2	0.4	1/2	1.25	1.03	0.56	1.61

Brass Adapter Fittings




BFMT-14N

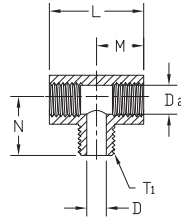

NITRA™ Brass Male Tee Fittings										
Inch Sizes - dimensions in inches										
Part No.	Price	Description	Parts Per Pkg	Weight	T1	T2	L	M	N	Flow Dia. D
BFMT-18N	<-->	Male tee, 1/8 inch NPT male	2	0.3	1/8	1/8	1.06	0.53	0.66	0.22
BFMT-14N	<-->	Male tee, 1/4 inch NPT male	2	0.3	1/4	1/4	1.52	0.76	0.91	0.31
BFMT-38N	<-->	Male tee, 3/8 inch NPT male	2	0.4	3/8	3/8	1.68	0.84	0.97	0.44




BFFT-14N

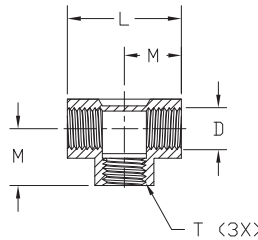

NITRA™ Brass Female Tee Fittings									
Inch Sizes - dimensions in inches									
Part No.	Price	Description	Parts Per Pkg	Weight	T	L	M	Flow Dia. D	
BFFT-18N	<-->	Female tee, 1/8 inch NPT female	2	0.3	1/8	1.06	0.53	0.34	
BFFT-14N	<-->	Female tee, 1/4 inch NPT female	2	0.3	1/4	1.52	0.76	0.44	
BFFT-38N	<-->	Female tee, 3/8 inch NPT female	2	0.5	3/8	1.68	0.84	0.57	
BFFT-12N	<-->	Female tee, 1/2 inch NPT female	2	0.9	1/2	2.14	1.07	0.70	




BFRHP-38N

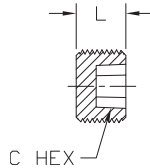

NITRA™ Brass Recessed Hex Plug Fittings						
Inch Sizes - dimensions in inches						
Part No.	Price	Description	Parts Per Pkg	Weight	C Hex	L
BFRHP-14N	<-->	Recessed hex plug, 1/4 inch NPT male	5	0.1	1/4	0.46
BFRHP-38N	<-->	Recessed hex plug, 3/8 inch NPT male	5	0.2	5/16	0.46
BFRHP-12N	<-->	Recessed hex plug, 1/2 inch NPT male	5	0.2	3/8	0.61



BFHHP-38N

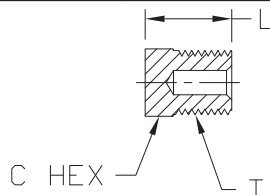

NITRA™ Brass Hex Plug Fittings							
Inch Sizes - dimensions in inches							
Part No.	Price	Description	Parts Per Pkg	Weight	T	C Hex	L
BFHHP-18N	<-->	Hex head plug, 1/8 inch NPT male	5	0.1	1/8	7/16	0.56
BFHHP-14N	<-->	Hex head plug, 1/4 inch NPT male	5	0.1	1/4	9/16	0.75
BFHHP-38N	<-->	Hex head plug, 3/8 inch NPT male	5	0.1	3/8	11/16	0.78
BFHHP-12N	<-->	Hex head plug, 1/2 inch NPT male	5	0.2	1/2		0.97