


# Tools – Thread Repair


RUKO internal and external thread chasers adjust to the correct thread diameter and pitch to repair damaged threads and remove rust and burrs. Using the undamaged thread as a guide, hardened tool steel blades reach into the root of the thread to trim the damaged area. They are suitable for right or left hand threads (metric and inches) and require no prior thread measurement.

## Internal Thread Chaser

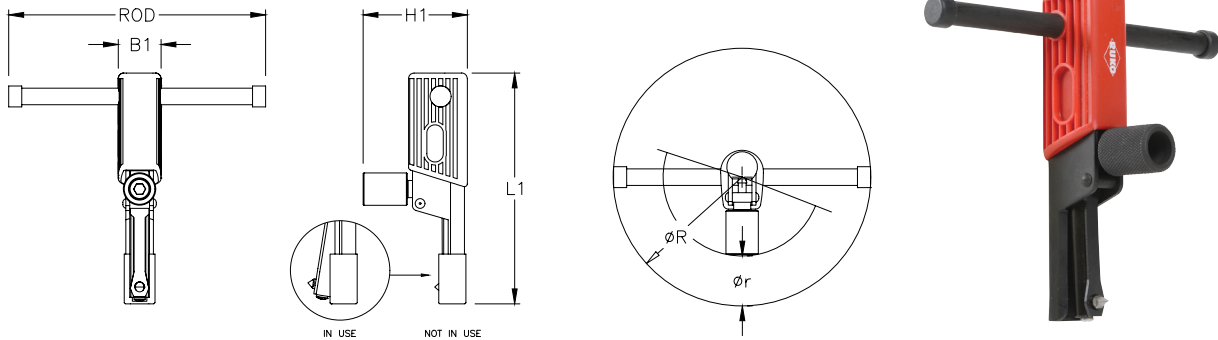

RUKO Internal Thread Chasers								
Part #	Price	Internal Thread Range Ø	Total Length L1	B1	H1	ROD	Ør	ØR
244800	\$91.00	5/16 to 7/16 in (M8 to M11)	4.291 in (109.0 mm)	0.709 in (18.0 mm)	1.771 in (45.0 mm)	4.567 in (116.0 mm)	0.669 in (17.0 mm)	1.535 to (39.0 mm)
244801	\$93.00	1/2 to 5/8 in (M12 to M16)	4.291 in (109.0 mm)	0.709 in (18.0 mm)	1.771 in (45.0 mm)	4.567 in (116.0 mm)	0.669 in (17.0 mm)	1.535 to (39.0 mm)
244802	\$98.00	11/16 to 13/16 in (M16 to M20)	4.370 in (111.0 mm)	0.827 in (21.0 mm)	2.087 in (53.0 mm)	5.118 in (130.0 mm)	0.787 in (20.0 mm)	1.772 in (45.0 mm)
244803	\$131.00	7/8 to 1-1/4 in (M22 to M32)	5.354 in (136.0 mm)	1.063 in (27.0 mm)	2.520 in (64.0 mm)	6.339 in (161.0 mm)	1.063 in (27.0 mm)	2.126 in (54.0 mm)
Spare blades								
244800-1	\$16.50	RUKO thread repair blade, replacement, 5/16 to 7/16 inch (M8 to M11), internal threads. For use with 244800.						
244801-1	\$17.00	RUKO thread repair blade, replacement, 1/2 to 5/8 inch (M12 to M16), internal threads. For use with 244801.						
244802-1	\$17.50	RUKO thread repair blade, replacement, 11/16 to 13/16 inch (M16 to M20), internal threads. For use with 244802.						
244803-1	\$18.00	RUKO thread repair blade, replacement, 7/8 to 1 1/4 inch (M22 to M32), internal threads. For use with 244803.						

## External Thread Chaser

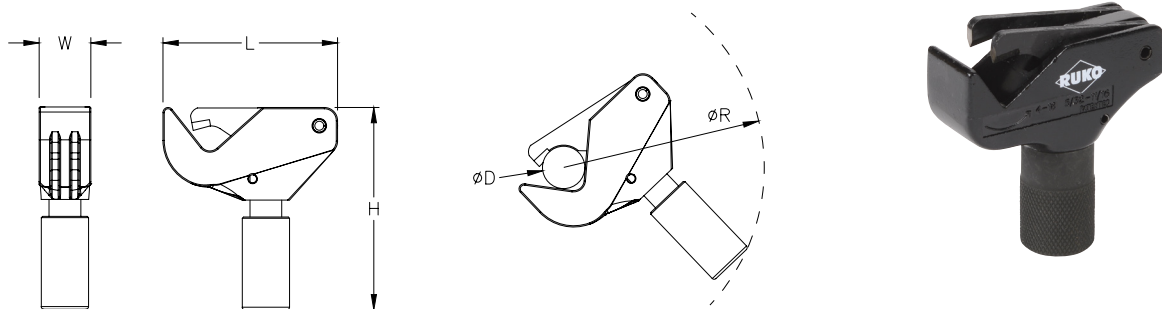

RUKO External Thread Chasers						
Part #	Price	External Thread Range Ø	L	W	H	ØR
244700	\$82.00	5/32 to 11/16 in (M4 to M18)	2.402 in (61.0 mm)	0.906 in (23.0 mm)	2.441 in (62.0 mm)	2.677 in (68.0 mm)
244701	\$82.00	11/16 in to 1-1/2 in (M17 to M38)	4.134 in (105.0 mm)	1.260 in (32.0 mm)	4.331 in (110.0 mm)	4.606 in (117.0 mm)
Spare blades						
244700-1	\$26.00	RUKO thread repair blade, replacement, 5/32 - 11/16 inch (M4 - M18), external threads. For use with 244700.				
244701-1	\$31.00	RUKO thread repair blade, replacement, 11/16 - 1 1/2 inches (M17 - M38), external threads. For use with 244701.				

# Tools – Thread Repair

## Thread Chaser Sets

RUKO Thread Chaser Sets		
Part #	Price	Description
<b>244900</b>	\$247.00	RUKO thread repair set, 4 pieces, 5/32 - 1-1/2 inch (M4 - M38) external threads. Heavy-duty plastic case included.
<b>244903</b>	\$419.00	RUKO thread repair set, 16 pieces, 5/16 - 1-1/4 inch (M8 - M32) internal threads. Heavy-duty plastic case, (4) thumb wrenches and (4) protective caps included.
<b>244905</b>	\$297.00	RUKO thread repair set, 10 pieces, 5/32 - 11/16 inch (M4 - M19) external threads, 5/16 - 5/8 inches (M8 - M16) internal threads. Heavy-duty plastic case, (2) thumb wrenches and (2) protective caps included.
<b>244907</b>	\$669.00	RUKO thread repair set, 20 pieces, 5/32 - 1-1/2 inch (M4 - M38) external threads, 5/16 - 1-1/4 inch (M8 - M32) internal threads. Heavy-duty plastic case, (4) thumb wrenches and (4) protective caps included.



**244900**



**244903**



**244905**



**244907**