



Wera

Zyklop Speed Ratchet and Socket Sets

3/8 inch Drive Imperial Ratchet Sets



3/8 inch Drive Imperial Ratchet Sets			
Part Number	Description	Pcs/Pkg	Price Each
05003595055	Wera socket set with Zyklop Speed ratchet, 3/8 inch drive, SAE, 17 pieces, includes ratchet, 125 mm and 200 mm extensions with free-turning sleeves, 165 mm sliding T-handle, universal joint, (12) sockets (1/4, 5/16, 11/32, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16 and 7/8 inch). Manufacturer part number: 003595. Sturdy metal case included.	1 set	
05003596055	Wera driver bit and socket set with Zyklop Speed ratchet, 3/8 inch drive, SAE, 38 pieces, includes ratchet, 125 mm and 200 mm locking extensions with free-turning sleeves, 165 mm sliding T-handle, universal joint, 76 mm wobble extension, 3/8 inch x 1/4 inch x 44 mm long bit adaptor, (12) sockets (1/4, 5/16, 11/32, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16 and 7/8 inch), 5.5 mm flat/slotted bit, (2) Phillips bits (#2 and #3), (2) Pozidriv bits (#2 and #3), (7) Hex-Plus bits (5/64, 3/32, 1/8, 9/64, 5/32, 3/16 and 7/32 inch), (7) Torx bits (TX10, TX15, TX20, TX25, TX27, TX30 and TX40). Manufacturer part number: 003596. Sturdy metal case included.	1 set	



Wera socket set with Zyklop Speed ratchet, 3/8 inch drive, SAE, 17 pieces. Includes the pieces listed in the table below.

05003595055 Ratchet Set Contents		
	3/8 Zyklop ratchet	
	Sliding T-handle	3/8 x 6
	6-point socket	1/4, 5/16, 11/32, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16, 7/8
	Extension	3/8 x 8, 3/8 x 5
	Universal joint	3/8 x 2

Note: All dimensions are in inches.



Wera driver bit and socket set with Zyklop Speed ratchet, 3/8 inch drive, SAE, 38 pieces. Includes the pieces listed in the table below.

05003596055 Ratchet Set Contents		
	3/8 Zyklop ratchet	
	Sliding T-handle	3/8 x 6
	6-point socket	1/4, 5/16, 11/32, 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4, 13/16, 7/8
	Wobble extension	3/8 x 3
	Universal joint	3/8 x 2
	Lockable extension	3/8 x 8, 3/8 x 5
	Bit adaptor	1/4 x 3/8 x 1.7
	Flat (slotted) bit	1.0 x 5.5
	Hex bit	5/64, 3/32, 1/8, 9/64, 5/32, 3/16, 7/32
	Phillips bit	PH 2, PH 3
	Pozidriv bit	PZ 2, PZ 3
	Torx® bit	TX 10, TX 15, TX 20, TX 25, TX 27, TX 30, TX 40

Note: All dimensions are in inches.



3/8 inch Drive Metric Ratchet Sets



Zyklop Speed Ratchet and Socket Sets

3/8 inch Drive Metric Ratchet Sets			
Part Number	Description	Pcs/Pkg	Price Each
05003593055	Wera socket set with Zyklop Speed ratchet, 3/8 inch drive, metric, 23 pieces, includes ratchet, 125 mm and 200 mm extensions with free-turning sleeves, 165 mm sliding T-handle, universal joint, (18) sockets (6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22 and 24 mm). Manufacturer part number: 003593. Sturdy metal case included.	1 set	
05003594055	Wera driver bit and socket set with Zyklop Speed ratchet, 3/8 inch drive, metric, 43 pieces, includes ratchet, 125 mm and 200 mm locking extensions with free-turning sleeves, 165 mm sliding T-handle, universal joint, 76 mm wobble extension, 3/8 inch x 1/4 inch x 44 mm long bit adaptor, (18) sockets (6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22 and 24 mm), 5.5 mm flat/slotted bit, (2) Phillips bits (#2 and #3), (2) Pozidriv bits (#2 and #3), (6) Hex-Plus bits (3, 4, 5, 6, 8 and 10 mm), (7) Torx bits (TX10, TX15, TX20, TX25, TX27, TX30 and TX40). Manufacturer part number: 003594. Sturdy metal case included.	1 set	



Wera socket set with Zyklop Speed ratchet, 3/8 inch drive, metric, 23 pieces. Includes the pieces listed in the table below.

05003593055 Ratchet Set Contents			
	3/8 Zyklop ratchet		
	Sliding T-handle	3/8 x 165	
	6-point socket	6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22, 24	
	Extension	3/8 x 200, 3/8 x 125	
	Universal joint	3/8 x 50	

Note: Fractional dimensions are in inches.
Whole and decimal dimensions are in millimeters.



Wera driver bit and socket set with Zyklop Speed ratchet, 3/8 inch drive, metric, 43 pieces. Includes the pieces listed in the table below.

05003594055 Ratchet Set Contents			
	3/8 Zyklop ratchet		
	Sliding T-handle	3/8 x 165	
	6-point socket	6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22, 24	
	Wobble extension	3/8 x 76	
	Universal joint	3/8 x 50	
	Lockable extension	3/8 x 200, 3/8 x 125	
	Bit adaptor	1/4 x 3/8 x 44	
	Flat (slotted) bit	1.0 x 5.5	
	Hex bit	3, 4, 5, 6, 8, 10	
	Phillips bit	PH 2, PH 3	
	Pozidriv bit	PZ 2, PZ 3	
	Torx® bit	TX 10, TX 15, TX 20, TX 25, TX 27, TX 30, TX 40	

Note: Fractional dimensions are in inches.
Whole and decimal dimensions are in millimeters.

Wera Ratchets



Zyklop Speed Ratchet




Small return angle

The fine 72 tooth ratchet mechanism has a low return angle of 5°. This short stroke allows fast and precise work in small spaces.



Swivel ratchet head


The ratchet head pivots freely and locks at 0°, 15° and 90°, making it possible to work in confined spaces with ample hand clearance.

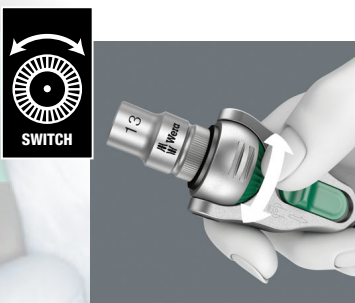

Simple direction change

Rotating the large thumbwheel quickly changes rotation from clockwise to counterclockwise from any position of the ratchet head.

Wera Speed Ratchets			
Part Number	Description	Pcs/ Pkg	Price Each
05003500055	Wera Zyklop Speed ratchet, 1/4 inch drive, with locking swivel head and ergonomic grip handle.	1	
05003550055	Wera Zyklop Speed ratchet, 3/8 inch drive, with locking swivel head and ergonomic grip handle.	1	
05003600055	Wera Zyklop Speed ratchet, 1/2 inch drive, with locking swivel head and ergonomic grip handle.	1	

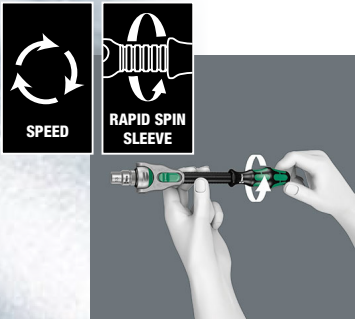

Unbelievably fast

The gyrating mass design along with the Kraftform handle and free-turning sleeve allow for rapid rotation when used as a screwdriver.