


Wera Screwdrivers

Large Ratcheting Multi-Bit Screwdrivers


Wera's large ratcheting multi-bit screwdriver is a high quality bit holder that boasts a Kraftform ergonomic handle, Rapidaptor or magnetic quick release chuck, and fine tooth ratcheting function. The ratchet is built into the handle with an 8° return angle, switchover ring (right, locked, left), and a maximum torque of 50 Nm.



Directional Ratchet Switch

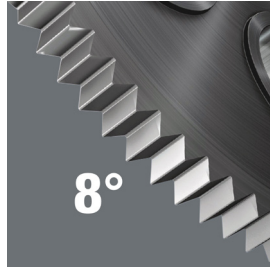

Fine-tooth Design

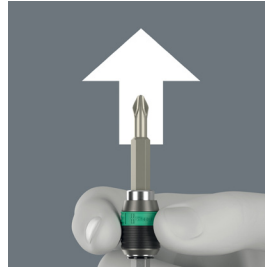

Rapidaptor Technology



KRAFTFORM
ERGONOMICS



RAPIDAPTOR
TECHNOLOGY



HEX-PLUS

Large Ratcheting Rapidaptor Multi-Bit Screwdrivers								
Part Number	Number of Pieces	Part Image	Type	Bit Size	Overall Length	Handle Type	Set Includes	Price
05051461001	1		n/a		5.6in [141mm]	Kraftform ergonomic handle	Handle only	
05051041001	17		Phillips	#1, #2, #3			(1) Kraftform Kompakt Rapidaptor bit holding ratcheting screwdriver, (16) 3.5in standard bits (Phillips: #1, #2, #3, tamperproof torx: T10, T15, T20, T25, T30, hex: 3/32in, 1/8in, 5/32in, 3/16in, slotted: 5.5mm, square: #1, #2, #3), (1) robust textile pouch, (1) hook and loop fastener strip for storage	
			Slotted	5.5mm				
			External Hex	3/32in, 1/8in, 5/32in, 3/16in				
			Tamperproof Torx	T10, T15, T20, T25, T30				
			Square	#1, #2, #3				
05051040001	17		Phillips	#1, #2, #3			(1) Kraftform Kompakt Rapidaptor bit holding ratcheting screwdriver, (16) 3.5in standard bits (Phillips: #1, #2, #3 Pozidriv: #1, #2, #3, tamperproof torx: T10, T15, T20, T25, T30, hex: 3mm, 4mm, 5mm, 6mm, slotted: 5.5mm), (1) robust textile pouch, (1) hook and loop fastener strip for storage	
			Slotted	5.5mm				
			External Hex	3mm, 4mm, 5mm, 6mm				
			Tamperproof Torx	T10, T15, T20, T25, T30				
			Pozidriv	#1, #2, #3				
05073660001	6		Phillips	#1, #2	8.5in [216mm]	Kraftform ergonomic handle with bit storage	(1) Kraftform ergonomic handle with bit storage ratcheting screwdriver, (6) 1in standard bits (Phillips: #1, #2, Pozidriv: #1, #2, slotted: 5.5mm, 6.5mm)	
			Slotted	5.5mm, 6.5mm				
			Pozidriv	#1, #2				
05073661002	6		Phillips	#1, #2			(1) Kraftform ergonomic handle with bit storage ratcheting screwdriver, (6) 1in standard bits (Phillips: #1, #2, square: #1, #2, slotted: 5.5mm, 6.5mm)	
			Slotted	5.5mm, 6.5mm				
			Square	#1, #2				

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.



Wera Screwdrivers

Large Ratcheting Rapidaptor Multi-Bit Screwdrivers


Wera's Rapidaptor ratcheting multi-bit screwdrivers feature a packed bitholding screwdriver built into a small footprint. The driver's Rapidaptor quick-release chuck allows lightning-fast bit changes without any extra tools. The ratchet mechanism with fine toothing is integrated in the handle (36 teeth/return angle 9°). This innovative function eases and accelerates screwdriving without having to reposition the tool, boasting three positions (clockwise/counterclockwise/no ratcheting).



Directional Ratchet Switch



Fine-tooth Design

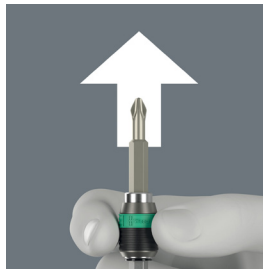

Rapidaptor Technology



KRAFTFORM
ERGONOMICS



RAPIDAPTOR
TECHNOLOGY



SWITCH

Large Ratcheting Rapidaptor Multi-Bit Screwdrivers

Part Number	Number of Pieces	Part Image	Drive Size	Handle Length	Overall Length	Handle Type	Locking Mechanism	Price
<u>05051494001</u>	1		1/4in	4.4in [111mm]	5.5in [140mm]	Kraftform ergonomic handle	Rapidaptor quick-release bit holder	

Large Ratcheting Rapidaptor Multi-Bit Screwdriver Sets

Part Number	Number of Pieces	Part Image	Type	Bit Size	Set Includes	Price
<u>05051530001</u>	17		Phillips	#1, #2, #3	(1) Kraftform Kompakt Rapidaptor bit holding ratcheting screwdriver, (16) 3.5in standard bits (Phillips: #1, #2, #3 Pozidriv: #1, #2, #3, tamperproof torx: T10, T15, T20, T25, T30, external hex: 3mm, 4mm, 5mm, 6mm, slotted: 5.5mm), (1) robust textile pouch	
			Pozidriv	#1, #2, #3		
			Tamperproof Torx	T10, T15, T20, T25, T30		
			External hex	3mm, 4mm, 5mm, 6mm		
			Slotted	5.5mm		
<u>05051531001</u>	17		Phillips	#1, #2, #3	(1) Kraftform Kompakt Rapidaptor bit holding ratcheting screwdriver, (16) 3.5in standard bits (Phillips: #1, #2, #3, tamperproof torx: T10, T15, T20, T25, T30, external hex: 3/32in, 1/8in, 5/32in, 3/16in, square: #1, #2, #3, slotted: 5.5mm), (1) robust textile pouch	
			Tamperproof Torx	T10, T15, T20, T25, T30		
			External hex	3/32in, 1/8in, 5/32in, 3/16in		
			Square	#1, #2, #3		
			Slotted	5.5mm		

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.