

# Enclosure Accessories - Panel Mounting



## JIC and NEMA Swing-Out Panel Kits

Swing-out panel kits are designed to allow mounting of switches, pilot lights and other components near the front of the enclosure for easy access or meter reading.

Sealing washers are included to ensure that the enclosure will meet the original NEMA rating after installation.

These kits are designed for use with standard Wiegmann JIC and NEMA panels. They do not work with N412xxx Ultimate Series enclosures or HW-XXXX series non-metal enclosures.



WAJCDFK



WANADFK

Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Panel Kits	Price	Description	Wt. [lb]
<a href="#"><u>WAJCDFK</u></a>	\$47.50	Wiegmann enclosure swing-out panel kit, plated steel, for use on NEMA continuous hinge style enclosures. Includes (2) hinge brackets, (2) fixed brackets, and mounting hardware. Panel sold separately.	1
<a href="#"><u>WANADFK</u></a>	\$58.00	Wiegmann enclosure swing-out panel kit, plated steel, for use on NEMA single and two-door style enclosures. Includes (2) hinge brackets, (2) fixed brackets, and mounting hardware. Panel sold separately.	3

**Note: Panels must be ordered separately from enclosure.**

## Panel Supports

Panel supports provide additional support for panels on which heavy instruments are mounted.

They are adjustable so the weight of the panel is partially supported by the bottom of the enclosure.



WAPS03

Panel Supports	Price	Description	Wt. [lb]
<a href="#"><u>WAPS03</u></a>	\$44.00	Wiegmann enclosure panel support foot, white polyester powder finish, for single and two-door enclosures where distance between bottom of panel and enclosure is less than 2.25 inches. Package of 2. Load limit: 250 lbs.	1
<a href="#"><u>WAPS09</u></a>	\$69.00	Wiegmann enclosure panel support foot, white polyester powder finish, for free-standing enclosures where distance between bottom of panel and enclosure is less than 8.5 inches and greater than 2.88 inches. Package of 2. Load limit: 250 lbs.	2

## Center Panel Supports for Freestanding Enclosures

Center Panel Supports	Price	Description	Wt. [lb]
<a href="#"><u>WA60FSCPS</u></a>	\$169.00	Wiegmann enclosure center panel support, white polyester powder finish, for 60 inch high enclosures. Allows two single-wide sub-panels (including swing-out panels and rack mount frames) to be mounted in a double-door enclosure.	15
<a href="#"><u>WA72FSCPS</u></a>	\$204.00	Wiegmann enclosure center panel support, white polyester powder finish, for 72 inch high enclosures. Allows two single-wide sub-panels (including swing-out panels and rack mount frames) to be mounted in a double-door enclosure.	21
<a href="#"><u>WA90FSCPS</u></a>	\$243.00	Wiegmann enclosure center panel support, white polyester powder finish, for 90 inch high enclosures. Allows two single-wide sub-panels (including swing-out panels and rack mount frames) to be mounted in a double-door enclosure.	22



WA60FSCPS

# Enclosure Accessories - Panel Mounting



Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

## Adjustable Depth Mounting Kit

Adjustable depth mounting kits allow mounting of accessories at variable depths from front to back. They fit Wiegmann Ultimate Series NEMA 412 enclosures of all depths.

Kits may be used to mount the following: swing-out panels, DIN rails, rack angles, mounting channels and grid straps.

Kits include either two or four sets of brackets, mounting clips, and hardware. One set required for each enclosure collar stud.

Finish: White Polyester Powder

Note: Dead front kit CANNOT be mounted on adjustable depth mounting kit.



HFWADM64C

Adjustable Depth Mounting Kit	Price	Enclosure Depth	Sets of Brackets, Mounting Clips, and Hardware Included in Kit	Wt. [lb]
<a href="#">HFWADM64C</a>	\$64.00	6 or more inches	4	2
<a href="#">HFWADM84C</a>	\$71.00	8 or more inches	4	
<a href="#">HFWADM82C</a>	\$38.50	8 or more inches	2	
<a href="#">HFWADM104C</a>	\$37.00	10 or more inches	4	1
<a href="#">HFWADM102C</a>	\$74.00	10 or more inches	2	
<a href="#">HFWADM124C</a>	\$83.00	12 or more inches	4	2
<a href="#">HFWADM122C</a>	\$42.00	12 or more inches	2	

## Dead Front Kit

Dead front kits allow fixed sub-mounting surface for installation directly behind the door of Ultimate Series NEMA 412 enclosures.

The clearance from the dead panel face to the interior door face is 1-5/16-inch on solid doors, and 1-1/16-inch on window doors.

Each kit includes mounting brackets, grounding hardware, and a carbon steel panel with white polyester powder finish.

Dead fronts meet NEMA 1 with enclosure door open.

Note: Dead front kit CANNOT be mounted on adjustable mounting kit.




HFWDF1212C

Dead Front Kit	Price	For Enclosure Size (HxW) in [mm]	Wt. [lb]
<a href="#">HFWDF1212C</a>	\$67.00	12 X 12 (304 x 304)	3
<a href="#">HFWDF1612C</a>	\$75.00	16 X 12 (406 x 304)	5
<a href="#">HFWDF2016C</a>	\$98.00	20 X 16 (508 x 406)	7
<a href="#">HFWDF2020C</a>	\$112.00	20 X 20 (508 x 508)	9
<a href="#">HFWDF2420C</a>	\$126.00	24 X 20 (609 x 508)	11
<a href="#">HFWDF2424C</a>	\$143.00	24 X 24 (609 x 609)	12
<a href="#">HFWDF3024C</a>	\$169.00	30 X 24 (762 x 609)	16

## Panel Conversion Kit

Panel conversion kits allow installation of standard NP series subpanels within Ultimate Series NEMA 12 enclosures. Conversion brackets bolt over the top of existing studs, then install the subpanel. Kit includes four adapter plates and hardware for mounting subpanels.

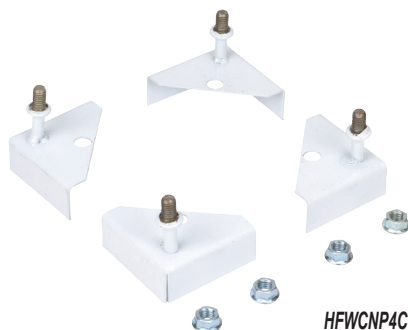

HFWCNP4C

Panel Conversion Kit	Price	For Enclosure Size	Wt. [lb]
<a href="#">HFWCNP4C</a>	\$50.00	Wiegmann enclosure panel conversion kit, white polyester powder finish. Allows standard NP series sub panels to mount in N412 series enclosures up to 30 x 30 inch (HxW) nominal size. Includes (4) brackets and mounting hardware.	2