

Cerabar[®] PMP23 Series Hygienic Pressure Transmitters

Features

- Ideal for industrial pressure measurement in gas, liquid, vapor, and dust applications with hygienic requirements
- Measuring ranges from 6 psig up to 600 psig
- Fully welded stainless steel 1-1/2in sanitary tri-clamp process connection for hygienic food and beverage applications
- Suitable for CIP (Clean-In-Place) / SIP (Sterilization-In-Place) cleaning
- Accuracy of +/- 0.3% of full range
- Models available with an analog 4-20mA output or 4-20mA output and IO-Link
- IP67 or IP69 protection rating depending on model
- 4-pin M12 electrical connection
- IO-Link connectivity on select models



Part No. [PMP23-CA1M1FF3CJ](#)



Part No. [PMP23-CAAN1FF3CJ](#)



For a variety of cable options see our website www.AutomationDirect.com

Endress + Hauser PMP23 Hygienic Pressure Transmitter Selection

Part Number	Price	Weight (lb)	Pressure Range (psig)	Max Working Pressure (psig)	Over Pressure Limit (psig)	Accuracy	Sensing Element	Output 1	Output 2	Process Connection	Protection Rating	Electrical Connection
PMP23-CA1M1FF3CJ	\$469.00	1.2	0 to 6	15	24	+/- 0.3% of full range	316L (1.4435)	4-20 mA	N/A	1-1/2in sanitary tri-clamp	IP65 / 67	4-pin M12 quick-disconnect (Plastic)
PMP23-CA1M1HF3CJ	\$469.00	1.2	0 to 15	40.5	60							
PMP23-CA1M1KF3CJ	\$469.00	1.2	0 to 30	100.5	150							
PMP23-CA1M1MF3CJ	\$469.00	1.2	0 to 60	160.5	240							
PMP23-CA1M1NF3CJ	\$469.00	1.2	0 to 90	240	360							
PMP23-CA1M1PF3CJ	\$469.00	1.2	0 to 150	375	600							
PMP23-CA1M1QF3CJ	\$469.00	1.2	0 to 240	375	960							
PMP23-CA1M1RF3CJ	\$469.00	1.2	0 to 375	375	1500							
PMP23-CA1M1SF3CJ	\$469.00	1.2	0 to 600	1500	2400							
Part Number	Price	Weight (lb)	Pressure Range (psig)	Max Working Pressure (psig)	Over Pressure Limit (psig)	Accuracy	Sensing Element	Output 1	Output 2	Process Connection	Protection Rating	Electrical Connection
PMP23-CAAN1FF3CJ	\$529.00	1.2	0 to 6	15	24	+/- 0.3% of full range	316L (1.4435)	4-20mA	IO-Link (SSP Ed.2 v1.1)	1-1/2in sanitary tri-clamp	IP66 / 69	4-pin M12 quick-disconnect (Metal)
PMP23-CAAN1HF3CJ	\$529.00	1.2	0 to 15	40.5	60							
PMP23-CAAN1KF3CJ	\$529.00	1.2	0 to 30	100.5	150							
PMP23-CAAN1MF3CJ	\$529.00	1.2	0 to 60	160.5	240							
PMP23-CAAN1NF3CJ	\$529.00	1.2	0 to 90	240	360							
PMP23-CAAN1PF3CJ	\$529.00	1.2	0 to 150	375	600							
PMP23-CAAN1QF3CJ	\$529.00	1.2	0 to 240	375	960							
PMP23-CAAN1RF3CJ	\$529.00	1.2	0 to 375	375	1500							
PMP23-CAAN1SF3CJ	\$529.00	1.2	0 to 600	1500	2400							

For complete technical information and installation see [Vendor Tech Specs](#) and [Vendor Manual links](#).


Cerabar® PMP23 Series Hygienic Pressure Transmitters

Endress + Hauser PMP23 Hygienic Pressure Transmitter Resources						
Part Number	Drawing Link	Vendor Technical Specifications	Vendor Operating Manual	Vendor Brief Operating Instructions	Vendor Insert	IO-Link Quick Start Guide
PMP23-CA1M1FF3CJ	PDF	PDF	PDF	PDF	PDF	N/A
PMP23-CA1M1HF3CJ	PDF					
PMP23-CA1M1KF3CJ	PDF					
PMP23-CA1M1MF3CJ	PDF					
PMP23-CA1M1NF3CJ	PDF					
PMP23-CA1M1PF3CJ	PDF					
PMP23-CA1M1QF3CJ	PDF					
PMP23-CA1M1RF3CJ	PDF					
PMP23-CA1M1SF3CJ	PDF					
PMP23-CAAN1FF3CJ	PDF	PDF	PDF	PDF	PDF	PDF
PMP23-CAAN1HF3CJ	PDF					
PMP23-CAAN1KF3CJ	PDF					
PMP23-CAAN1MF3CJ	PDF					
PMP23-CAAN1NF3CJ	PDF					
PMP23-CAAN1PF3CJ	PDF					
PMP23-CAAN1QF3CJ	PDF					
PMP23-CAAN1RF3CJ	PDF					
PMP23-CAAN1SF3CJ	PDF					

For complete technical information and installation see Vendor Tech Specs and Vendor Manual links.


PMP23 Series Wiring Examples

(PMP23-CA1xxxxxxx Models)

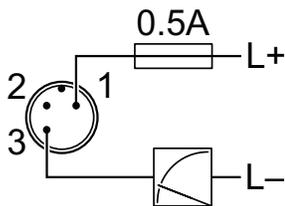

1 x analog

(PMP23-CAAxxxxxxx Models)

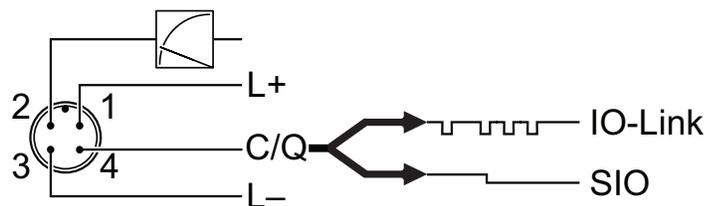

1 x analog / 1 x IO-Link