

NEMA 1 and 3R Screw Cover Wall-Mount with Knockouts



Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted pre-galvanized steel

Construction

- Bodies and doors fabricated from 16 or 14 gauge carbon steel [see table]
- Drip shield top and smooth seamless sides and front
- A slip-on reversible cover is securely fastened with screws located along bottom edge
- No gasketing is required
- Hasp for padlocking or meter seal is provided, except as noted

Listings

- UL 50, Types 1 and 3 [UL file E23553]
- NEMA/EEMAC Type 1 and 3R



Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount with Knockouts

ANSI 61 Gray Light-Textured	Price	Galvanized	Price	Body/Door Steel Gauge	Enclosure Size HxWxD	Knockout Patterns
RSC040404*	\$21.00	RSC040404G*	\$21.00	16/16	4.25 x 4.63 x 4.63 [108 x 118 x 118]	A
RSC040604*	\$25.00	RSC040604G	\$25.00	16/16	6.25 x 4.63 x 4.63 [159 x 118 x 118]	A
RSC060604	\$26.50	RSC060604G	\$26.50	16/16	6.25 x 6.63 x 4.63 [159 x 168 x 118]	A-B-A
RSC060606	\$28.00	RSC060606G	\$28.00	16/16	6.25 x 6.63 x 6.63 [159 x 168 x 168]	A-B-A
RSC060804	\$30.50	RSC060804G	\$30.50	16/16	8.25 x 6.63 x 4.63 [210 x 168 x 118]	A-B-A
RSC060806	\$35.50	RSC060806G	\$35.50	16/16	8.25 x 6.63 x 6.63 [210 x 168 x 168]	A-B-A
RSC080804	\$35.00	RSC080804G	\$35.00	16/16	8.25 x 8.63 x 4.63 [210 x 219 x 118]	A-B-A
RSC080806	\$41.50	RSC080806G	\$41.50	16/16	8.25 x 8.63 x 6.63 [210 x 219 x 168]	A-B-A
RSC081004	\$40.00	RSC081004G	\$39.50	16/16	10.25 x 8.63 x 4.63 [260 x 219 x 118]	A-B-A
RSC081006	\$47.00	RSC081006G	\$46.50	16/16	10.25 x 8.63 x 6.63 [260 x 219 x 168]	A-B-A
RSC081206	\$52.00	RSC081206G	\$51.00	16/16	12.25 x 8.63 x 6.63 [311 x 219 x 168]	A-B-A
RSC101004	\$45.00	RSC101004G	\$45.00	16/16	10.25 x 10.63 x 4.63 [260 x 270 x 118]	B-A-F-F-A
RSC101006	\$53.00	RSC101006G	\$52.00	16/16	10.25 x 10.63 x 6.63 [260 x 270 x 168]	B-A-F-F-A
RSC101204	\$51.00	RSC101204G	\$51.00	16/16	12.19 x 10.63 x 4.63 [310 x 270 x 118]	B-A-F-F-A
RSC101206	\$59.00	RSC101206G	\$59.00	16/16	12.19 x 10.63 x 6.63 [310 x 270 x 168]	B-A-F-F-A
RSC121204	\$57.00	RSC121204G	\$57.00	16/16	12.63 x 12.63 x 4.63 [321 x 321 x 118]	B-A-F-F-A-B
RSC121206	\$66.00	RSC121206G	\$66.00	16/16	12.19 x 12.63 x 6.63 [310 x 321 x 168]	B-A-F-F-A-B
RSC121504	\$65.00	RSC121504G	\$65.00	16/16	15.19 x 12.63 x 4.63 [386 x 321 x 118]	B-A-F-F-A-B
RSC121506	\$76.00	RSC121506G	\$76.00	16/16	15.19 x 12.63 x 6.63 [386 x 321 x 168]	B-A-F-F-A-B
RSC121806	\$94.00	RSC121806G	\$94.00	16/16	18.19 x 12.63 x 6.63 [462 x 321 x 168]	B-A-F-F-A-B
RSC151806	\$111.00	RSC151806G	\$111.00	16/16	18.19 x 15.63 x 6.63 [462 x 397 x 168]	A-B-A-F-F-A-B-A
RSC181804	\$116.00	RSC181804G	\$111.00	16/16	18.19 x 18.63 x 4.63 [462 x 473 x 118]	A-B-A-F-F-A-B-A
RSC181806	\$133.00	RSC181806G	\$133.00	16/16	18.19 x 18.63 x 6.63 [462 x 473 x 168]	A-B-A-F-F-A-B-A
RSC182406	\$168.00	RSC182406G	\$162.00	16/16	24.19 x 18.63 x 6.63 [614 x 473 x 168]	A-B-A-F-F-A-B-A
RSC242406	\$199.00	RSC242406G	\$205.00	14/14	24.19 x 24.62 x 6.63 [614 x 625 x 168]	A-B-A-F-F-A-B-A

Notes: Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.

*No hasp or meter seal.


Notes: For removal of cover, move downward, then outward. 4x4x4 only has 2 mounting holes centered horizontally. 4x6x4 only has 2 mounting holes centered vertically.

A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard

NEMA 1 and 3R Screw Cover Wall-Mount without Knockouts



Dimensions

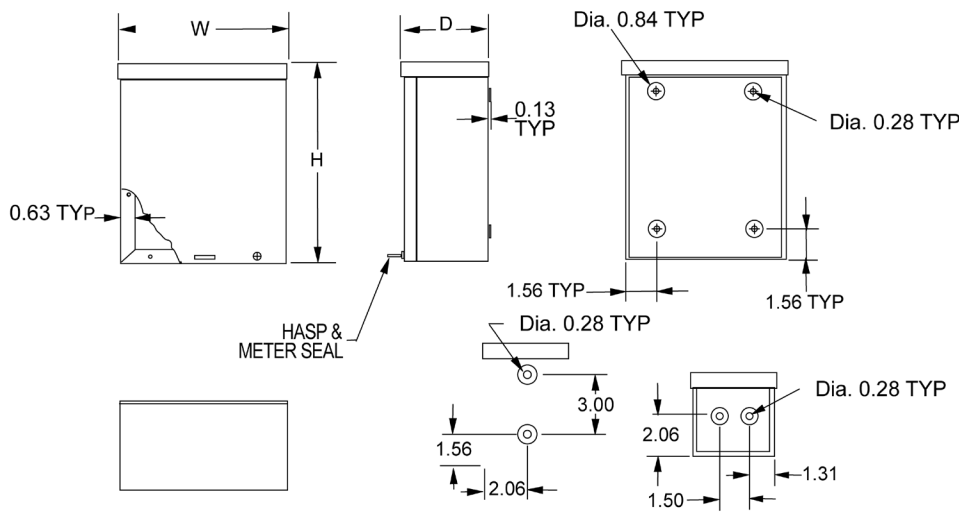

NOTES:

- 1. Enclosures with D=8.00" or more do not have an internal flange.

4.00" x 6.00"
MOUNTING

4.00" x 4.00"
MOUNTING

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$2.75
Note: Field grounding kit includes necessary parts to properly ground enclosure		

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.