

# NEMA 1 and 3R Screw Cover Wall Mount with Knockouts



## Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

## Construction

- Bodies and doors fabricated from 16 or 14 gauge carbon steel [see table]
- Drip shield top and smooth seamless sides and front
- A slip-on reversible cover is securely fastened with screws located along bottom edge
- No gasketing is required
- Hasp for padlocking or meter seal is provided, except as noted

## Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted pre-galvanized steel

## Listings

- UL 50, Types 1 and 3R [UL file E23553]
- CSA Certified, Type 1 and 3R [CSA file LL66078]
- NEMA/EEMAC Type 1 and 3R



Enclosure Shipping Schedule		
Same day	1 - 7 days	1 - 10 days
Color indicates shipping lead time in business days.		


RSC Series NEMA 1 and 3R Screw Cover Wall Mount w/Knockouts						
ANSI 61 Gray Light-Textured	Price	Galvanized	Price	Body/Door Steel Gauge	Enclosure Size HxWxD	Knockout Patterns
RSC040404*	\$17.50	RSC040404G*	\$17.50	16/16	4.25 x 4.63 x 4.63 [108 x 118 x 118]	A
RSC040604*	\$17.75	RSC040604G*	\$17.75	16/16	6.25 x 4.63 x 4.63 [159 x 118 x 118]	A
RSC060604	\$18.00	RSC060604G	\$18.00	16/16	6.25 x 6.63 x 4.63 [159 x 168 x 118]	A-B-A
RSC060606	\$23.00	RSC060606G	\$23.00	16/16	6.25 x 6.63 x 6.63 [159 x 168 x 168]	A-B-A
RSC060804	\$22.00	RSC060804G	\$22.00	16/16	8.25 x 6.63 x 4.63 [210 x 168 x 118]	A-B-A
RSC060806	\$30.00	RSC060806G	\$30.00	16/16	8.25 x 6.63 x 6.63 [210 x 168 x 168]	A-B-A
RSC080804	\$25.50	RSC080804G	\$25.50	16/16	8.25 x 8.63 x 4.63 [210 x 219 x 118]	A-B-A
RSC080806	\$32.50	RSC080806G	\$32.50	16/16	8.25 x 8.63 x 6.63 [210 x 219 x 168]	A-B-A
RSC081004	\$31.00	RSC081004G	\$31.00	16/16	10.25 x 8.63 x 4.63 [260 x 219 x 118]	A-B-A
RSC081006	\$41.00	RSC081006G	\$41.00	16/16	10.25 x 8.63 x 6.63 [260 x 219 x 168]	A-B-A
RSC081206	\$43.50	RSC081206G	\$43.50	16/16	12.25 x 8.63 x 6.63 [311 x 219 x 168]	A-B-A
RSC101004	\$35.50	RSC101004G	\$35.50	16/16	10.25 x 10.63 x 4.63 [260 x 270 x 118]	B-A-F-F-A
RSC101006	\$44.00	RSC101006G	\$44.00	16/16	10.25 x 10.63 x 6.63 [260 x 270 x 168]	B-A-F-F-A
RSC101204	\$43.50	RSC101204G	\$43.50	16/16	12.19 x 10.63 x 4.63 [310 x 270 x 118]	B-A-F-F-A
RSC101206	\$44.50	RSC101206G	\$44.50	16/16	12.19 x 10.63 x 6.63 [310 x 270 x 168]	B-A-F-F-A
RSC121204	\$44.50	RSC121204G	\$44.50	16/16	12.63 x 12.63 x 4.63 [321 x 321 x 118]	B-A-F-F-A-B
RSC121206	\$50.00	RSC121206G	\$50.00	16/16	12.19 x 12.63 x 6.63 [310 x 321 x 168]	B-A-F-F-A-B
RSC121504	\$55.00	RSC121504G	\$55.00	16/16	15.19 x 12.63 x 4.63 [386 x 321 x 118]	B-A-F-F-A-B
RSC121506	\$64.00	RSC121506G	\$64.00	16/16	15.19 x 12.63 x 6.63 [386 x 321 x 168]	B-A-F-F-A-B
RSC121806	\$74.00	RSC121806G	\$74.00	16/16	18.19 x 12.63 x 6.63 [462 x 321 x 168]	B-A-F-F-A-B
RSC151806	\$97.00	RSC151806G	\$97.00	16/16	18.19 x 15.63 x 6.63 [462 x 397 x 168]	A-B-A-F-F-A-B-A
RSC181804	\$101.00	RSC181804G	\$101.00	16/16	18.19 x 18.63 x 4.63 [462 x 473 x 118]	A-B-A-F-F-A-B-A
RSC181806	\$104.00	RSC181806G	\$104.00	16/16	18.19 x 18.63 x 6.63 [462 x 473 x 168]	A-B-A-F-F-A-B-A
RSC182406	\$150.00	RSC182406G	\$150.00	16/16	24.19 x 18.63 x 6.63 [614 x 473 x 168]	A-B-A-F-F-A-B-A
RSC242406	\$175.00	RSC242406G	\$175.00	14/14	24.19 x 24.62 x 6.63 [614 x 625 x 168]	A-B-A-F-F-A-B-A

Note: Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.  
 \*No hasp or meter seal.

Note 1: For removal of cover, move downward, then outward.  
 4x4x4 only has 2 mounting holes centered horizontally.  
 4x6x4 only has 2 mounting holes centered vertically.


Note 2: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

# NEMA 1 and 3R Screw Cover Wall Mount

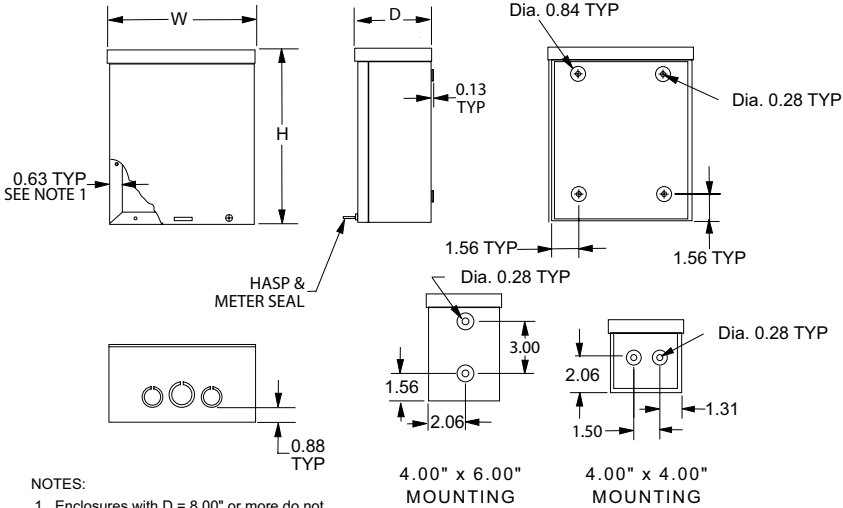

**Knockout Patterns**

- A -- 1/2" TO 3/4"
- B -- 3/4" TO 1"
- F -- 1" TO 1-1/4"

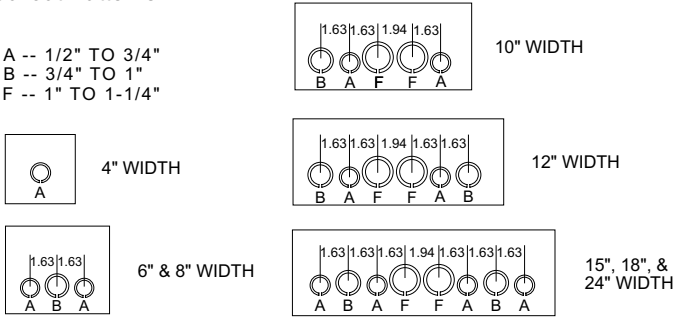

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$1.25
Note: Field grounding kit includes necessary parts to properly ground enclosure		