

# RSC Series NEMA 1 and 3R Screw Cover Wall Mount without Knockouts



## Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

## Construction

- Bodies and doors fabricated from 16, 14, or 12 gauge carbon steel [see table]
- Drip shield top and smooth seamless sides and front
- A slip-on reversible cover is securely fastened with screws located along bottom edge
- No gasketing is required
- Hasp for padlocking or meter seal is provided except as noted

## Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted, pre-galvanized steel

## Listings

- UL 50, Types 1 and 3R [UL file E23553]
- CSA Certified, Type 1 and 3R [CSA file LL66078]
- NEMA/EEMAC Type 1 and 3R



**Note 1:** For removal of cover, move downward, then outward.  
 4x4x4 only has 2 mounting holes centered horizontally.  
 4x6x4 only has 2 mounting holes centered vertically.


**Note 2:** A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

RSC Series NEMA 1 and 3R Screw Cover Wall Mount w/o Knockouts					
ANSI 61 Gray Light-Textured	Price	Galvanized	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
RSC040404NK*	\$18.75	RSC040404GNK*	\$18.75	16/16	4x4x4 [102x102x102]
RSC040604NK*	\$23.00	RSC040604GNK*	\$22.00	16/16	6x4x4 [152x102x102]
RSC060604NK	\$18.00	RSC060604GNK	\$18.00	16/16	6x6x4 [152x152x102]
RSC060606NK	\$25.00	RSC060606GNK	\$25.00	16/16	6x6x6 [152x152x152]
RSC060804NK	\$24.00	RSC060804GNK	\$24.00	16/16	8x6x4 [203x152x102]
RSC060806NK	\$31.50	RSC060806GNK	\$31.50	16/16	8x6x6 [203x152x152]
RSC080804NK	\$24.00	RSC080804GNK	\$24.00	16/16	8x8x4 [203x203x102]
RSC080806NK	\$32.50	RSC080806GNK	\$32.50	16/16	8x8x6 [203x203x152]
RSC081004NK	\$31.50	RSC081004GNK	\$31.50	16/16	10x8x4 [254x203x102]
RSC081006NK	\$41.00	RSC081006GNK	\$41.00	16/16	10x8x6 [254x203x152]
RSC081206NK	\$45.50	RSC081206GNK	\$45.50	16/16	12x8x6 [305x203x152]
RSC101004NK	\$35.50	RSC101004GNK	\$35.50	16/16	10x10x4 [254x254x102]
RSC101006NK	\$46.50	RSC101006GNK	\$46.50	16/16	10x10x6 [254x254x152]
RSC101204NK	\$45.00	RSC101204GNK	\$45.00	16/16	12x10x4 [305x254x102]
RSC101206NK	\$52.00	RSC101206GNK	\$52.00	16/16	12x10x6 [305x254x152]
RSC121204NK	\$45.00	RSC121204GNK	\$45.00	16/16	12x12x4 [305x305x102]
RSC121206NK	\$45.00	RSC121206GNK	\$45.00	16/16	12x12x6 [305x305x152]
RSC121208	\$70.00	RSC121208G	\$67.00	16/16	12x12x8 [305x305x203]
RSC121210	\$77.00	RSC121210G	\$74.00	16/16	12x12x10 [305x305x254]
RSC121504NK	\$57.00	RSC121504GNK	\$57.00	16/16	15x12x4 [381x305x102]
RSC121506NK	\$67.00	RSC121506GNK	\$67.00	16/16	15x12x6 [381x305x152]
RSC121806NK	\$74.00	RSC121806GNK	\$74.00	16/16	18x12x6 [457x305x152]
RSC121808	\$90.00	RSC121808G	\$87.00	16/16	18x12x8 [457x305x203]
RSC151806NK	\$97.00	RSC151806GNK	\$97.00	16/16	18x15x6 [457x381x152]
RSC151808	\$110.00	RSC151808G	\$105.00	16/16	18x15x8 [457x381x203]
RSC161610	\$101.00	RSC161610G	\$97.00	16/16	16x16x10 [406x406x254]
RSC181804NK	\$102.00	RSC181804GNK	\$102.00	16/16	18x18x4 [457x457x102]
RSC181806NK	\$105.00	RSC181806GNK	\$105.00	16/16	18x18x6 [457x457x152]
RSC181808	\$136.00	RSC181808G	\$131.00	16/16	18x18x8 [457x457x203]
RSC182406NK	\$148.00	RSC182406GNK	\$148.00	16/16	24x18x6 [610x457x152]
RSC182408	\$170.00	RSC182408G	\$163.00	14/14	24x18x8 [610x457x203]
RSC202408	\$181.00	RSC202408G	\$174.00	14/14	24x20x8 [610x508x203]
RSC242406NK	\$175.00	RSC242406GNK	\$175.00	14/14	24x24x6 [610x610x152]
RSC242408	\$185.00	RSC242408G	\$177.00	14/14	24x24x8 [610x610x203]
RSC242412	\$244.00	RSC242412G	\$235.00	14/14	24x24x12 [610x610x305]
RSC242416	\$289.00	RSC242416G	\$278.00	14/14	24x24x16 [610x610x406]
RSC243008	\$244.00	RSC243008G	\$235.00	14/14	30x24x8 [762x610x203]
RSC243612	\$310.00	RSC243612G	\$298.00	12/12	36x24x12 [914x610x305]
RSC303012	\$443.00	RSC303012G	\$426.00	12/12	30x30x12 [762x762x305]
RSC303016	\$410.00	RSC303016G	\$394.00	12/12	30x30x16 [762x762x406]
RSC303612	\$460.00	RSC303612G	\$443.00	12/12	36x30x12 [914x762x305]
RSC363612	\$583.00	RSC363612G	\$560.00	12/12	36x36x12 [914x914x305]
RSC363616	\$529.00	RSC363616G	\$509.00	12/12	36x36x16 [914x914x406]
RSC364816	\$737.00	RSC364816G	\$709.00	12/12	48x36x16 [1219x914x406]

**Note:** Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.  
 \* No hasp or meter seal


Enclosure Shipping Schedule	
1 - 7 days	1 - 10 days
Color indicates shipping lead time in business days.	

# RSC Series NEMA 1 and 3R Screw Cover Wall Mount

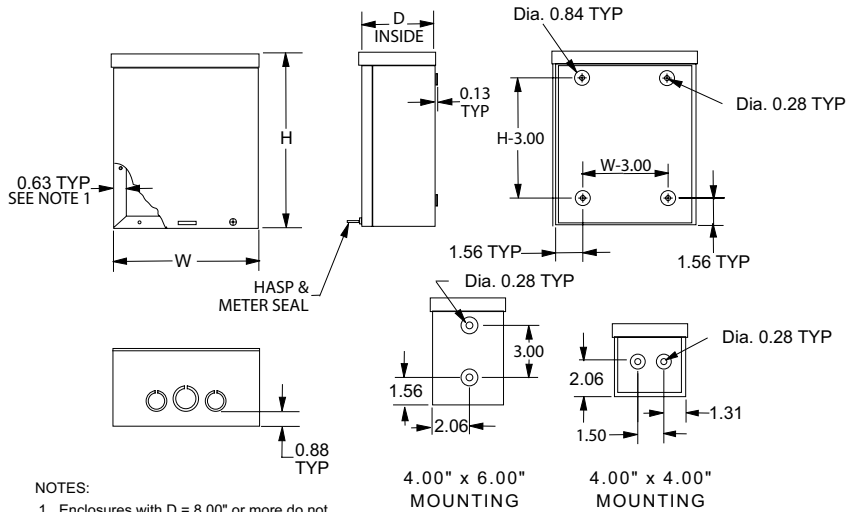

## Knockout Patterns

- A -- 1/2" TO 3/4"
- B -- 3/4" TO 1"
- F -- 1" TO 1-1/4"

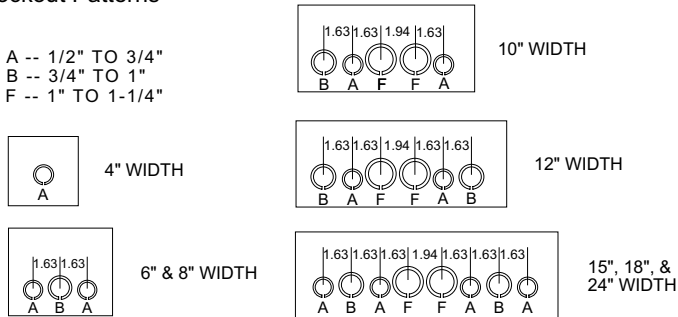

**Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.**

**No partial CSA orders accepted**

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$1.25
Field grounding kit includes necessary parts to properly ground enclosure		

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.