

# NEMA 1 and 3R Screw Cover Wall Mount without Knockouts



## Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

## Construction

- Bodies and doors fabricated from 16, 14, or 12 gauge carbon steel [see table]
- Drip shield top and smooth seamless sides and front
- A slip-on reversible cover is securely fastened with screws located along bottom edge
- No gasketing is required
- Hasp for padlocking or meter seal is provided except as noted

## Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted, pre-galvanized steel

## Listings

- UL 50, Types 1 and 3R [UL file E23553]
- CSA Certified, Type 1 and 3R [CSA file LL66078]
- NEMA/EEMAC Type 1 and 3R



**Note 1:** For removal of cover, move downward, then outward.  
 4x4x4 only has 2 mounting holes centered horizontally.  
 4x6x4 only has 2 mounting holes centered vertically.


**Note 2:** A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

RSC Series NEMA 1 and 3R Screw Cover Wall Mount w/o Knockouts					
ANSI 61 Gray Light-Textured	Price	Galvanized	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
<b>RSC040404NK*</b>	\$17.50	<b>RSC040404GNK*</b>	\$17.50	16/16	4.25 x 4.63 x 4.63 [108 x 118 x 118]
<b>RSC040604NK*</b>	\$17.75	<b>RSC040604GNK*</b>	\$17.75	16/16	6.25 x 4.63 x 4.63 [159 x 118 x 118]
<b>RSC060604NK</b>	\$18.00	<b>RSC060604GNK</b>	\$18.00	16/16	6.25 x 6.63 x 4.63 [159 x 168 x 118]
<b>RSC060606NK</b>	\$23.00	<b>RSC060606GNK</b>	\$23.00	16/16	6.25 x 6.63 x 6.63 [159 x 168 x 168]
<b>RSC060804NK</b>	\$22.00	<b>RSC060804GNK</b>	\$22.00	16/16	8.25 x 6.63 x 4.63 [210 x 168 x 118]
<b>RSC060806NK</b>	\$30.00	<b>RSC060806GNK</b>	\$30.00	16/16	8.25 x 6.63 x 6.63 [210 x 168 x 168]
<b>RSC080804NK</b>	\$25.50	<b>RSC080804GNK</b>	\$25.50	16/16	8.25 x 8.63 x 4.63 [210 x 219 x 118]
<b>RSC080806NK</b>	\$32.50	<b>RSC080806GNK</b>	\$32.50	16/16	8.25 x 8.63 x 6.63 [210 x 219 x 168]
<b>RSC081004NK</b>	\$31.00	<b>RSC081004GNK</b>	\$31.00	16/16	10.25 x 8.63 x 4.63 [260 x 219 x 118]
<b>RSC081006NK</b>	\$41.00	<b>RSC081006GNK</b>	\$41.00	16/16	10.25 x 8.63 x 6.63 [260 x 219 x 168]
<b>RSC081206NK</b>	\$43.50	<b>RSC081206GNK</b>	\$43.50	16/16	12.25 x 8.63 x 6.63 [311 x 219 x 168]
<b>RSC101004NK</b>	\$35.50	<b>RSC101004GNK</b>	\$35.50	16/16	10.25 x 10.63 x 4.63 [260 x 270 x 118]
<b>RSC101006NK</b>	\$44.00	<b>RSC101006GNK</b>	\$44.00	16/16	10.25 x 10.63 x 6.63 [260 x 270 x 168]
<b>RSC101204NK</b>	\$43.50	<b>RSC101204GNK</b>	\$43.50	16/16	12.25 x 10.63 x 4.63 [311 x 270 x 118]
<b>RSC101206NK</b>	\$44.50	<b>RSC101206GNK</b>	\$44.50	16/16	12.25 x 10.63 x 6.63 [311 x 270 x 168]
<b>RSC121204NK</b>	\$44.50	<b>RSC121204GNK</b>	\$44.50	16/16	12.25 x 12.63 x 4.63 [311 x 321 x 118]
<b>RSC121206NK</b>	\$50.00	<b>RSC121206GNK</b>	\$50.00	16/16	12.25 x 12.63 x 6.63 [311 x 321 x 168]
<b>RSC121208</b>	\$64.00	<b>RSC121208G</b>	\$64.00	16/16	12.06 x 12.31 x 8.38 [306 x 313 x 213]
<b>RSC121210</b>	\$70.00	<b>RSC121210G</b>	\$70.00	16/16	12.06 x 12.31 x 10.38 [306 x 313 x 264]
<b>RSC121504NK</b>	\$55.00	<b>RSC121504GNK</b>	\$55.00	16/16	15.25 x 12.63 x 4.63 [387 x 321 x 118]
<b>RSC121506NK</b>	\$64.00	<b>RSC121506GNK</b>	\$64.00	16/16	15.25 x 12.63 x 6.63 [387 x 321 x 168]
<b>RSC121806NK</b>	\$74.00	<b>RSC121806GNK</b>	\$74.00	16/16	18.25 x 12.63 x 6.63 [464 x 321 x 168]
<b>RSC121808</b>	\$88.00	<b>RSC121808G</b>	\$88.00	16/16	18.06 x 12.31 x 8.38 [459 x 313 x 213]
<b>RSC151806NK</b>	\$97.00	<b>RSC151806GNK</b>	\$97.00	16/16	18.25 x 15.63 x 6.63 [464 x 397 x 168]
<b>RSC151808</b>	\$103.00	<b>RSC151808G</b>	\$103.00	16/16	18.06 x 15.31 x 8.38 [459 x 389 x 213]
<b>RSC161610</b>	\$97.00	<b>RSC161610G</b>	\$97.00	16/16	16.06 x 16.31 x 10.38 [408 x 414 x 264]
<b>RSC181804NK</b>	\$101.00	<b>RSC181804GNK</b>	\$101.00	16/16	18.25 x 18.63 x 4.63 [464 x 473 x 118]
<b>RSC181806NK</b>	\$104.00	<b>RSC181806GNK</b>	\$104.00	16/16	18.25 x 18.63 x 6.63 [464 x 473 x 168]
<b>RSC181808</b>	\$132.00	<b>RSC181808G</b>	\$132.00	16/16	18.06 x 18.31 x 8.38 [459 x 465 x 213]
<b>RSC182406NK</b>	\$150.00	<b>RSC182406GNK</b>	\$150.00	16/16	24.25 x 18.63 x 6.63 [616 x 473 x 168]
<b>RSC182408</b>	\$166.00	<b>RSC182408G</b>	\$166.00	14/14	24.07 x 18.34 x 8.38 [611 x 466 x 213]
<b>RSC202408</b>	\$171.00	<b>RSC202408G</b>	\$171.00	14/14	24.07 x 20.34 x 8.38 [611 x 517 x 213]
<b>RSC242406NK</b>	\$175.00	<b>RSC242406GNK</b>	\$175.00	14/14	24.25 x 24.63 x 6.63 [616 x 610 x 168]
<b>RSC242408</b>	\$176.00	<b>RSC242408G</b>	\$176.00	14/14	24.07 x 24.34 x 8.38 [611 x 618 x 213]
<b>RSC242412</b>	\$221.00	<b>RSC242412G</b>	\$221.00	14/14	24.07 x 24.34 x 12.38 [611 x 618 x 314]
<b>RSC242416</b>	\$282.00	<b>RSC242416G</b>	\$282.00	14/14	24.07 x 24.34 x 16.38 [611 x 618 x 416]
<b>RSC243008</b>	\$238.00	<b>RSC243008G</b>	\$238.00	14/14	30.07 x 24.34 x 8.38 [764 x 618 x 213]
<b>RSC243612</b>	\$296.00	<b>RSC243612G</b>	\$296.00	12/12	36.09 x 24.37 x 12.38 [917 x 619 x 314]
<b>RSC303012</b>	\$386.00	<b>RSC303012G</b>	\$386.00	12/12	30.09 x 30.37 x 12.38 [764 x 771 x 314]
<b>RSC303016</b>	\$392.00	<b>RSC303016G</b>	\$392.00	12/12	30.09 x 30.37 x 16.38 [764 x 771 x 416]
<b>RSC303612</b>	\$423.00	<b>RSC303612G</b>	\$423.00	12/12	36.09 x 30.37 x 12.38 [917 x 771 x 314]
<b>RSC363612</b>	\$502.00	<b>RSC363612G</b>	\$502.00	12/12	36.09 x 36.37 x 12.38 [917 x 924 x 314]
<b>RSC363616</b>	\$505.00	<b>RSC363616G</b>	\$505.00	12/12	36.09 x 36.37 x 16.38 [917 x 924 x 416]
<b>RSC364816</b>	\$720.00	<b>RSC364816G</b>	\$720.00	12/12	48.09 x 36.17 x 16.38 [1221 x 919 x 416]

**Note:** Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.  
 \*No hasp or meter seal


Enclosure Shipping Schedule		
1 - 7 days	1 - 10 days	1 - 15 days
Color indicates shipping lead time in business days.		

# NEMA 1 and 3R Screw Cover Wall Mount

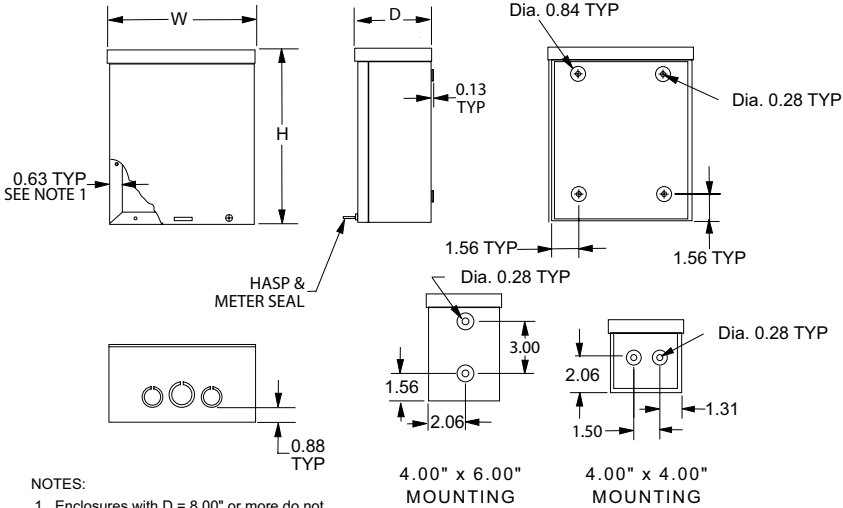

**Knockout Patterns**

- A -- 1/2" TO 3/4"
- B -- 3/4" TO 1"
- F -- 1" TO 1-1/4"

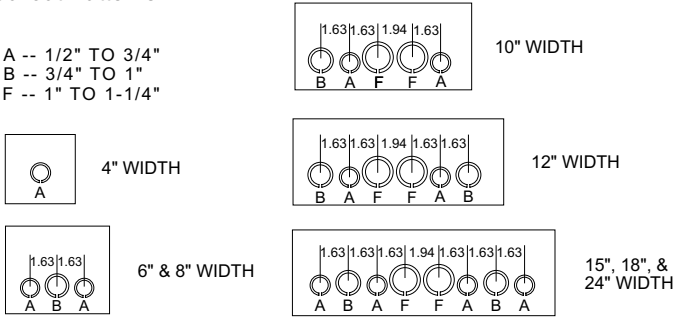

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$1.25
Note: Field grounding kit includes necessary parts to properly ground enclosure		