

NEMA 1 and 3R Screw Cover Wall Mount without Knockouts



Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

Construction

- Bodies and doors fabricated from 16, 14, or 12 gauge carbon steel [see table]
- Drip shield top and smooth seamless sides and front
- A slip-on reversible cover is securely fastened with screws located along bottom edge
- No gasketing is required
- Hasp for padlocking or meter seal is provided except as noted

Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted, pre-galvanized steel

Listings

- UL 50, Types 1 and 3R [UL file E23553]
- CSA Certified, Type 1 and 3R [CSA file LL66078]
- NEMA/EEMAC Type 1 and 3R



Note 1: For removal of cover, move downward, then outward.
 4x4x4 only has 2 mounting holes centered horizontally.
 4x6x4 only has 2 mounting holes centered vertically.

Note 2: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.


RSC Series NEMA 1 and 3R Screw Cover Wall Mount w/o Knockouts					
ANSI 61 Gray Light-Textured	Price	Galvanized	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
RSC040404NK*	\$18.00	RSC040404GNK*	\$18.00	16/16	4.25 x 4.63 x 4.63 [108 x 118 x 118]
RSC040604NK*	\$18.00	RSC040604GNK*	\$18.00	16/16	6.25 x 4.63 x 4.63 [159 x 118 x 118]
RSC060604NK	\$18.50	RSC060604GNK	\$18.50	16/16	6.25 x 6.63 x 4.63 [159 x 168 x 118]
RSC060606NK	\$23.50	RSC060606GNK	\$23.50	16/16	6.25 x 6.63 x 6.63 [159 x 168 x 168]
RSC060804NK	\$22.50	RSC060804GNK	\$22.50	16/16	8.25 x 6.63 x 4.63 [210 x 168 x 118]
RSC060806NK	\$30.00	RSC060806GNK	\$30.00	16/16	8.25 x 6.63 x 6.63 [210 x 168 x 168]
RSC080804NK	\$25.50	RSC080804GNK	\$25.50	16/16	8.25 x 8.63 x 4.63 [210 x 219 x 118]
RSC080806NK	\$34.00	RSC080806GNK	\$34.00	16/16	8.25 x 8.63 x 6.63 [210 x 219 x 168]
RSC081004NK	\$31.50	RSC081004GNK	\$31.50	16/16	10.25 x 8.63 x 4.63 [260 x 219 x 118]
RSC081006NK	\$41.50	RSC081006GNK	\$41.50	16/16	10.25 x 8.63 x 6.63 [260 x 219 x 168]
RSC081206NK	\$44.00	RSC081206GNK	\$44.00	16/16	12.25 x 8.63 x 6.63 [311 x 219 x 168]
RSC101004NK	\$36.00	RSC101004GNK	\$36.00	16/16	10.25 x 10.63 x 4.63 [260 x 270 x 118]
RSC101006NK	\$44.50	RSC101006GNK	\$44.50	16/16	10.25 x 10.63 x 6.63 [260 x 270 x 168]
RSC101204NK	\$44.00	RSC101204GNK	\$44.00	16/16	12.25 x 10.63 x 4.63 [311 x 270 x 118]
RSC101206NK	\$45.00	RSC101206GNK	\$45.00	16/16	12.25 x 10.63 x 6.63 [311 x 270 x 168]
RSC121204NK	\$45.00	RSC121204GNK	\$45.00	16/16	12.25 x 12.63 x 4.63 [311 x 321 x 118]
RSC121206NK	\$50.00	RSC121206GNK	\$50.00	16/16	12.25 x 12.63 x 6.63 [311 x 321 x 168]
RSC121208	\$65.00	RSC121208G	\$65.00	16/16	12.06 x 12.31 x 8.38 [306 x 313 x 213]
RSC121210	\$71.00	RSC121210G	\$71.00	16/16	12.06 x 12.31 x 10.38 [306 x 313 x 264]
RSC121504NK	\$55.00	RSC121504GNK	\$55.00	16/16	15.25 x 12.63 x 4.63 [387 x 321 x 118]
RSC121506NK	\$65.00	RSC121506GNK	\$65.00	16/16	15.25 x 12.63 x 6.63 [387 x 321 x 168]
RSC121806NK	\$75.00	RSC121806GNK	\$75.00	16/16	18.25 x 12.63 x 6.63 [464 x 321 x 168]
RSC121808	\$89.00	RSC121808G	\$89.00	16/16	18.06 x 12.31 x 8.38 [459 x 313 x 213]
RSC151806NK	\$98.00	RSC151806GNK	\$98.00	16/16	18.25 x 15.63 x 6.63 [464 x 397 x 168]
RSC151808	\$105.00	RSC151808G	\$105.00	16/16	18.06 x 15.31 x 8.38 [459 x 389 x 213]
RSC161610	\$98.00	RSC161610G	\$98.00	16/16	16.06 x 16.31 x 10.38 [408 x 414 x 264]
RSC181804NK	\$103.00	RSC181804GNK	\$103.00	16/16	18.25 x 18.63 x 4.63 [464 x 473 x 118]
RSC181806NK	\$106.00	RSC181806GNK	\$106.00	16/16	18.25 x 18.63 x 6.63 [464 x 473 x 168]
RSC181808	\$134.00	RSC181808G	\$134.00	16/16	18.06 x 18.31 x 8.38 [459 x 465 x 213]
RSC182406NK	\$152.00	RSC182406GNK	\$152.00	16/16	24.25 x 18.63 x 6.63 [616 x 473 x 168]
RSC182408	\$168.00	RSC182408G	\$168.00	14/14	24.07 x 18.34 x 8.38 [611 x 466 x 213]
RSC202408	\$173.00	RSC202408G	\$173.00	14/14	24.07 x 20.34 x 8.38 [611 x 517 x 213]
RSC242406NK	\$177.00	RSC242406GNK	\$177.00	14/14	24.25 x 24.63 x 6.63 [616 x 610 x 168]
RSC242408	\$178.00	RSC242408G	\$178.00	14/14	24.07 x 24.34 x 8.38 [611 x 618 x 213]
RSC242412	\$225.00	RSC242412G	\$225.00	14/14	24.07 x 24.34 x 12.38 [611 x 618 x 314]
RSC242416	\$286.00	RSC242416G	\$286.00	14/14	24.07 x 24.34 x 16.38 [611 x 618 x 416]
RSC243008	\$242.00	RSC243008G	\$242.00	14/14	30.07 x 24.34 x 8.38 [764 x 618 x 213]
RSC243612	\$300.00	RSC243612G	\$300.00	12/12	36.09 x 24.37 x 12.38 [917 x 619 x 314]
RSC303012	\$392.00	RSC303012G	\$392.00	12/12	30.09 x 30.37 x 12.38 [764 x 771 x 314]
RSC303016	\$398.00	RSC303016G	\$398.00	12/12	30.09 x 30.37 x 16.38 [764 x 771 x 416]
RSC303612	\$430.00	RSC303612G	\$430.00	12/12	36.09 x 30.37 x 12.38 [917 x 771 x 314]
RSC363612	\$510.00	RSC363612G	\$510.00	12/12	36.09 x 36.37 x 12.38 [917 x 924 x 314]
RSC363616	\$513.00	RSC363616G	\$513.00	12/12	36.09 x 36.37 x 16.38 [917 x 924 x 416]
RSC364816	\$731.00	RSC364816G	\$731.00	12/12	48.09 x 36.17 x 16.38 [1221 x 919 x 416]

Note: Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.
 *No hasp or meter seal

Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days


Color indicates shipping lead time in business days.

NEMA 1 and 3R Screw Cover Wall Mount

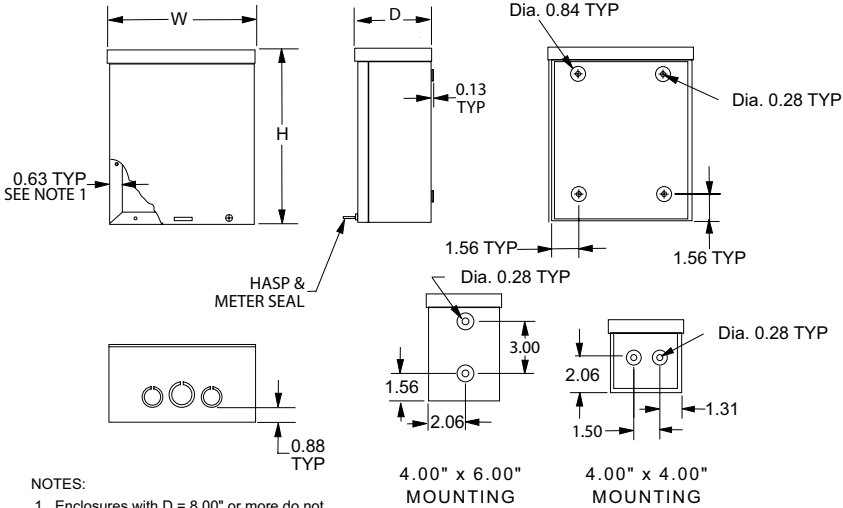

Knockout Patterns

- A -- 1/2" TO 3/4"
- B -- 3/4" TO 1"
- F -- 1" TO 1-1/4"

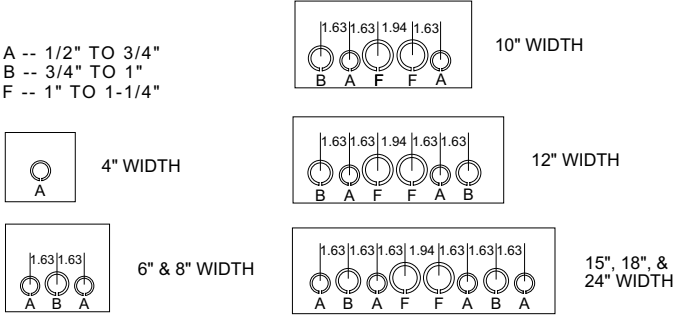

See our website: www.AutomationDirect.com for complete engineering drawings.

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$1.25
Note: Field grounding kit includes necessary parts to properly ground enclosure		