

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount without Knockouts



Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1-10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.					

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount without Knockouts

ANSI 61 Gray Light-Textured	Price	Galvanized	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
RSC040404NK*	\$24.00	RSC040404GNK*	\$24.00	16/16	4.25 x 4.63 x 4.63 [108 x 118 x 118]
RSC040604NK*	\$28.50	RSC040604GNK*	\$28.50	16/16	6.25 x 4.63 x 4.63 [159 x 118 x 118]
RSC060604NK	\$30.50	RSC060604GNK	\$30.50	16/16	6.25 x 6.63 x 4.63 [159 x 168 x 118]
RSC060606NK	\$32.00	RSC060606GNK	\$32.00	16/16	6.25 x 6.63 x 6.63 [159 x 168 x 168]
RSC060804NK	\$35.00	RSC060804GNK	\$35.00	16/16	8.25 x 6.63 x 4.63 [210 x 168 x 118]
RSC060806NK	\$40.50	RSC060806GNK	\$40.50	16/16	8.25 x 6.63 x 6.63 [210 x 168 x 168]
RSC080804NK	\$40.00	RSC080804GNK	\$40.00	16/16	8.25 x 8.63 x 4.63 [210 x 219 x 118]
RSC080806NK	\$47.00	RSC080806GNK	\$47.00	16/16	8.25 x 8.63 x 6.63 [210 x 219 x 168]
RSC081004NK	\$45.50	RSC081004GNK	\$45.50	16/16	10.25 x 8.63 x 4.63 [260 x 219 x 118]
RSC081006NK	\$53.00	RSC081006GNK	\$53.00	16/16	10.25 x 8.63 x 6.63 [260 x 219 x 168]
RSC081206NK	\$59.00	RSC081206GNK	\$59.00	16/16	12.25 x 8.63 x 6.63 [311 x 219 x 168]
RSC101004NK	\$51.00	RSC101004GNK	\$51.00	16/16	10.25 x 10.63 x 4.63 [260 x 270 x 118]
RSC101006NK	\$60.00	RSC101006GNK	\$60.00	16/16	10.25 x 10.63 x 6.63 [260 x 270 x 168]
RSC101204NK	\$58.00	RSC101204GNK	\$58.00	16/16	12.25 x 10.63 x 4.63 [311 x 270 x 118]
RSC101206NK	\$67.00	RSC101206GNK	\$67.00	16/16	12.25 x 10.63 x 6.63 [311 x 270 x 168]
RSC121204NK	\$65.00	RSC121204GNK	\$65.00	16/16	12.25 x 12.63 x 4.63 [311 x 321 x 118]
RSC121206NK	\$75.00	RSC121206GNK	\$75.00	16/16	12.25 x 12.63 x 6.63 [311 x 321 x 168]
RSC121208	\$91.00	RSC121208G	\$91.00	16/16	12.06 x 12.31 x 8.38 [306 x 313 x 213]
RSC121210	\$95.00	RSC121210G	\$95.00	16/16	12.06 x 12.31 x 10.38 [306 x 313 x 264]
RSC121504NK	\$74.00	RSC121504GNK	\$74.00	16/16	15.25 x 12.63 x 4.63 [387 x 321 x 118]
RSC121506NK	\$86.00	RSC121506GNK	\$86.00	16/16	15.25 x 12.63 x 6.63 [387 x 321 x 168]
RSC121806NK	\$107.00	RSC121806GNK	\$107.00	16/16	18.25 x 12.63 x 6.63 [464 x 321 x 168]
RSC121808	\$112.00	RSC121808G	\$112.00	16/16	18.06 x 12.31 x 8.38 [459 x 313 x 213]
RSC151806NK	\$126.00	RSC151806GNK	\$126.00	16/16	18.25 x 15.63 x 6.63 [464 x 397 x 168]
RSC151808	\$136.00	RSC151808G	\$136.00	16/16	18.06 x 15.31 x 8.38 [459 x 389 x 213]
RSC161610	\$126.00	RSC161610G	\$126.00	16/16	16.06 x 16.31 x 10.38 [408 x 414 x 264]
RSC181804NK	\$132.00	RSC181804GNK	\$132.00	16/16	18.25 x 18.63 x 4.63 [464 x 473 x 118]
RSC181806NK	\$151.00	RSC181806GNK	\$151.00	16/16	18.25 x 18.63 x 6.63 [464 x 473 x 168]
RSC181808	\$169.00	RSC181808G	\$169.00	16/16	18.06 x 18.31 x 8.38 [459 x 465 x 213]
RSC182406NK	\$191.00	RSC182406GNK	\$191.00	16/16	24.25 x 18.63 x 6.63 [616 x 473 x 168]
RSC182408	\$211.00	RSC182408G	\$211.00	14/14	24.07 x 18.34 x 8.38 [611 x 466 x 213]
RSC202408	\$225.00	RSC202408G	\$225.00	14/14	24.07 x 20.34 x 8.38 [611 x 517 x 213]
RSC242406NK	\$227.00	RSC242406GNK	\$227.00	14/14	24.25 x 24.62 x 6.63 [616 x 625 x 168]
RSC242408	\$256.00	RSC242408G	\$256.00	14/14	24.07 x 24.34 x 8.38 [611 x 618 x 213]
RSC242412	\$303.00	RSC242412G	\$303.00	14/14	24.07 x 24.34 x 12.38 [611 x 618 x 314]
RSC242416	\$360.00	RSC242416G	\$360.00	14/14	24.07 x 24.34 x 16.38 [611 x 618 x 416]
RSC243008	\$303.00	RSC243008G	\$303.00	14/14	30.07 x 24.34 x 8.38 [764 x 618 x 213]
RSC243612	\$385.00	RSC243612G	\$385.00	12/12	36.09 x 24.37 x 12.38 [917 x 619 x 314]
RSC303012	\$551.00	RSC303012G	\$551.00	12/12	30.09 x 30.37 x 12.38 [764 x 771 x 314]
RSC303016	\$568.00	RSC303016G	\$568.00	12/12	30.09 x 30.37 x 16.38 [764 x 771 x 416]
RSC303612	\$572.00	RSC303612G	\$572.00	12/12	36.09 x 30.37 x 12.38 [917 x 771 x 314]
RSC363612	\$724.00	RSC363612G	\$724.00	12/12	36.09 x 36.37 x 12.38 [917 x 924 x 314]
RSC363616	\$733.00	RSC363616G	\$733.00	12/12	36.09 x 36.37 x 16.38 [917 x 924 x 416]
RSC364816	\$916.00	RSC364816G	\$916.00	12/12	48.09 x 36.37 x 16.38 [1221 x 924 x 416]



Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

Construction

- Bodies and doors fabricated from 12-, 14-, or 16-gauge carbon steel (see table)
- Drip shield top and smooth seamless sides and front
- Slip-on reversible cover securely fastened with screws located along bottom edge
- No gasket required
- Hasp for padlocking or meter seal is provided except as noted

Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted, pre-galvanized steel

Listings

- UL 50, Types 1 and 3R [UL file E23553]
- NEMA/EEMAC 1 and 3R




Note: To remove cover, move down, then out. 4x 4 in [102 x 102 x 102 mm] only has 2 mounting holes centered horizontally. 4x 6 x 4 in [102 x 152 x 102 mm] only has 2 mounting holes centered vertically.

Notes: Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.
*No hasp or meter seal

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount



Dimensions

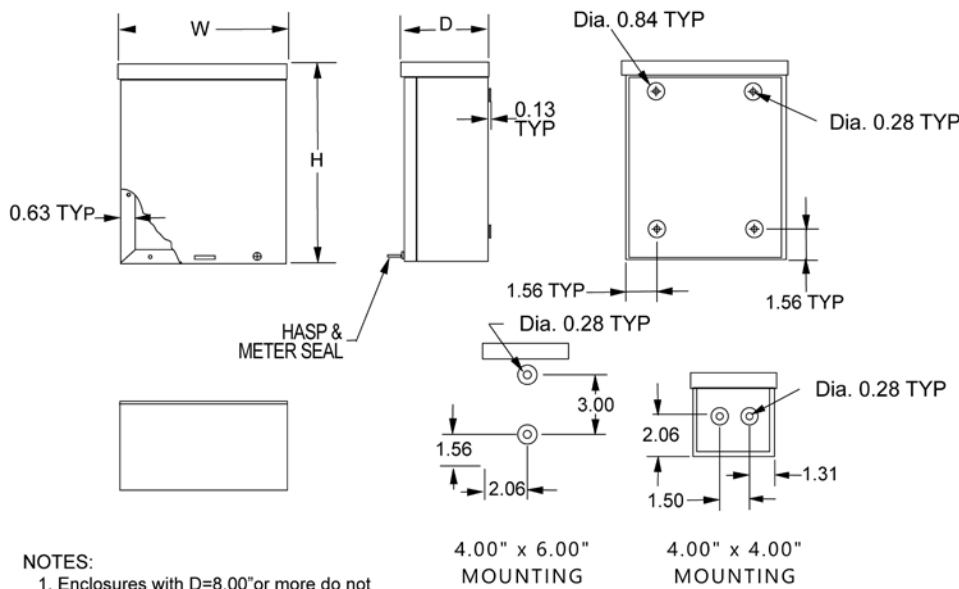

NOTES:
 1. Enclosures with D=8.00" or more do not have an internal flange.

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$3.25
Note: Field grounding kit includes necessary parts to properly ground enclosure.		

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.