

NEMA 1 and 3R Screw Cover Wall-Mount without Knockouts



Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.



Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

Construction

- Bodies and doors fabricated from 16, 14, or 12 gauge carbon steel [see table]
- Drip shield top and smooth seamless sides and front
- A slip-on reversible cover is securely fastened with screws located along bottom edge
- No gasketing is required
- Hasp for padlocking or meter seal is provided except as noted

Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted, pre-galvanized steel

Listings

- UL 50, Types 1 and 3R [UL file E23553]
- NEMA/EEMAC Type 1 and 3R



Note: For removal of cover, move downward, then outward. 4x4x4 only has 2 mounting holes centered horizontally. 4x6x4 only has 2 mounting holes centered vertically.

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount w/o Knockouts


ANSI 61 Gray Light-Textured	Price	Galvanized	Price	Body/Door Steel Gauge	Enclosure Size HxWxD
RSC040404NK*	\$21.00	RSC040404GNK*	\$21.00	16/16	4.25 x 4.63 x 4.63 [108 x 118 x 118]
RSC040604NK*	\$25.00	RSC040604GNK*	\$25.00	16/16	6.25 x 4.63 x 4.63 [159 x 118 x 118]
RSC060604NK	\$26.50	RSC060604GNK	\$26.50	16/16	6.25 x 6.63 x 4.63 [159 x 168 x 118]
RSC060606NK	\$28.00	RSC060606GNK	\$28.00	16/16	6.25 x 6.63 x 6.63 [159 x 168 x 168]
RSC060804NK	\$30.50	RSC060804GNK	\$30.50	16/16	8.25 x 6.63 x 4.63 [210 x 168 x 118]
RSC060806NK	\$35.50	RSC060806GNK	\$35.50	16/16	8.25 x 6.63 x 6.63 [210 x 168 x 168]
RSC080804NK	\$35.00	RSC080804GNK	\$35.00	16/16	8.25 x 8.63 x 4.63 [210 x 219 x 118]
RSC080806NK	\$41.50	RSC080806GNK	\$41.50	16/16	8.25 x 8.63 x 6.63 [210 x 219 x 168]
RSC081004NK	\$40.00	RSC081004GNK	\$40.00	16/16	10.25 x 8.63 x 4.63 [260 x 219 x 118]
RSC081006NK	\$47.00	RSC081006GNK	\$47.00	16/16	10.25 x 8.63 x 6.63 [260 x 219 x 168]
RSC081206NK	\$52.00	RSC081206GNK	\$52.00	16/16	12.25 x 8.63 x 6.63 [311 x 219 x 168]
RSC101004NK	\$45.00	RSC101004GNK	\$45.00	16/16	10.25 x 10.63 x 4.63 [260 x 270 x 118]
RSC101006NK	\$53.00	RSC101006GNK	\$53.00	16/16	10.25 x 10.63 x 6.63 [260 x 270 x 168]
RSC101204NK	\$51.00	RSC101204GNK	\$51.00	16/16	12.25 x 10.63 x 4.63 [311 x 270 x 118]
RSC101206NK	\$59.00	RSC101206GNK	\$59.00	16/16	12.25 x 10.63 x 6.63 [311 x 270 x 168]
RSC121204NK	\$57.00	RSC121204GNK	\$57.00	16/16	12.25 x 12.63 x 4.63 [311 x 321 x 118]
RSC121206NK	\$66.00	RSC121206GNK	\$66.00	16/16	12.25 x 12.63 x 6.63 [311 x 321 x 168]
RSC121208	\$76.00	RSC121208G	\$76.00	16/16	12.06 x 12.31 x 8.38 [306 x 313 x 213]
RSC121210	\$84.00	RSC121210G	\$84.00	16/16	12.06 x 12.31 x 10.38 [306 x 313 x 264]
RSC121504NK	\$65.00	RSC121504GNK	\$65.00	16/16	15.25 x 12.63 x 4.63 [387 x 321 x 118]
RSC121506NK	\$76.00	RSC121506GNK	\$76.00	16/16	15.25 x 12.63 x 6.63 [387 x 321 x 168]
RSC121806NK	\$94.00	RSC121806GNK	\$94.00	16/16	18.25 x 12.63 x 6.63 [464 x 321 x 168]
RSC121808	\$99.00	RSC121808G	\$98.00	16/16	18.06 x 12.31 x 8.38 [459 x 313 x 213]
RSC151806NK	\$111.00	RSC151806GNK	\$111.00	16/16	18.25 x 15.63 x 6.63 [464 x 397 x 168]
RSC151808	\$120.00	RSC151808G	\$119.00	16/16	18.06 x 15.31 x 8.38 [459 x 389 x 213]
RSC161610	\$111.00	RSC161610G	\$111.00	16/16	16.06 x 16.31 x 10.38 [408 x 414 x 264]
RSC181804NK	\$116.00	RSC181804GNK	\$116.00	16/16	18.25 x 18.63 x 4.63 [464 x 473 x 118]
RSC181806NK	\$133.00	RSC181806GNK	\$133.00	16/16	18.25 x 18.63 x 6.63 [464 x 473 x 168]
RSC181808	\$148.00	RSC181808G	\$143.00	16/16	18.06 x 18.31 x 8.38 [459 x 465 x 213]
RSC182406NK	\$168.00	RSC182406GNK	\$168.00	16/16	24.25 x 18.63 x 6.63 [616 x 473 x 168]
RSC182408	\$185.00	RSC182408G	\$180.00	14/14	24.07 x 18.34 x 8.38 [611 x 466 x 213]
RSC202408	\$198.00	RSC202408G	\$190.00	14/14	24.07 x 20.34 x 8.38 [611 x 517 x 213]
RSC242406NK	\$199.00	RSC242406GNK	\$199.00	14/14	24.25 x 24.63 x 6.63 [616 x 610 x 168]
RSC242408	\$225.00	RSC242408G	\$224.00	14/14	24.07 x 24.34 x 8.38 [611 x 618 x 213]
RSC242412	\$266.00	RSC242412G	\$266.00	14/14	24.07 x 24.34 x 12.38 [611 x 618 x 314]
RSC242416	\$316.00	RSC242416G	\$304.00	14/14	24.07 x 24.34 x 16.38 [611 x 618 x 416]
RSC243008	\$266.00	RSC243008G	\$266.00	14/14	30.07 x 24.34 x 8.38 [764 x 618 x 213]
RSC243612	\$339.00	RSC243612G	\$338.00	12/12	36.09 x 24.37 x 12.38 [917 x 619 x 314]
RSC303012	\$484.00	RSC303012G	\$351.00	12/12	30.09 x 30.37 x 12.38 [764 x 771 x 314]
RSC303016	\$499.00	RSC303016G	\$499.00	12/12	30.09 x 30.37 x 16.38 [764 x 771 x 416]
RSC303612	\$503.00	RSC303612G	\$484.00	12/12	36.09 x 30.37 x 12.38 [917 x 771 x 314]
RSC363612	\$636.00	RSC363612G	\$613.00	12/12	36.09 x 36.37 x 12.38 [917 x 924 x 314]
RSC363616	\$644.00	RSC363616G	\$644.00	12/12	36.09 x 36.37 x 16.38 [917 x 924 x 416]
RSC364816	\$805.00	RSC364816G	\$805.00	12/12	48.09 x 36.17 x 16.38 [1221 x 919 x 416]

Notes: Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.
*No hasp or meter seal

NEMA 1 and 3R Screw Cover Wall-Mount without Knockouts



Dimensions

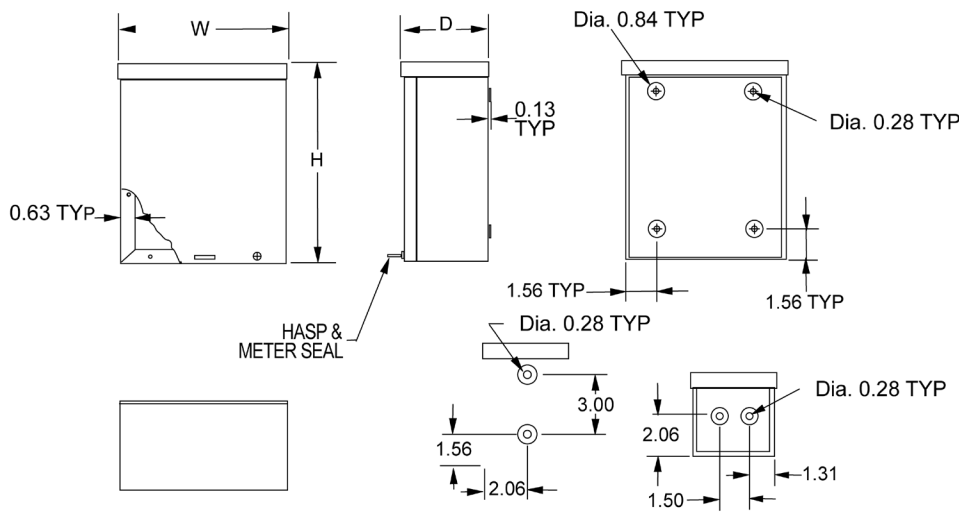

NOTES:

- 1. Enclosures with D=8.00" or more do not have an internal flange.

4.00" x 6.00" MOUNTING 4.00" x 4.00" MOUNTING

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$2.75
Note: Field grounding kit includes necessary parts to properly ground enclosure		

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.