

# Enclosure Accessories



Your Enclosure Source®

## Deep-Hinged Doors



SCE-HA1010LG

Designed to house electrical controls, instruments and components used in an indoor or outdoor environment to provide a degree of protection for the equipment inside the enclosure against ingress of solid foreign objects (falling dirt); and provide a degree of protection with respect to the harmful effects on the equipment due to the ingress of water (rain, sleet, snow). ELJ hinges. Black mini 1/4-turn latches. Gasket and hardware included.

### Listings

- Carbon Steel:
  - NEMA Type 3R, 4, 12 & 13
  - UL Listed Type 3R, 4 & 12 [File E69392]
- Stainless Steel:
  - NEMA Type 3R, 4, 4X, 12 & 13
  - UL Listed Type 3R, 4, 4X, 12 & 13 [File E69392]

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Deep-Hinged Doors							
RAL7035	ANSI 61	White	Price	304 Stainless Steel	Price	Size HxWxD	Drawing Link
SCE-HA1010LG	SCE-HA1010	SCE-HA1010-05	\$223.00	SCE-HA1010SS	\$509.00	10.00 x 10.00 x 2.63 [254 x 254 x 67]	<a href="#">PDF</a>
SCE-HA1212LG	SCE-HA1212	SCE-HA1212-05	\$242.00	SCE-HA1212SS	\$532.00	12.00 x 12.00 x 2.63 [305 x 305 x 67]	<a href="#">PDF</a>
SCE-HA1814LG	SCE-HA1814	—	\$286.00	SCE-HA1814SS	\$729.00	18.00 x 14.00 x 2.63 [457 x 356 x 67]	<a href="#">PDF</a>


*Note: Dimensions in inches [millimeters].*

# Enclosure Accessories



Your Enclosure Source®

## Deep-Hinged Doors

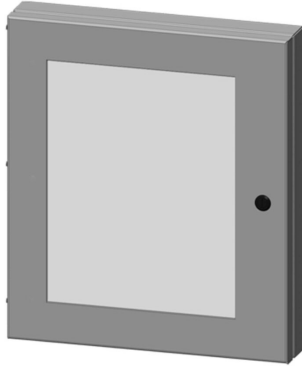

SCE-HWK1212

Designed to mount on the exterior of an enclosure to provide protection for controls with easy access. ELJ hinges. Black mini 1/4-turn latches. UV stable Polycarbonate viewing window. Gasket and hardware included. Made of heavy gauge carbon steel and powder coated.

“SS” parts made of heavy gauge stainless steel Type 304 with #4 brushed finish. Recommend use as Type 3R rating in full outdoor exposure and extreme weather environments – the addition of ventilation is necessary to handle the large negative pressure differential caused in a tightly sealed enclosure in extreme weather conditions. Temperatures that may exceed 140°F, such as outdoor in direct sunlight should be evaluated, shading or sun shield may be necessary.

### Listings

- NEMA Type 3R, 12, & 13
- UL Recognized Type 3R & 12

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Deep-Hinged Doors with Windows								
ANSI 61	RAL 7035	Price	304 Stainless Steel	Price	Overall Size HxWxD	Window Size HxW	Maximum Cut-Out Size HxW	Drawing Link
SCE-HWK1212	SCE-HWK1212LG	\$279.00	SCE-HWK1212SS	\$576.00	12.00 x 12.00 x 2.63 [305 x 305 x 67]	8.00 x 7.38 [203 x 187]	9.50 x 9.50 [241 x 241]	<a href="#">PDF</a>
SCE-HWK1312	—	\$292.00	—	—	13.00 x 12.00 x 2.63 [330 x 305 x 67]	8.00 x 7.38 [203 x 187]	10.50 x 9.50 [267 x 241]	<a href="#">PDF</a>
SCE-HWK1814	SCE-HWK1814LG	\$324.00	SCE-HWK1814SS	\$781.00	18.00 x 14.00 x 2.63 [457 x 356 x 67]	14.00 x 7.38 [356 x 187]	15.50 x 11.50 [394 x 292]	<a href="#">PDF</a>
SCE-HWK2218	SCE-HWK2218LG	\$390.00	SCE-HWK2218SS	\$942.00	22.00 x 18.00 x 2.63 [559 x 457 x 67]	18.00 x 13.38 [457 x 340]	19.50 x 15.50 [495 x 394]	<a href="#">PDF</a>
SCE-HWK2228	SCE-HWK2228LG	\$446.00	SCE-HWK2228SS	\$1,165.00	22.00 x 28.00 x 2.63 [559 x 711 x 67]	(2) 18.00 x 10.56 [457 x 268]	19.50 x 25.50 [495 x 648]	<a href="#">PDF</a>
SCE-HWK2822	SCE-HWK2822LG	\$446.00	SCE-HWK2822SS	\$1,165.00	28.00 x 22.00 x 2.63 [711 x 559 x 67]	(2) 10.88 x 17.38 [276 x 441]	25.50 x 19.50 [648 x 495]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# Enclosure Accessories



Your Enclosure Source®

## Hinges and Hinge Pins

Standard replacement hinges for standard Saginaw enclosures. Includes hinge, pin, and clip.

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Replacement Hinges					
Carbon Steel	Price	304 Stainless Steel	Price	Description	Qty
<b>SCE-3916</b>	\$10.50	<b>SCE-3916SS</b>	\$22.00	large concealed hinge	1
<b>SCE-3918</b>	\$17.00	<b>SCE-3918SS</b>	\$41.00	small concealed hinge	1
<b>SCE-ELJHINGE</b>	\$5.75	—	—	ELJ hinge	1
<b>SCE-101670</b>	\$10.75	—	—	retaining clip for concealed hinge	1
<b>SCE-101221</b>	\$27.50	—	—	large hinge pin	20
<b>SCE-101226</b>	\$52.00	—	—	small hinge pin	20



**SCE-3916**



**SCE-ELJHINGE**



**SCE-101670**




**SCE-101221**

# Enclosure Accessories



Your Enclosure Source®

## Enclosure Windows

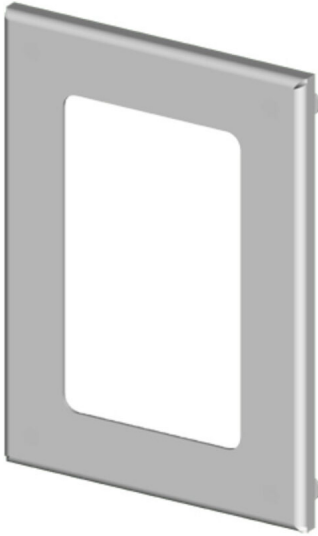

**SCE-PWK53NF**

Designed for use on most SCE Type 4, 4X and 12 enclosures. Includes frame, window, oil-resistant gasket, and mounting hardware. Installed by making a cutout in the enclosure and fastening the window and frame in place.

The window is 0.25" UV stable polycarbonate material. Made of heavy gauge steel and powder coated ANSI 61 gray. "SS" kits are made of Type 304 stainless with #4 brushed finish. Recommend use as Type 3R rating in full outdoor exposure and extreme weather environments.

### Listings

- NEMA Type 1, 3R, 4, 4X & 12
- UL Recognized Type 1, 3R & 12

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

UV-Resistant Window Kits					
Carbon Steel	Price	304 Stainless Steel	Price	Window Size HxW	Drawing Link
<b>SCE-PWK53NF</b>	\$102.00	<b>SCE-PWK53NFSS</b>	\$153.00	5.25 x 3.25 [133 x 83]	<a href="#">PDF</a>
<b>SCE-PWK63NF</b>	\$112.00	—	—	6.55 x 2.85 [166 x 72]	<a href="#">PDF</a>
<b>SCE-PWK95NF</b>	\$122.00	<b>SCE-PWK95NFSS</b>	\$184.00	9.25 x 5.75 [235 x 146]	<a href="#">PDF</a>
<b>SCE-PWK138NF</b>	\$155.00	<b>SCE-PWK138NFSS</b>	\$234.00	13.25 x 8.25 [337 x 210]	<a href="#">PDF</a>
<b>SCE-PWK1711NF</b>	\$214.00	<b>SCE-PWK1711NFSS</b>	\$308.00	17.25 x 11.25 [438 x 286]	<a href="#">PDF</a>
<b>SCE-PWK2315NF</b>	\$263.00	<b>SCE-PWK2315NFSS</b>	\$398.00	23.25 x 15.25 [591 x 387]	<a href="#">PDF</a>
<b>SCE-PWK2919NF</b>	\$391.00	<b>SCE-PWK2919NFSS</b>	\$590.00	29.25 x 19.25 [743 x 489]	<a href="#">PDF</a>

*Note: Dimensions in inches [millimeters].*

# Enclosure Accessories



Your Enclosure Source®

## Enclosure Windows

Designed for use on most SCE Type 4, 4X and 12 enclosures. Includes frame, window, oil-resistant gasket, and mounting hardware. Installed by making a cutout in the enclosure and fastening the window and frame in place. For technical information, consult our Installation Manual. The window is made of laminated safety glass for easier clean up and an aluminum extruded frame. Recommend use as Type 3R rating in full outdoor exposure and extreme weather environments.

For more details see Design Considerations When Specifying Your Enclosure on our website.



**SCE-AW1208SG**

### Listings

- NEMA Type 1, 3R, 4, 4X & 12
- UL Recognized Type 1, 3R & 12

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Extruded Aluminum Safety Glass UV-Resistant Windows			
Part Number	Price	Window Size HxW	Drawing Link
<b>SCE-AW1208SG</b>	\$279.00	12.00 x 8.00 [305 x 203]	<a href="#">PDF</a>
<b>SCE-AW1812SG</b>	\$357.00	18.00 x 12.00 [457 x 305]	<a href="#">PDF</a>
<b>SCE-AW2016SG</b>	\$425.00	20.00 x 16.00 [508 x 406]	<a href="#">PDF</a>
<b>SCE-AW2620SG</b>	\$520.00	26.00 x 20.00 [660 x 508]	<a href="#">PDF</a>
<b>SCE-AW6020SG</b>	\$854.00	60.00 x 20.00 [1524 x 508]	<a href="#">PDF</a>
<i>Note: Dimensions in inches [millimeters].</i>			