

# NEMA 4, 4X, 12, and 13 Extra-Large Stainless Steel Wall-Mount Pushbutton



## Finish

- #4 brushed finish on all exterior surfaces.
- Optional subpanels powder coated white.

## Listings

- NEMA Type 4, 4X, 12, and 13
- cULus Listed Type 4, 4X, and 12 [File E69392]
- IEC 60529 IP66



## Applications

Designed to offer protection for oil-tight pushbuttons, switches, and pilot lights from dust, water, dirt and oil.

## Construction

- 16 gauge stainless steel, Type 304 and 316/316L
- Continuously welded seams.
- Captivated cover screws thread into sealed wells.
- 4-way pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights.
- Hole diameter is 0.87in [22.5 mm] or 1.20in [30.5 mm].
- Poured-in-place oil- and water-resistant gasket.
- Provisions for subpanel.
- Ground stud on door and body.
- Bolt-on continuous hinge with stainless steel hinge pin.
- Welded mounting provision top and bottom of back.



| Shipping Schedule                                    |             |
|--|-------------|
| Same day   | 1 - 15 days |
| Color indicates shipping lead time in business days. |             |

| 22mm NEMA 4, 4X, 12, and 13 Extra-Large Stainless Steel Wall-Mount Pushbutton |          |                      |          |  |       |              |                   |        |
|---|----------|----------------------|----------|--|-------|--------------|-------------------|--------|
| 304 Stainless Steel   | Price    | 316L Stainless Steel | Price    | Size HxWxD                             | Holes | Drawing Link | Optional Subpanel | Price  |
| <b>SCE-9PBHSSI</b>  | \$241.00 | <b>SCE-9PBHSS6I</b>  | \$289.00 | 10.38 x 10.31 x 6.20 [264 x 262 x 157] | 9     | PDF          | <b>SCE-10P10</b>  | \$7.25 |
| <b>SCE-16PBHSSI</b>   | \$411.00 | <b>SCE-16PBHSS6I</b> | \$493.00 | 12.38 x 12.31 x 6.20 [314 x 313 x 157] | 16    | PDF          | <b>SCE-12P12</b>  | \$9.75 |

*Note: Dimensions in inches [millimeters]*



| 30mm NEMA 4, 4X, 12, and 13 Extra-Large Stainless Steel Wall-Mount Pushbutton |          |                     |          |  |       |              |                   |        |
|---|----------|---------------------|----------|--|-------|--------------|-------------------|--------|
| 304 Stainless   | Price    | 316 Stainless       | Price    | Size HxWxD                             | Holes | Drawing Link | Optional Subpanel | Price  |
| <b>SCE-9PBHSS</b>   | \$225.00 | <b>SCE-9PBHSS6</b>  | \$270.00 | 10.38 x 10.31 x 6.20 [264 x 262 x 157] | 9     | PDF          | <b>SCE-10P10</b>  | \$7.00 |
| <b>SCE-16PBHSS</b>  | \$384.00 | <b>SCE-16PBHSS6</b> | \$461.00 | 12.38 x 12.31 x 6.20 [314 x 313 x 157] | 16    | PDF          | <b>SCE-12P12</b>  | \$9.00 |

*Note: Dimensions in inches [millimeters]*


# NEMA 4, 4X, 12, and 13 Extra-Large Stainless Steel Wall-Mount Pushbutton



## Dimensions

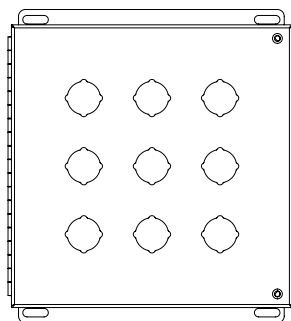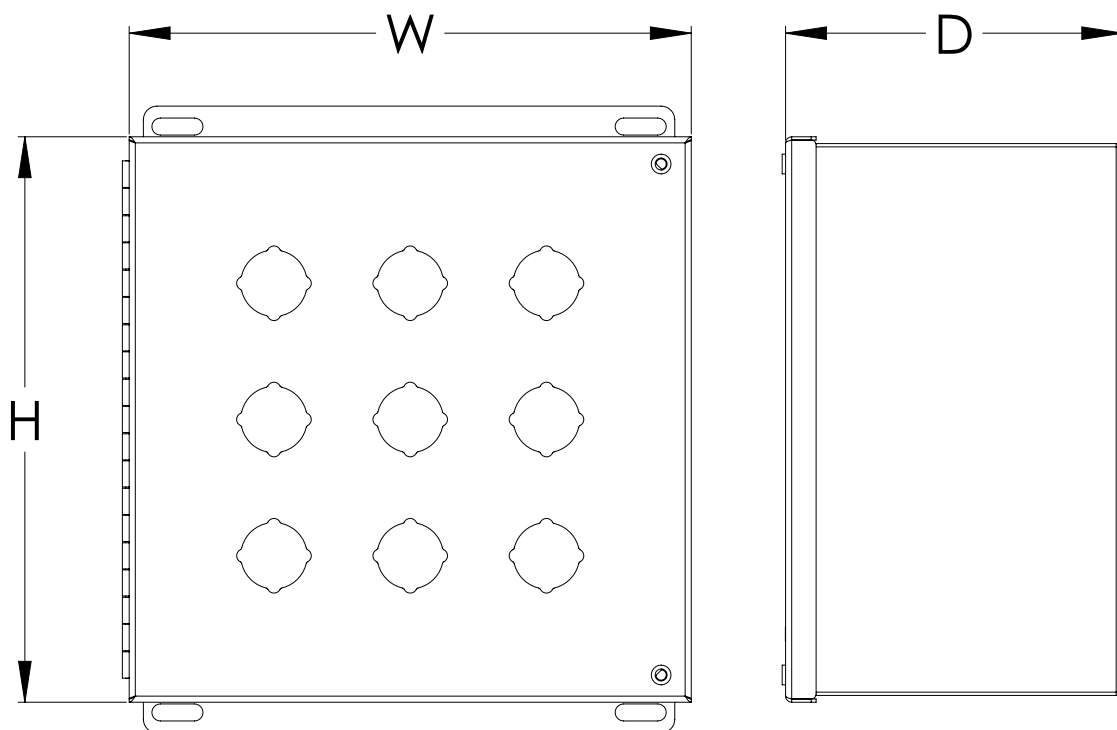

9

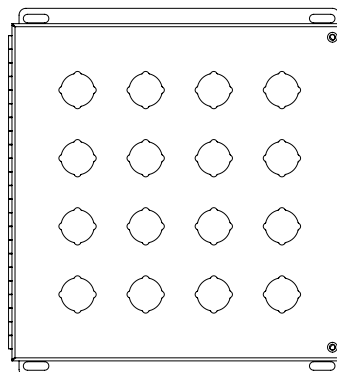

16