

NEMA 1 Single-Door Wall-Mount with Knockouts



Your Enclosure Source®



Applications

Designed to house electrical controls, instruments and components in areas that do not require oil, water and dust tight protection.

Construction


- 14 gauge, 16 gauge, or 18 gauge carbon steel depending on size.
- Spot weld construction.
- Knockouts provided in the top, bottom, right and left side.
- Standoffs provided for mounting optional subpanels.
- Butt hinge.
- Doors open 180°.
- Keylocking 1/4-turn latches.
- Latches are opened or closed with a screwdriver.
- Mounting holes in back of enclosure.
- Sub-panel with 2 in x 2 in [51 mm x 51 mm] mounting grid pattern included.
- Note: Tamper-resistant inserts available. Optional mounting straps available.

Finish

- Precaution Blue or Taupe Tan powder coat finish inside and out.
- Subpanels powder coated white.

Listings

- NEMA Type 1
- cULus Listed Type 1
- IEC 60529 IP30

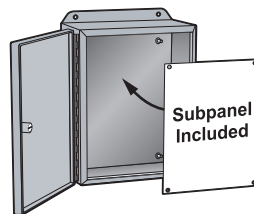

Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

NEMA 1 Single-Door Wall-Mount with Knockouts					
Blue	Tan	Price	Size HxWxD	Steel Thickness	Drawing Link
SCE-18N1606NK-B	SCE-18N1606NK-T	\$144.00	18.38 x 16.38 x 6.13 [467 x 416 x 156]	18 gauge	PDF
SCE-24N2006NK-B	SCE-24N2006NK-T	\$170.00	24.38 x 20.38 x 6.13 [619 x 518 x 156]	16 gauge	PDF
SCE-36N2406NK-B	SCE-36N2406NK-T	\$262.00	36.38 x 24.38 x 6.13 [924 x 619 x 156]	14 gauge	PDF

Note: Dimensions in inches [millimeters].

NEMA 1 Single-Door Wall-Mount with Knockouts



Your Enclosure Source®

Dimensions

