

NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



Applications

Designed for use as electrical junction boxes, terminal wiring boxes, instrument housings, and electrical control enclosures. Provides protection from dust, dirt, oil and water.

Construction

- 16 gauge carbon steel.
- Seams continuously welded and ground smooth, no holes or knockouts.
- Bolt-on continuous hinge with stainless steel pin.
- Stainless steel external screw clamps are quick and easy to operate.
- Poured-in-place oil- and water-resistant gasket.
- Standoffs provided for mounting optional subpanels.
- Welded mounting provision top and bottom of back.
- Ground stud on door and body.

Finish


- ANSI 61 gray powder coated inside and out.
- Optional subpanels powder coated white.

Listings

- NEMA Type 3R, 4, 12, and 13
- cULus Listed Type 3R, 4 and 12 [File E69392]
- IEC 60529 IP66



Dimensions

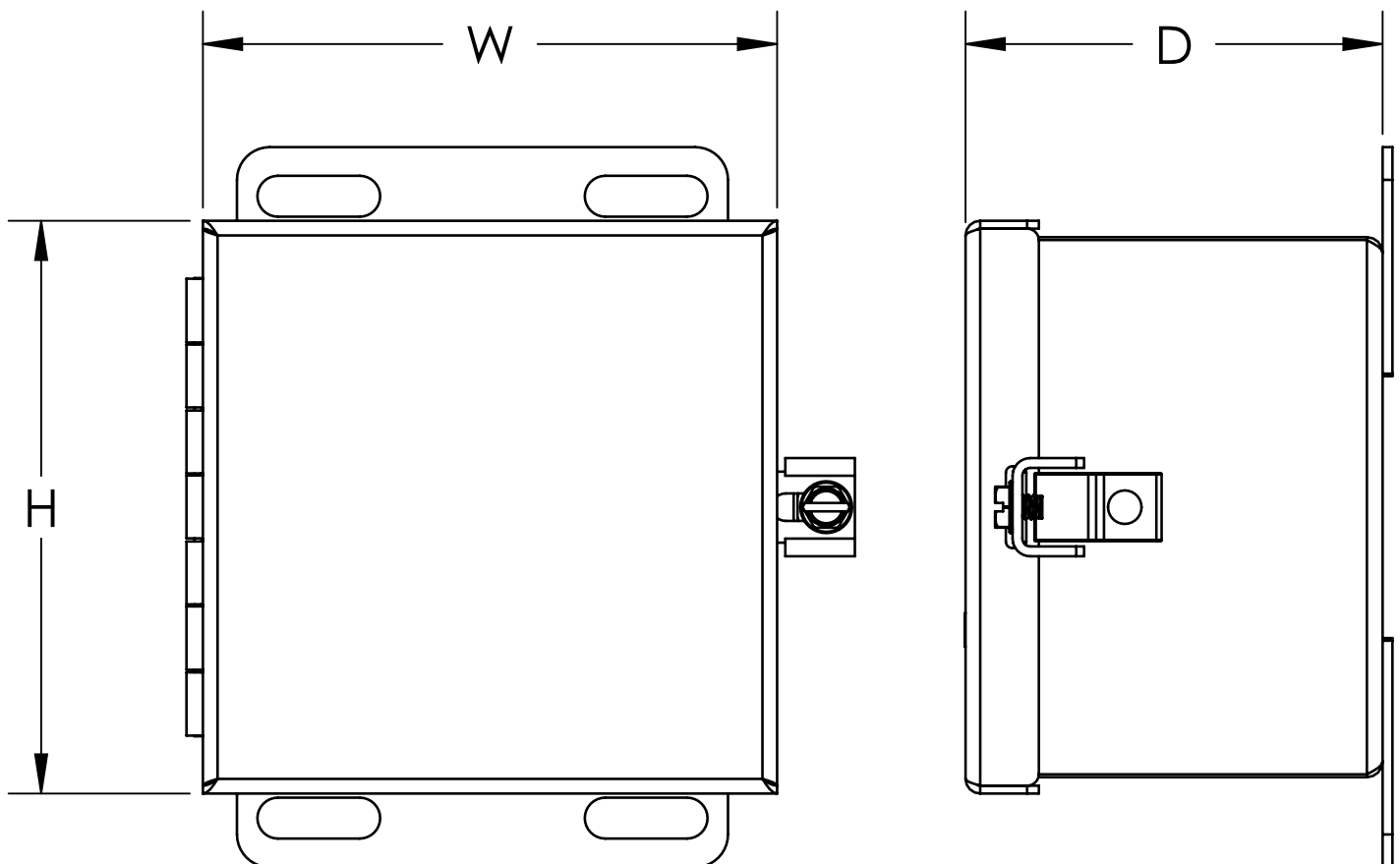

NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount					
Part Number	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-404CHNF	\$39.50	4.38 x 4.39 x 3.20 [111 x 112 x 81]	PDF	–	–
SCE-4044CHNF	\$41.00	4.38 x 4.39 x 4.20 [111 x 112 x 107]	PDF	–	–
SCE-604CHNF	\$44.50	6.38 x 4.39 x 3.20 [162 x 112 x 81]	PDF	SCE-6P4	\$3.25
SCE-6044CHNF	\$48.00	6.38 x 4.39 x 4.20 [162 x 112 x 107]	PDF	SCE-6P4	\$3.25
SCE-606CHNF	\$52.00	6.38 x 6.39 x 4.20 [162 x 162 x 107]	PDF	SCE-6P6	\$3.75
SCE-806CHNF	\$56.00	8.38 x 6.39 x 3.70 [213 x 162 x 94]	PDF	SCE-8P6	\$4.50
SCE-8066CHNF	\$66.00	8.38 x 6.39 x 6.20 [213 x 162 x 157]	PDF	SCE-8P6	\$4.50
SCE-808CHNF	\$63.00	8.38 x 8.39 x 4.20 [213 x 213 x 107]	PDF	SCE-8P8	\$5.25
SCE-8086CHNF	\$72.00	8.38 x 8.39 x 6.20 [213 x 213 x 157]	PDF	SCE-8P8	\$5.25
SCE-1008CHSNF*	\$77.00	8.39 x 10.38 x 4.20 [213 x 264 x 107]	PDF	SCE-10P8	\$6.00
SCE-1008CHNF	\$73.00	10.38 x 8.39 x 4.20 [264 x 213 x 107]	PDF	SCE-10P8	\$6.00
SCE-10086CHNF	\$84.00	10.38 x 8.39 x 6.20 [264 x 213 x 157]	PDF	SCE-10P8	\$6.00
SCE-10106CHNF	\$85.00	10.38 x 10.39 x 6.20 [264 x 264 x 157]	PDF	SCE-10P10	\$7.25
SCE-1210CHSNF*	\$94.00	10.39 x 12.38 x 5.20 [264 x 314 x 132]	PDF	SCE-12P10	\$8.25
SCE-12064CHNF	\$67.00	12.38 x 6.39 x 4.20 [314 x 162 x 107]	PDF	SCE-12P6	\$5.75
SCE-1210CHNF	\$92.00	12.38 x 10.39 x 5.20 [314 x 264 x 132]	PDF	SCE-12P10	\$8.25
SCE-12106CHNF	\$97.00	12.38 x 10.39 x 6.20 [314 x 264 x 157]	PDF	SCE-12P10	\$8.25
SCE-12108CHNF	\$104.00	12.38 x 10.39 x 8.20 [314 x 264 x 208]	PDF	SCE-12P10	\$8.25
SCE-1212CHNF	\$107.00	12.38 x 12.39 x 6.20 [314 x 315 x 157]	PDF	SCE-12P12	\$9.75
SCE-1412CHSNF*	\$125.00	12.39 x 14.38 x 6.20 [315 x 365 x 157]	PDF	SCE-14P12	\$10.75
SCE-14086CHNF	\$92.00	14.38 x 8.39 x 6.20 [365 x 213 x 157]	PDF	SCE-14P8	\$7.75
SCE-1412CHNF	\$119.00	14.38 x 12.39 x 6.20 [365 x 315 x 157]	PDF	SCE-14P12	\$10.75
SCE-14128CHNF	\$126.00	14.38 x 12.39 x 8.20 [365 x 315 x 208]	PDF	SCE-14P12	\$10.75
SCE-1614CHSNF*	\$146.00	14.39 x 16.38 x 6.20 [366 x 416 x 157]	PDF	SCE-16P14	\$21.00
SCE-16106CHNF	\$108.00	16.38 x 10.39 x 6.20 [416 x 264 x 157]	PDF	SCE-16P10	\$10.50
SCE-1614CHNF	\$139.00	16.38 x 14.39 x 6.20 [416 x 366 x 157]	PDF	SCE-16P14	\$21.00
SCE-16148CHNF	\$152.00	16.38 x 14.39 x 8.20 [416 x 366 x 208]	PDF	SCE-16P14	\$21.00
SCE-161410CHNF	\$159.00	16.38 x 14.39 x 10.20 [416 x 366 x 259]	PDF	SCE-16P14	\$21.00

Note: *Part numbers containing an S are hinged on the short side.
Dimensions in inches [millimeters].