

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®



## Applications

Designed for use as electrical junction boxes, terminal wiring boxes, instrument housings, and electrical control enclosures. For use in wet and hosed down areas and in corrosive atmospheres.

## Construction

- 16 gauge stainless steel Type 304 and 316/316L
- Seams continuously welded and ground smooth.
- Stainless steel continuous hinge.
- Stainless steel external screw clamps are quick and easy to operate.
- Poured-in-place oil- and water-resistant gasket
- Ground stud on door and body.
- Standoffs provided for mounting optional sub-panels.
- Welded mounting provision top and bottom of back.

## Finish

- #4 brushed finish on all exterior surfaces.
- Optional subpanels powder coated white.

## Listings

- NEMA Type 3R, 4, 4X, 12, and 13
- cULus Listed Type 3R, 4 and 12 [File E69392]
- IEC 60529 IP66



### Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

### NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
<b>SCE-6044CHNFSS</b>	\$148.00	<b>SCE-6044CHNFSS6</b>	\$177.00	6.38 x 4.39 x 3.20 [162 x 112 x 81]	<b>PDF</b>	<b>SCE-6P4</b>	\$3.25
<b>SCE-8064CHNFSS</b>	\$192.00	<b>SCE-8064CHNFSS6</b>	\$221.00	8.38 x 6.39 x 3.70 [213 x 162 x 94]	<b>PDF</b>	<b>SCE-8P6</b>	\$4.50
<b>SCE-606CHNFSS</b>	\$185.00	<b>SCE-606CHNFSS6</b>	\$202.00	6.38 x 6.39 x 4.20 [162 x 162 x 107]	<b>PDF</b>	<b>SCE-6P6</b>	\$3.75
<b>SCE-1008CHNFSS</b>	\$278.00	<b>SCE-1008CHNFSS6</b>	\$326.00	10.38 x 8.39 x 4.20 [264 x 213 x 107]	<b>PDF</b>	<b>SCE-10P8</b>	\$6.00
<b>SCE-10086CHNFSS</b>	\$304.00	<b>SCE-10086CHNFSS6</b>	\$356.00	10.38 x 8.39 x 6.20 [264 x 213 x 157]	<b>PDF</b>	<b>SCE-10P8</b>	\$6.00
<b>SCE-12106CHNFSS</b>	\$344.00	<b>SCE-12106CHNFSS6</b>	\$383.00	12.38 x 10.39 x 6.20 [314 x 264 x 157]	<b>PDF</b>	<b>SCE-12P10</b>	\$8.25
<b>SCE-12108CHNFSS</b>	\$367.00	<b>SCE-12108CHNFSS6</b>	\$440.00	12.38 x 10.39 x 8.20 [314 x 264 x 208]	<b>PDF</b>	<b>SCE-12P10</b>	\$8.25
<b>SCE-1212CHNFSS</b>	\$368.00	<b>SCE-1212CHNFSS6</b>	\$422.00	12.38 x 12.39 x 6.20 [314 x 315 x 157]	<b>PDF</b>	<b>SCE-12P12</b>	\$9.75
<b>SCE-1412CHNFSS</b>	\$389.00	<b>SCE-1412CHNFSS6</b>	\$462.00	14.38 x 12.39 x 6.20 [365 x 315 x 157]	<b>PDF</b>	<b>SCE-14P12</b>	\$10.75
<b>SCE-1614CHNFSS</b>	\$458.00	<b>SCE-1614CHNFSS6</b>	\$550.00	16.38 x 14.39 x 6.20 [416 x 366 x 157]	<b>PDF</b>	<b>SCE-16P14</b>	\$21.00
<b>SCE-16148CHNFSS</b>	\$508.00	<b>SCE-16148CHNFSS6</b>	\$569.00	16.38 x 14.39 x 8.20 [416 x 366 x 208]	<b>PDF</b>	<b>SCE-16P14</b>	\$21.00


Note: Dimensions in inches [millimeters]

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®

## Dimensions

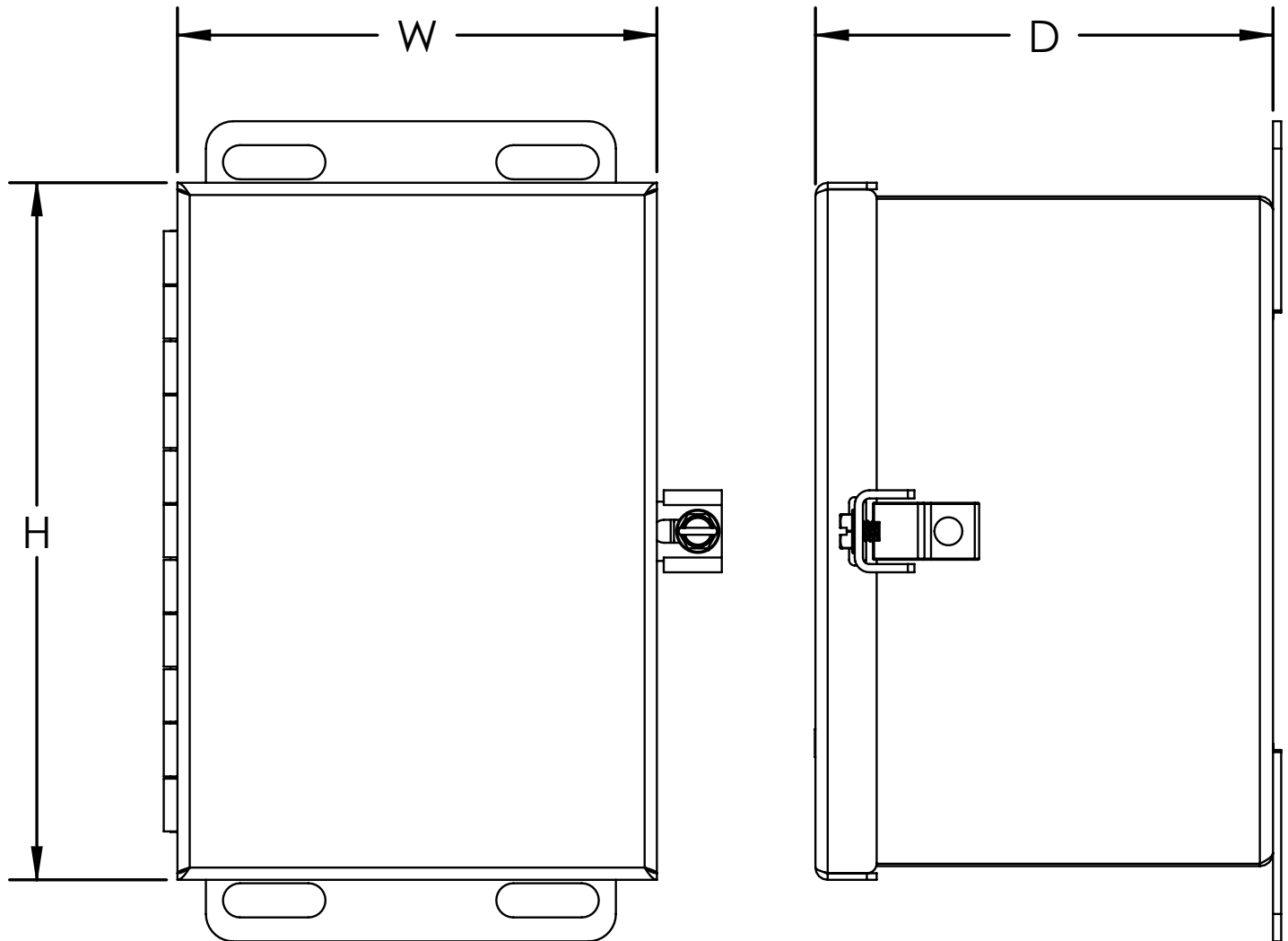

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



## Applications

Designed to house electrical and electronic controls, instruments and components in areas which are in very wet conditions. Provides a degree of protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended.

### Construction

- 14 gauge Type 304 or 316L stainless steel.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Poured-in-place oil- and water-resistant gasket.
- Collar studs provided for mounting optional subpanels.
- Stainless steel continuous hinges.
- Interior print pocket.
- Ground studs on door and body.
- Stainless steel door clamps.
- Hasp and staple for padlocking.
- Welded mounting provision top and bottom of back.

## Finish

- #4 brushed finish on all exterior surfaces.
- Optional subpanels powder coated white.

## Listings

- NEMA Type 3R, 4, 4X, 12, and 13
- cULus Listed Type 3R, 4, 4X, and 12 [File E69392]
- IEC 60529 IP66



# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount Right-Flange Disconnect							
304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
<b>SCE-16H1206SSLP</b>	\$524.00	<b>SCE-16H1206SS6LP</b>	\$629.00	16.00 x 12.00 x 7.07 [406 x 305 x 180]	PDF	<b>SCE-16P12</b>	\$15.75
<b>SCE-16H1208SSLP</b>	\$562.00	<b>SCE-16H1208SS6LP</b>	\$674.00	16.00 x 12.00 x 9.07 [406 x 305 x 230]	PDF	<b>SCE-16P12</b>	\$15.75
<b>SCE-16H1606SSLP</b>	\$582.00	<b>SCE-16H1606SS6LP</b>	\$699.00	16.00 x 16.00 x 7.07 [406 x 406 x 180]	PDF	<b>SCE-16P16</b>	\$26.00
<b>SCE-16H2006SSLP</b>	\$640.00	<b>SCE-16H2006SS6LP</b>	\$768.00	16.00 x 20.00 x 7.07 [406 x 508 x 180]	PDF	<b>SCE-20P16</b>	\$32.50
<b>SCE-20H1606SSLP</b>	\$640.00	<b>SCE-20H1606SS6LP</b>	\$768.00	20.00 x 16.00 x 7.07 [508 x 406 x 180]	PDF	<b>SCE-20P16</b>	\$32.50
<b>SCE-20H1608SSLP</b>	\$685.00	<b>SCE-20H1608SS6LP</b>	\$822.00	20.00 x 16.00 x 9.07 [508 x 406 x 230]	PDF	<b>SCE-20P16</b>	\$32.50
<b>SCE-20H1610SSLP</b>	\$732.00	<b>SCE-20H1610SS6LP</b>	\$878.00	20.00 x 16.00 x 11.07 [508 x 406 x 281]	PDF	<b>SCE-20P16</b>	\$32.50
<b>SCE-20H2006SSLP</b>	\$706.00	<b>SCE-20H2006SS6LP</b>	\$847.00	20.00 x 20.00 x 7.07 [508 x 508 x 180]	PDF	<b>SCE-20P20</b>	\$37.50
<b>SCE-20H2408SSLP</b>	\$828.00	<b>SCE-20H2408SS6LP</b>	\$994.00	20.00 x 24.00 x 9.07 [508 x 610 x 230]	PDF	<b>SCE-24P20</b>	\$48.50
<b>SCE-24H1608SSLP</b>	\$745.00	<b>SCE-24H1608SS6LP</b>	\$895.00	24.00 x 16.00 x 9.07 [610 x 406 x 230]	PDF	<b>SCE-24P16</b>	\$35.00
<b>SCE-24H2006SSLP</b>	\$773.00	<b>SCE-24H2006SS6LP</b>	\$927.00	24.00 x 20.00 x 7.07 [610 x 508 x 180]	PDF	<b>SCE-24P20</b>	\$48.50
<b>SCE-24H2008SSLP</b>	\$828.00	<b>SCE-24H2008SS6LP</b>	\$994.00	24.00 x 20.00 x 9.07 [610 x 508 x 230]	PDF	<b>SCE-24P20</b>	\$48.50
<b>SCE-24H2010SSLP</b>	\$885.00	<b>SCE-24H2010SS6LP</b>	\$1,062.00	24.00 x 20.00 x 11.07 [610 x 508 x 281]	PDF	<b>SCE-24P20</b>	\$48.50
<b>SCE-24H2406SSLP</b>	\$794.00	—	—	24.00 x 24.00 x 7.07 [610 x 610 x 180]	PDF	<b>SCE-24P24</b>	\$56.00
<b>SCE-24H2408SSLP</b>	\$911.00	<b>SCE-24H2408SS6LP</b>	\$1,093.00	24.00 x 24.00 x 9.07 [610 x 610 x 230]	PDF	<b>SCE-24P24</b>	\$56.00
<b>SCE-24H2412SSLP</b>	\$1,035.00	<b>SCE-24H2412SS6LP</b>	\$1,242.00	24.00 x 24.00 x 13.07 [610 x 610 x 332]	PDF	<b>SCE-24P24</b>	\$56.00
<b>SCE-24H3008SSLP</b>	\$1,035.00	<b>SCE-24H3008SS6LP</b>	\$1,242.00	24.00 x 30.00 x 9.07 [610 x 762 x 230]	PDF	<b>SCE-30P24</b>	\$67.00
<b>SCE-30H2008SSLP</b>	\$937.00	<b>SCE-30H2008SS6LP</b>	\$1,125.00	30.00 x 20.00 x 9.07 [762 x 508 x 230]	PDF	<b>SCE-30P20</b>	\$59.00
<b>SCE-30H2408SSLP</b>	\$1,035.00	<b>SCE-30H2408SS6LP</b>	\$1,242.00	30.00 x 24.00 x 9.07 [762 x 610 x 230]	PDF	<b>SCE-30P24</b>	\$67.00
<b>SCE-30H2412SSLP</b>	\$1,173.00	<b>SCE-30H2412SS6LP</b>	\$1,408.00	30.00 x 24.00 x 13.07 [762 x 610 x 332]	PDF	<b>SCE-30P24</b>	\$67.00
<b>SCE-30H2416SSLP</b>	\$1,314.00	<b>SCE-30H2416SS6LP</b>	\$1,577.00	30.00 x 24.00 x 17.07 [762 x 610 x 434]	PDF	<b>SCE-30P24</b>	\$67.00
<b>SCE-30H3008SSLP</b>	\$1,182.00	<b>SCE-30H3008SS6LP</b>	\$1,419.00	30.00 x 30.00 x 9.07 [762 x 762 x 230]	PDF	<b>SCE-30P30</b>	\$89.00
<b>SCE-36H2408SSLP</b>	\$1,159.00	<b>SCE-36H2408SS6LP</b>	\$1,390.00	36.00 x 24.00 x 9.07 [914 x 610 x 230]	PDF	<b>SCE-36P24</b>	\$81.00
<b>SCE-36H2410SSLP</b>	\$1,237.00	<b>SCE-36H2410SS6LP</b>	\$1,484.00	36.00 x 24.00 x 11.07 [914 x 610 x 281]	PDF	<b>SCE-36P24</b>	\$81.00
<b>SCE-36H3008SSLP</b>	\$1,329.00	<b>SCE-36H3008SS6LP</b>	\$1,594.00	36.00 x 30.00 x 9.07 [914 x 762 x 230]	PDF	<b>SCE-36P30</b>	\$108.00
<b>SCE-36H3010SSLP</b>	\$1,414.00	<b>SCE-36H3010SS6LP</b>	\$1,697.00	36.00 x 30.00 x 11.07 [914 x 762 x 281]	PDF	<b>SCE-36P30</b>	\$108.00
<b>SCE-36H3012SSLP</b>	\$1,499.00	<b>SCE-36H3012SS6LP</b>	\$1,799.00	36.00 x 30.00 x 13.07 [914 x 762 x 332]	PDF	<b>SCE-36P30</b>	\$108.00
<b>SCE-36H3016SSLP</b>	\$1,668.00	<b>SCE-36H3016SS6LP</b>	\$2,002.00	36.00 x 30.00 x 17.07 [914 x 762 x 434]	PDF	<b>SCE-36P30</b>	\$108.00
<b>SCE-36H3612SSLP</b>	\$1,684.00	<b>SCE-36H3612SS6LP</b>	\$2,021.00	36.00 x 36.00 x 13.07 [914 x 914 x 332]	PDF	<b>SCE-36P36</b>	\$126.00
<b>SCE-42H3010SSLP</b>	\$1,568.00	<b>SCE-42H3010SS6LP</b>	\$1,882.00	42.00 x 30.00 x 11.07 [1067 x 762 x 281]	PDF	<b>SCE-42P30</b>	\$124.00
<b>SCE-42H3608SSLP</b>	\$1,668.00	<b>SCE-42H3608SS6LP</b>	\$2,002.00	42.00 x 36.00 x 9.07 [1067 x 914 x 230]	PDF	<b>SCE-42P36</b>	\$145.00
<b>SCE-48H3608SSLP</b>	\$1,838.00	<b>SCE-48H3608SS6LP</b>	\$2,206.00	48.00 x 36.00 x 9.07 [1219 x 914 x 230]	PDF	<b>SCE-48P36</b>	\$164.00
<b>SCE-48H3610SSLP</b>	\$2,040.00	—	—	48.00 x 36.00 x 11.07 [1219 x 914 x 281]	PDF	<b>SCE-48P36</b>	\$164.00
<b>SCE-48H3612SSLP</b>	\$2,054.00	<b>SCE-48H3612SS6LP</b>	\$2,465.00	48.00 x 36.00 x 13.07 [1219 x 914 x 332]	PDF	<b>SCE-48P36</b>	\$164.00
<b>SCE-48H3616SSLP</b>	\$2,270.00	<b>SCE-48H3616SS6LP</b>	\$2,725.00	48.00 x 36.00 x 17.07 [1219 x 914 x 434]	PDF	<b>SCE-48P36</b>	\$164.00
<b>SCE-60H3612SSLP</b>	\$2,425.00	<b>SCE-60H3612SS6LP</b>	\$2,910.00	60.00 x 36.00 x 13.07 [1524 x 914 x 332]	PDF	<b>SCE-60P36</b>	\$202.00

Note: Dimensions in inches [millimeters]

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



## Dimensions

