

NEMA 3R Painted Galvannealed Steel Single-Door Wall-Mount



Your Enclosure Source®



Applications

Designed to house electrical controls, instruments, and components in an outdoor environment. Protects against rain, sleet and snow.

Construction

- 14-gauge, 16-gauge, or 18-gauge galvannealed steel
- Concealed hinges
- Spot weld construction
- Rain cap
- Mounting holes in back of enclosure
- Provisions for subpanel
- Doors open 180°
- Black, 1/4-turn latch with padlocking wing-knobs
- Poured-in-place oil- and water-resistant gasket
- Ground studs on door and body
- 3/8-16 grounding kit
- Subpanel mounting hardware included

Note: Optional mounting straps or mounting foot kits available.

Finish


- ANSI 61 gray powder coated inside and out
- Optional subpanels are powder coated white.

Listings

- NEMA Type 3R
- cULus Listed Type 3R [File E69392]
- IEC 60529 IP32



Dimensions

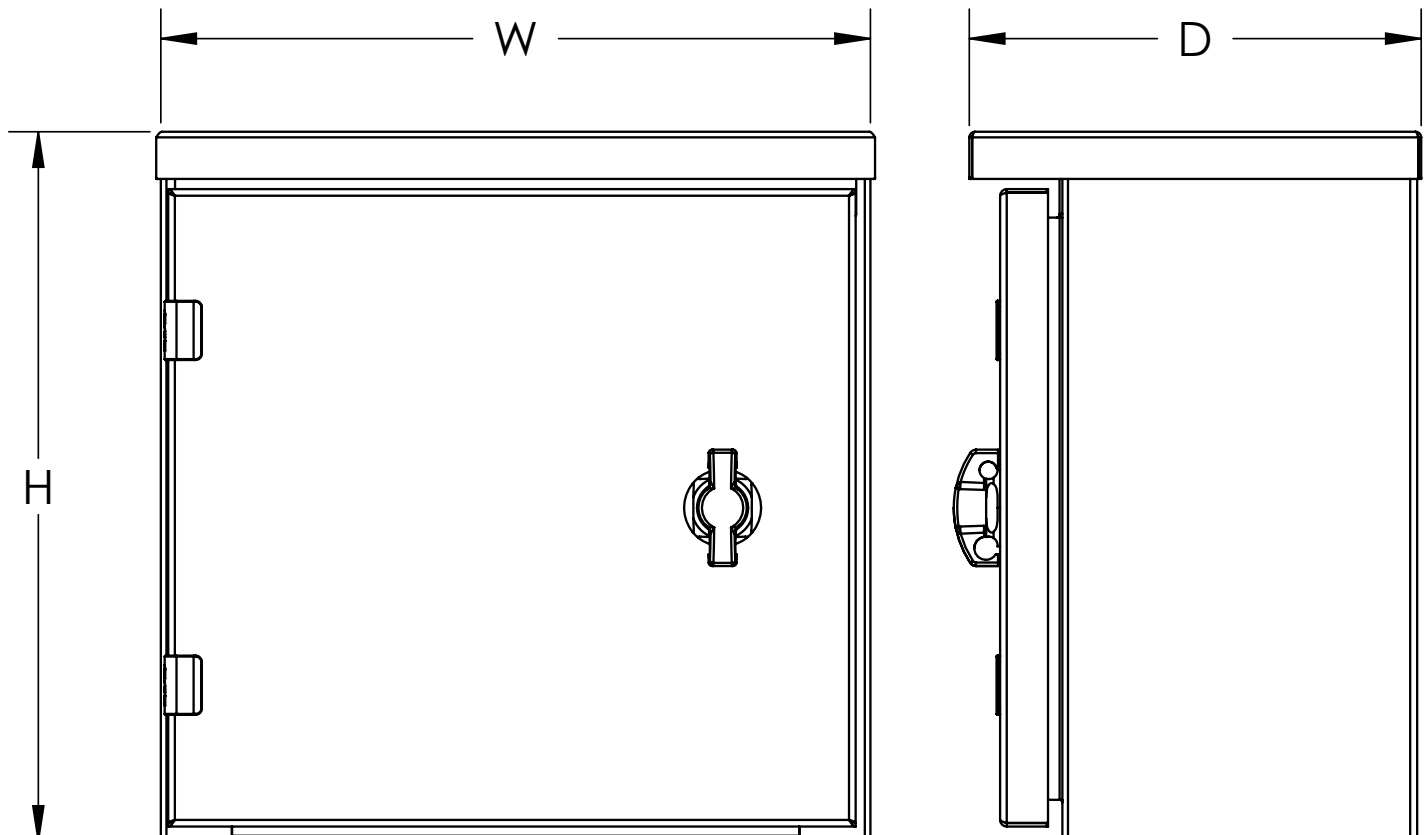

NEMA 3R Painted Galvannealed Steel Single-Door Wall-Mount



Your Enclosure Source®

Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3 Painted Galvannealed Steel Single-Door Wall-Mount

Part Number	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-12R1206LP	\$114.00	12.00 x 12.20 x 7.70 [305 x 310 x 196]	PDF	SCE-12DLP12	\$20.50
SCE-12R1208LP	\$120.00	12.00 x 12.20 x 9.70 [305 x 310 x 246]	PDF	SCE-12DLP12	\$20.50
SCE-16R1206LP	\$148.00	16.00 x 12.20 x 7.70 [406 x 310 x 196]	PDF	SCE-16P12	\$22.00
SCE-16R1208LP	\$155.00	16.00 x 12.20 x 9.70 [406 x 310 x 246]	PDF	SCE-16P12	\$22.00
SCE-20R1606LP	\$199.00	20.00 x 16.20 x 7.70 [508 x 411 x 196]	PDF	SCE-20P16	\$45.00
SCE-20R1608LP	\$209.00	20.00 x 16.20 x 9.70 [508 x 411 x 246]	PDF	SCE-20P16	\$45.00
SCE-24R2006LP	\$305.00	24.00 x 20.20 x 7.70 [610 x 513 x 196]	PDF	SCE-24P20	\$68.00
SCE-24R2008LP	\$320.00	24.00 x 20.20 x 9.70 [610 x 513 x 246]	PDF	SCE-24P20	\$68.00
SCE-24R2012LP	\$343.00	24.00 x 20.20 x 13.70 [610 x 513 x 348]	PDF	SCE-24P20	\$68.00
SCE-24R2016LP	\$372.00	24.00 x 20.20 x 17.70 [610 x 513 x 450]	PDF	SCE-24P20	\$68.00
SCE-24R2408LP	\$347.00	24.00 x 24.20 x 9.70 [610 x 615 x 246]	PDF	SCE-24P24	\$79.00
SCE-24R2412LP	\$371.00	24.00 x 24.20 x 13.70 [610 x 615 x 348]	PDF	SCE-24P24	\$79.00
SCE-24R2416LP	\$402.00	24.00 x 24.20 x 17.70 [610 x 615 x 450]	PDF	SCE-24P24	\$79.00
SCE-30R2408LP	\$422.00	30.00 x 24.20 x 9.70 [762 x 615 x 246]	PDF	SCE-30P24	\$94.00
SCE-30R2412LP	\$447.00	30.00 x 24.20 x 13.70 [762 x 615 x 348]	PDF	SCE-30P24	\$94.00
SCE-30R2416LP	\$478.00	30.00 x 24.20 x 17.70 [762 x 615 x 450]	PDF	SCE-30P24	\$94.00
SCE-36R2408LP	\$619.00	36.00 x 24.20 x 9.70 [914 x 615 x 246]	PDF	SCE-36P24	\$113.00
SCE-36R2412LP	\$647.00	36.00 x 24.20 x 13.70 [914 x 615 x 348]	PDF	SCE-36P24	\$113.00
SCE-36R2416LP	\$676.00	36.00 x 24.20 x 17.70 [914 x 615 x 450]	PDF	SCE-36P24	\$113.00
SCE-36R3008LP	\$657.00	36.00 x 30.20 x 9.70 [914 x 767 x 246]	PDF	SCE-36P30	\$151.00
SCE-36R3012LP	\$688.00	36.00 x 30.20 x 13.70 [914 x 767 x 348]	PDF	SCE-36P30	\$151.00
SCE-36R3016LP	\$716.00	36.00 x 30.20 x 17.70 [914 x 767 x 450]	PDF	SCE-36P30	\$151.00
SCE-42R3012LP	\$776.00	42.00 x 30.20 x 13.70 [1067 x 767 x 348]	PDF	SCE-42P30	\$173.00
SCE-42R3016LP	\$816.00	42.00 x 30.20 x 17.70 [1067 x 767 x 450]	PDF	SCE-42P30	\$173.00

Note: Dimensions in inches [millimeters].