

NEMA 3R Painted Galvannealed Steel Single-Door Wall-Mount



Applications

Designed to house electrical controls, instruments and components in an outdoor environment. Protects against rain, sleet and snow.

Construction

- 14 gauge, 16 gauge, or 18 gauge galvannealed steel.
- Concealed hinges.
- Spot weld construction.
- Rain cap.
- Mounting holes in back of enclosure.
- Provisions for subpanel.
- Doors open 180°.
- Black 1/4-turn latch with padlocking wing-knobs.
- Poured-in-place oil- and water-resistant gasket.
- Ground studs on door and body.
- 3/8-16 grounding kit.
- Subpanel mounting hardware included.
- Note: Optional mounting straps or mounting foot kits available.

Finish


- ANSI 61 gray powder coated inside and out.
- Optional subpanels powder coated white.

Listings

- NEMA Type 3R
- cULus Listed Type 3R [File E69392]
- IEC 60529 IP32



Dimensions

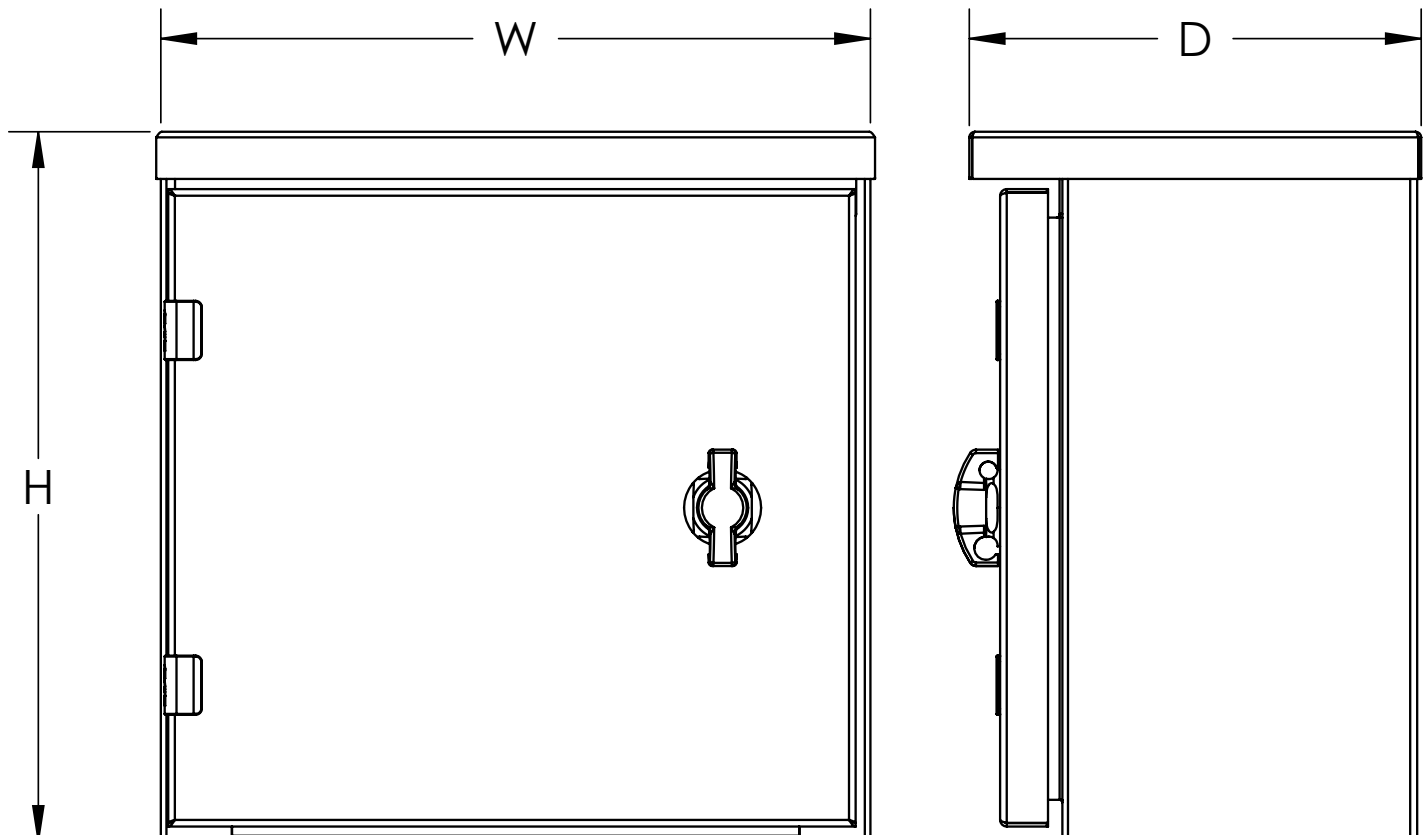

NEMA 3R Painted Galvannealed Steel Single-Door Wall-Mount



Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3 Painted Galvannealed Steel Single-Door Wall-Mount

| Part Number | Price | Size HxWxD | Drawing Link | Optional Subpanel | Price |
|----------------------|----------|--|---------------------|----------------------|----------|
| SCE-12R1206LP | \$83.00 | 12.00 x 12.20 x 7.70 [305 x 310 x 196] | PDF | SCE-12DLP12 | \$14.50 |
| SCE-12R1208LP | \$88.00 | 12.00 x 12.20 x 9.70 [305 x 310 x 246] | PDF | SCE-12DLP12 | \$14.50 |
| SCE-16R1206LP | \$108.00 | 16.00 x 12.20 x 7.70 [406 x 310 x 196] | PDF | SCE-16P12 | \$15.75 |
| SCE-16R1208LP | \$114.00 | 16.00 x 12.20 x 9.70 [406 x 310 x 246] | PDF | SCE-16P12 | \$15.75 |
| SCE-20R1606LP | \$146.00 | 20.00 x 16.20 x 7.70 [508 x 411 x 196] | PDF | SCE-20P16 | \$32.50 |
| SCE-20R1608LP | \$153.00 | 20.00 x 16.20 x 9.70 [508 x 411 x 246] | PDF | SCE-20P16 | \$32.50 |
| SCE-24R2006LP | \$223.00 | 24.00 x 20.20 x 7.70 [610 x 513 x 196] | PDF | SCE-24P20 | \$48.50 |
| SCE-24R2008LP | \$234.00 | 24.00 x 20.20 x 9.70 [610 x 513 x 246] | PDF | SCE-24P20 | \$48.50 |
| SCE-24R2012LP | \$251.00 | 24.00 x 20.20 x 13.70 [610 x 513 x 348] | PDF | SCE-24P20 | \$48.50 |
| SCE-24R2016LP | \$272.00 | 24.00 x 20.20 x 17.70 [610 x 513 x 450] | PDF | SCE-24P20 | \$48.50 |
| SCE-24R2408LP | \$254.00 | 24.00 x 24.20 x 9.70 [610 x 615 x 246] | PDF | SCE-24P24 | \$56.00 |
| SCE-24R2412LP | \$271.00 | 24.00 x 24.20 x 13.70 [610 x 615 x 348] | PDF | SCE-24P24 | \$56.00 |
| SCE-24R2416LP | \$294.00 | 24.00 x 24.20 x 17.70 [610 x 615 x 450] | PDF | SCE-24P24 | \$56.00 |
| SCE-30R2408LP | \$309.00 | 30.00 x 24.20 x 9.70 [762 x 615 x 246] | PDF | SCE-30P24 | \$67.00 |
| SCE-30R2412LP | \$327.00 | 30.00 x 24.20 x 13.70 [762 x 615 x 348] | PDF | SCE-30P24 | \$67.00 |
| SCE-30R2416LP | \$350.00 | 30.00 x 24.20 x 17.70 [762 x 615 x 450] | PDF | SCE-30P24 | \$67.00 |
| SCE-36R2408LP | \$452.00 | 36.00 x 24.20 x 9.70 [914 x 615 x 246] | PDF | SCE-36P24 | \$81.00 |
| SCE-36R2412LP | \$473.00 | 36.00 x 24.20 x 13.70 [914 x 615 x 348] | PDF | SCE-36P24 | \$81.00 |
| SCE-36R2416LP | \$494.00 | 36.00 x 24.20 x 17.70 [914 x 615 x 450] | PDF | SCE-36P24 | \$81.00 |
| SCE-36R3008LP | \$480.00 | 36.00 x 30.20 x 9.70 [914 x 767 x 246] | PDF | SCE-36P30 | \$108.00 |
| SCE-36R3012LP | \$503.00 | 36.00 x 30.20 x 13.70 [914 x 767 x 348] | PDF | SCE-36P30 | \$108.00 |
| SCE-36R3016LP | \$524.00 | 36.00 x 30.20 x 17.70 [914 x 767 x 450] | PDF | SCE-36P30 | \$108.00 |
| SCE-42R3012LP | \$567.00 | 42.00 x 30.20 x 13.70 [1067 x 767 x 348] | PDF | SCE-42P30 | \$124.00 |
| SCE-42R3016LP | \$596.00 | 42.00 x 30.20 x 17.70 [1067 x 767 x 450] | PDF | SCE-42P30 | \$124.00 |

Note: Dimensions in inches [millimeters].