


Enviroline Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount

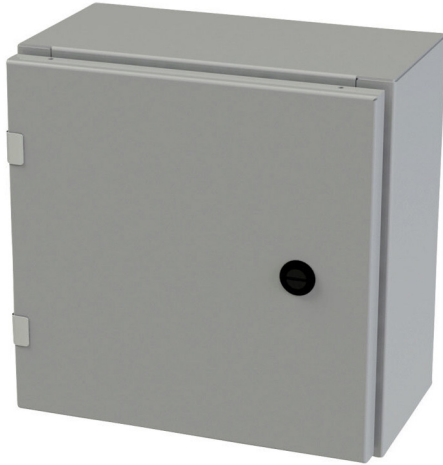

Applications

Designed to house electrical and electronic controls, instruments and components. Provides protection from dust, oil and water. For outdoor application a drip shield is recommended.

Construction

- 14 gauge carbon steel.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Poured-in-place oil- and water-resistant gasket.
- Collar studs provided for mounting optional subpanels.
- Easy to install swing-out panel kits that mount to the concealed hinges.
- Concealed hinges can be removed by pulling the pin.
- Removable and interchangeable doors.
- Black 1/4-turn latches.
- Latches can be replaced with a variety of latches, including wing knob, keylocking, padlocking, coinproof, and tamper resistant inserts.
- Latches can be replaced with several handles, including chrome keylocking and padlocking, and the black 5in and 7in SCE handles, including keylocking, padlocking, and coinproof.
- Latches are opened or closed with a screwdriver.
- A three-point latching system is available for enclosures over 40in [1016mm] high.
- Mounting holes in back of enclosure.
- Mounting hardware, sealing washers and hole plugs included.
- Removable print pocket furnished if height and width of enclosure is greater than 12in [305mm].
- Ground studs on door and body.
- Provision for lifting lugs included on enclosures with height greater than 48in [1219mm] and with depth greater than 16 in [406 mm]. Lifting lug assembly included with the enclosure bolt pack.

Options

- Optional mounting feet available (SCE-ELMFK4)
- Door hardware available.

Finish

- ANSI 61 gray or RAL 7035 gray powder coated inside and out.
- Optional subpanels powder coated white.

Listings

- NEMA Type 3R, 4, 12, and 13
- cULus Listed Type 3R, 4 and 12 [File E69392]
- IEC 60529 IP66



Enviroline Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



Your Enclosure Source®

Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

Enviroline Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount						
ANSI 61 Gray	RAL 7035 Gray	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-12EL1206LP	SCE-12EL1206LPLG	\$176.00	12.00 x 12.00 x 7.10 [305 x 305 x 180]	PDF	SCE-12DLP12	\$14.50
SCE-12EL2406LP	SCE-12EL2406LPLG	\$210.00	12.00 x 24.00 x 7.10 [305 x 610 x 180]	PDF	SCE-12P24	\$29.50
SCE-12EL2408LP	SCE-12EL2408LPLG	\$230.00	12.00 x 24.00 x 9.10 [305 x 610 x 231]	PDF	SCE-12P24	\$29.50
SCE-16EL1206LP	SCE-16EL1206LPLG	\$187.00	16.00 x 12.00 x 7.10 [406 x 305 x 180]	PDF	SCE-16P12	\$15.75
SCE-16EL1208LP	SCE-16EL1208LPLG	\$197.00	16.00 x 12.00 x 9.10 [406 x 305 x 231]	PDF	SCE-16P12	\$15.75
SCE-16EL1408LP	SCE-16EL1408LPLG	\$203.00	16.00 x 14.00 x 9.10 [406 x 356 x 231]	PDF	SCE-16DLP14	\$18.75
SCE-16EL1606LP	SCE-16EL1606LPLG	\$202.00	16.00 x 16.00 x 7.10 [406 x 406 x 180]	PDF	SCE-16P16	\$26.00
SCE-16EL1608LP	SCE-16EL1608LPLG	\$226.00	16.00 x 16.00 x 9.10 [406 x 406 x 231]	PDF	SCE-16P16	\$26.00
SCE-16EL2006LP	SCE-16EL2006LPLG	\$227.00	16.00 x 20.00 x 7.10 [406 x 508 x 180]	PDF	SCE-20P16	\$32.50
SCE-16EL2008LP	SCE-16EL2008LPLG	\$228.00	16.00 x 20.00 x 9.10 [406 x 508 x 231]	PDF	SCE-20P16	\$32.50
SCE-20EL1206LP	SCE-20EL1206LPLG	\$201.00	20.00 x 12.00 x 7.10 [508 x 305 x 180]	PDF	SCE-20P12	\$24.50
SCE-20EL1606LP	SCE-20EL1606LPLG	\$216.00	20.00 x 16.00 x 7.10 [508 x 406 x 180]	PDF	SCE-20P16	\$32.50
SCE-20EL1608LP	SCE-20EL1608LPLG	\$228.00	20.00 x 16.00 x 9.10 [508 x 406 x 231]	PDF	SCE-20P16	\$32.50
SCE-20EL1610LP	SCE-20EL1610LPLG	\$243.00	20.00 x 16.00 x 11.10 [508 x 406 x 282]	PDF	SCE-20P16	\$32.50
SCE-20EL1612LP	SCE-20EL1612LPLG	\$253.00	20.00 x 16.00 x 13.10 [508 x 406 x 333]	PDF	SCE-20P16	\$32.50
SCE-20EL2006LP	SCE-20EL2006LPLG	\$233.00	20.00 x 20.00 x 7.10 [508 x 508 x 180]	PDF	SCE-20P20	\$37.50
SCE-20EL2008LP	SCE-20EL2008LPLG	\$246.00	20.00 x 20.00 x 9.10 [508 x 508 x 231]	PDF	SCE-20P20	\$37.50
SCE-20EL2010LP	SCE-20EL2010LPLG	\$260.00	20.00 x 20.00 x 11.10 [508 x 508 x 282]	PDF	SCE-20P20	\$37.50
SCE-20EL2012LP	SCE-20EL2012LPLG	\$273.00	20.00 x 20.00 x 13.10 [508 x 508 x 333]	PDF	SCE-20P20	\$37.50
SCE-20EL2408LP	SCE-20EL2408LPLG	\$265.00	20.00 x 24.00 x 9.10 [508 x 610 x 231]	PDF	SCE-24P20	\$48.50
SCE-24EL1206LP	SCE-24EL1206LPLG	\$210.00	24.00 x 12.00 x 7.10 [610 x 305 x 180]	PDF	SCE-12P24	\$29.50
SCE-24EL1606LP	SCE-24EL1606LPLG	\$231.00	24.00 x 16.00 x 7.10 [610 x 406 x 180]	PDF	SCE-24P16	\$35.00
SCE-24EL1608LP	SCE-24EL1608LPLG	\$244.00	24.00 x 16.00 x 9.10 [610 x 406 x 231]	PDF	SCE-24P16	\$35.00
SCE-24EL2006LP	SCE-24EL2006LPLG	\$251.00	24.00 x 20.00 x 7.10 [610 x 508 x 180]	PDF	SCE-24P20	\$48.50
SCE-24EL2008LP	SCE-24EL2008LPLG	\$265.00	24.00 x 20.00 x 9.10 [610 x 508 x 231]	PDF	SCE-24P20	\$48.50
SCE-24EL2010LP	SCE-24EL2010LPLG	\$281.00	24.00 x 20.00 x 11.10 [610 x 508 x 282]	PDF	SCE-24P20	\$48.50
SCE-24EL2012LP	SCE-24EL2012LPLG	\$296.00	24.00 x 20.00 x 13.10 [610 x 508 x 333]	PDF	SCE-24P20	\$48.50
SCE-24EL2016LP	SCE-24EL2016LPLG	\$324.00	24.00 x 20.00 x 17.10 [610 x 508 x 434]	PDF	SCE-24P20	\$48.50
SCE-24EL2406LP	SCE-24EL2406LPLG	\$271.00	24.00 x 24.00 x 7.10 [610 x 610 x 180]	PDF	SCE-24P24	\$56.00
SCE-24EL2408LP	SCE-24EL2408LPLG	\$286.00	24.00 x 24.00 x 9.10 [610 x 610 x 231]	PDF	SCE-24P24	\$56.00
SCE-24EL2410LP	SCE-24EL2410LPLG	\$303.00	24.00 x 24.00 x 11.10 [610 x 610 x 282]	PDF	SCE-24P24	\$56.00
SCE-24EL2412LP	SCE-24EL2412LPLG	\$317.00	24.00 x 24.00 x 13.10 [610 x 610 x 333]	PDF	SCE-24P24	\$56.00
SCE-24EL2416LP	SCE-24EL2416LPLG	\$349.00	24.00 x 24.00 x 17.10 [610 x 610 x 434]	PDF	SCE-24P24	\$56.00
SCE-24EL3008LP	SCE-24EL3008LPLG	\$317.00	24.00 x 30.00 x 9.10 [610 x 762 x 231]	PDF	SCE-30P24	\$67.00
SCE-24EL3010LP	SCE-24EL3010LPLG	\$342.00	24.00 x 30.00 x 11.10 [610 x 762 x 282]	PDF	SCE-30P24	\$67.00
SCE-24EL3012LP	SCE-24EL3012LPLG	\$366.00	24.00 x 30.00 x 13.10 [610 x 762 x 333]	PDF	SCE-30P24	\$67.00
SCE-30EL1606LP	SCE-30EL1606LPLG	\$253.00	30.00 x 16.00 x 7.10 [762 x 406 x 180]	PDF	SCE-30P16	\$48.50
SCE-30EL2008LP	SCE-30EL2008LPLG	\$292.00	30.00 x 20.00 x 9.10 [762 x 508 x 231]	PDF	SCE-30P20	\$59.00
SCE-30EL2010LP	SCE-30EL2010LPLG	\$307.00	30.00 x 20.00 x 11.10 [762 x 508 x 282]	PDF	SCE-30P20	\$59.00
SCE-30EL2406LP	SCE-30EL2406LPLG	\$298.00	30.00 x 24.00 x 7.10 [762 x 610 x 180]	PDF	SCE-30P24	\$67.00
SCE-30EL2408LP	SCE-30EL2408LPLG	\$317.00	30.00 x 24.00 x 9.10 [762 x 610 x 231]	PDF	SCE-30P24	\$67.00

Note: Dimensions in inches [millimeters].

Enviroline Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

Enviroline Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount						
ANSI 61 Gray	RAL 7035 Gray	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-30EL2410LP	SCE-30EL2410LPLG	\$342.00	30.00 x 24.00 x 11.10 [762 x 610 x 282]	PDF	SCE-30P24	\$67.00
SCE-30EL2412LP	SCE-30EL2412LPLG	\$352.00	30.00 x 24.00 x 13.10 [762 x 610 x 333]	PDF	SCE-30P24	\$67.00
SCE-30EL2416LP	SCE-30EL2416LPLG	\$389.00	30.00 x 24.00 x 17.10 [762 x 610 x 434]	PDF	SCE-30P24	\$67.00
SCE-30EL2420LP	SCE-30EL2420LPLG	\$424.00	30.00 x 24.00 x 21.10 [762 x 610 x 536]	PDF	SCE-30P24	\$67.00
SCE-30EL2424LP	SCE-30EL2424LPLG	\$460.00	30.00 x 24.00 x 25.10 [762 x 610 x 638]	PDF	SCE-30P24	\$67.00
SCE-30EL3008LP	SCE-30EL3008LPLG	\$355.00	30.00 x 30.00 x 9.10 [762 x 762 x 231]	PDF	SCE-30P30	\$89.00
SCE-30EL3010LP	SCE-30EL3010LPLG	\$395.00	30.00 x 30.00 x 11.10 [762 x 762 x 282]	PDF	SCE-30P30	\$89.00
SCE-30EL3012LP	SCE-30EL3012LPLG	\$407.00	30.00 x 30.00 x 13.10 [762 x 762 x 333]	PDF	SCE-30P30	\$89.00
SCE-30EL3608LP	SCE-30EL3608LPLG	\$392.00	30.00 x 36.00 x 9.10 [762 x 914 x 231]	PDF	SCE-36P30	\$108.00
SCE-36EL2408LP	SCE-36EL2408LPLG	\$349.00	36.00 x 24.00 x 9.10 [914 x 610 x 231]	PDF	SCE-36P24	\$81.00
SCE-36EL2410LP	SCE-36EL2410LPLG	\$379.00	36.00 x 24.00 x 11.10 [914 x 610 x 282]	PDF	SCE-36P24	\$81.00
SCE-36EL2412LP	SCE-36EL2412LPLG	\$389.00	36.00 x 24.00 x 13.10 [914 x 610 x 333]	PDF	SCE-36P24	\$81.00
SCE-36EL2416LP	SCE-36EL2416LPLG	\$402.00	36.00 x 24.00 x 17.10 [914 x 610 x 434]	PDF	SCE-36P24	\$81.00
SCE-36EL3008LP	SCE-36EL3008LPLG	\$392.00	36.00 x 30.00 x 9.10 [914 x 762 x 231]	PDF	SCE-36P30	\$108.00
SCE-36EL3010LP	SCE-36EL3010LPLG	\$418.00	36.00 x 30.00 x 11.10 [914 x 762 x 282]	PDF	SCE-36P30	\$108.00
SCE-36EL3012LP	SCE-36EL3012LPLG	\$435.00	36.00 x 30.00 x 13.10 [914 x 762 x 333]	PDF	SCE-36P30	\$108.00
SCE-36EL3016LP	SCE-36EL3016LPLG	\$479.00	36.00 x 30.00 x 17.10 [914 x 762 x 434]	PDF	SCE-36P30	\$108.00
SCE-36EL3020LP	SCE-36EL3020LPLG	\$521.00	36.00 x 30.00 x 21.10 [914 x 762 x 536]	PDF	SCE-36P30	\$108.00
SCE-36EL3608LP	SCE-36EL3608LPLG	\$435.00	36.00 x 36.00 x 9.10 [914 x 914 x 231]	PDF	SCE-36P36	\$126.00
SCE-36EL3610LP	SCE-36EL3610LPLG	\$470.00	36.00 x 36.00 x 11.10 [914 x 914 x 282]	PDF	SCE-36P36	\$126.00
SCE-36EL3612LP	SCE-36EL3612LPLG	\$482.00	36.00 x 36.00 x 13.10 [914 x 914 x 333]	PDF	SCE-36P36	\$126.00
SCE-36EL3616LP	SCE-36EL3616LPLG	\$530.00	36.00 x 36.00 x 17.10 [914 x 914 x 434]	PDF	SCE-36P36	\$126.00
SCE-40EL2412LP	SCE-40EL2412LPLG	\$411.00	40.00 x 24.00 x 13.10 [1016 x 610 x 333]	PDF	SCE-40P24	\$91.00
SCE-42EL2410LP	SCE-42EL2410LPLG	\$440.00	42.00 x 24.00 x 11.10 [1067 x 610 x 282]	PDF	SCE-42P24	\$97.00
SCE-42EL3008LP	SCE-42EL3008LPLG	\$431.00	42.00 x 30.00 x 9.10 [1067 x 762 x 231]	PDF	SCE-42P30	\$124.00
SCE-42EL3010LP	SCE-42EL3010LPLG	\$453.00	42.00 x 30.00 x 11.10 [1067 x 762 x 282]	PDF	SCE-42P30	\$124.00
SCE-42EL3012LP	SCE-42EL3012LPLG	\$478.00	42.00 x 30.00 x 13.10 [1067 x 762 x 333]	PDF	SCE-42P30	\$124.00
SCE-42EL3016LP	SCE-42EL3016LPLG	\$508.00	42.00 x 30.00 x 17.10 [1067 x 762 x 434]	PDF	SCE-42P30	\$124.00
SCE-42EL3608LP	SCE-42EL3608LPLG	\$480.00	42.00 x 36.00 x 9.10 [1067 x 914 x 231]	PDF	SCE-42P36	\$145.00
SCE-42EL3610LP	SCE-42EL3610LPLG	\$504.00	42.00 x 36.00 x 11.10 [1067 x 914 x 282]	PDF	SCE-42P36	\$145.00
SCE-42EL3612LP	SCE-42EL3612LPLG	\$530.00	42.00 x 36.00 x 13.10 [1067 x 914 x 333]	PDF	SCE-42P36	\$145.00
SCE-42EL3616LP	SCE-42EL3616LPLG	\$582.00	42.00 x 36.00 x 17.10 [1067 x 914 x 434]	PDF	SCE-42P36	\$145.00
SCE-48EL2408LP	SCE-48EL2408LPLG	\$413.00	48.00 x 24.00 x 9.10 [1219 x 610 x 231]	PDF	SCE-48P24	\$105.00
SCE-48EL2412LP	SCE-48EL2412LPLG	\$459.00	48.00 x 24.00 x 13.10 [1219 x 610 x 333]	PDF	SCE-48P24	\$105.00
SCE-48EL3008LP	SCE-48EL3008LPLG	\$479.00	48.00 x 30.00 x 9.10 [1219 x 762 x 231]	PDF	SCE-48P30	\$137.00
SCE-48EL3010LP	SCE-48EL3010LPLG	\$493.00	48.00 x 30.00 x 11.10 [1219 x 762 x 282]	PDF	SCE-48P30	\$137.00
SCE-48EL3012LP	-	-	48.00 x 30.00 x 13.10 [1219 x 762 x 333]	PDF	SCE-48P30	\$137.00
SCE-48EL3016LP	SCE-48EL3016LPLG	\$552.00	48.00 x 30.00 x 17.10 [1219 x 762 x 434]	PDF	SCE-48P30	\$137.00
SCE-48EL3608LP	SCE-48EL3608LPLG	\$521.00	48.00 x 36.00 x 9.10 [1219 x 914 x 231]	PDF	SCE-48P36	\$164.00
SCE-48EL3610LP	SCE-48EL3610LPLG	\$551.00	48.00 x 36.00 x 11.10 [1219 x 914 x 282]	PDF	SCE-48P36	\$164.00
SCE-48EL3612LP	SCE-48EL3612LPLG	\$577.00	48.00 x 36.00 x 13.10 [1219 x 914 x 333]	PDF	SCE-48P36	\$164.00

Note: Dimensions in inches [millimeters].

Enviroline Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



Your Enclosure Source®

Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

Enviroline Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount

ANSI 61 Gray	RAL 7035 Gray	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-48EL3616LP	SCE-48EL3616LPLG	\$632.00	48.00 x 36.00 x 17.10 [1219 x 914 x 434]	PDF	SCE-48P36	\$164.00
SCE-48EL3620LP	SCE-48EL3620LPLG	\$688.00	48.00 x 36.00 x 21.10 [1219 x 914 x 536]	PDF	SCE-48P36	\$164.00
SCE-60EL2412LP	SCE-60EL2412LPLG	\$530.00	60.00 x 24.00 x 13.10 [1524 x 610 x 333]	PDF	SCE-60P24	\$137.00
SCE-60EL3608LP	SCE-60EL3608LPLG	\$624.00	60.00 x 36.00 x 9.10 [1524 x 914 x 231]	PDF	SCE-60P36	\$202.00
SCE-60EL3610LP	SCE-60EL3610LPLG	\$642.00	60.00 x 36.00 x 11.10 [1524 x 914 x 282]	PDF	SCE-60P36	\$202.00
SCE-60EL3612LP	SCE-60EL3612LPLG	\$671.00	60.00 x 36.00 x 13.10 [1524 x 914 x 333]	PDF	SCE-60P36	\$202.00
SCE-60EL3616LP	SCE-60EL3616LPLG	\$735.00	60.00 x 36.00 x 17.10 [1524 x 914 x 434]	PDF	SCE-60P36	\$202.00
SCE-60EL3620LP	SCE-60EL3620LPLG	\$800.00	60.00 x 36.00 x 21.10 [1524 x 914 x 536]	PDF	SCE-60P36	\$202.00
SCE-60EL3624LP	SCE-60EL3624LPLG	\$1,084.00	60.00 x 36.00 x 25.10 [1524 x 914 x 638]	PDF	SCE-60P36	\$202.00
SCE-72EL3012LP	SCE-72EL3012LPLG	\$720.00	72.00 x 30.00 x 13.10 [1829 x 762 x 333]	PDF	SCE-72P30	\$223.00
SCE-72EL3016LP	SCE-72EL3016LPLG	\$823.00	72.00 x 30.00 x 17.10 [1829 x 762 x 434]	PDF	SCE-72P30	\$223.00
SCE-72EL3024LP	SCE-72EL3024LPLG	\$904.00	72.00 x 30.00 x 25.10 [1829 x 762 x 638]	PDF	SCE-72P30	\$223.00
SCE-72EL3612LP	SCE-72EL3612LPLG	\$768.00	72.00 x 36.00 x 13.10 [1829 x 914 x 333]	PDF	SCE-72P36	\$239.00
SCE-72EL3616LP	SCE-72EL3616LPLG	\$875.00	72.00 x 36.00 x 17.10 [1829 x 914 x 434]	PDF	SCE-72P36	\$239.00
SCE-72EL3624LP	SCE-72EL3624LPLG	\$1,191.00	72.00 x 36.00 x 25.10 [1829 x 914 x 638]	PDF	SCE-72P36	\$239.00

Note: Dimensions in inches [millimeters].