

Small RHC Series NEMA 3R Hinge-Cover Wall Mount



Applications

Designed for use as wiring boxes and junction boxes, this model provides protection against rain, sleet and snow in outdoor installations, or against dripping water indoors.

Construction

- Bodies and doors fabricated from 16 gauge carbon steel
 - Continuous hinge
 - Lid is supplied with a padlockable draw latch
 - Hinge is made of carbon steel with a stainless steel hinge pin
 - Standard size enclosures provided with knockouts in bottom
 - Weldnuts provided for mounting optional back panels
 - External mounting plates, top and bottom of enclosure
 - Grounding provisions provided
- *Subpanels must be ordered separately.

Finish

- ANSI-61 gray polyester powder inside and out over phosphatized surfaces
- Optional back panels are white polyester powder over phosphatized surfaces

Listings


- UL 50, Types 1 & 3R
- UL File E6924
- CSA Certified, Type 1 & 3R CSA File LL66078
- NEMA/EEMAC Type 1 & 3R

Enclosure Shipping Schedule		
Same day	1 - 7 days	1 -10 days
Color indicates shipping lead time in business days.		


Part Number	Price	Body/Door PriceSteel Gauge	Enclosure Size HxWxD	Knockout Pattern	Subpanel Part Number	Price	Subpanel Size A&B	C	E
RHC060604	<--->	16/16	6.06x6.00x4.13 (154x152x105)	G-F-G	N1P0606	<--->	4.25x4.25 (108x108)	8 (203)	7 (178)
RHC060804	<--->	16/16	8.06x6.00x4.13 (205x152x105)	G-F-G	N1P0608	<--->	6.25x4.25 (159x108)	10 (254)	9 (229)
RHC080804	<--->	16/16	8.06x8.00x4.13 (205x203x105)	G-F-G	N1P0808	<--->	6.25x6.25 (159x159)	10 (254)	9 (229)
RHC080806	<--->	16/16	8.06x8.00x6.13 (205x203x156)	G-F-G	N1P0808	<--->	6.25x6.25 (159x159)	10 (254)	9 (229)
RHC081006	<--->	16/16	10.06x8.00x6.13 (256x203x156)	G-F-G	N1P0810	<--->	8.25x6.25 (210x159)	12 (305)	11 (279)
RHC101206	<--->	16/16	12.06x10.00x6.13 (306x254x156)	G-F-G	N1P1012	<--->	10.25x8.25 (260x210)	14 (356)	13 (330)
RHC121206	<--->	16/16	12.06x12.00x6.13 (306x305x156)	F-G-H-I-G	N1P1212	<--->	10.25x10.25 (260x260)	14 (356)	13 (330)

Note: Dimensions in inches (millimeters); letters in table correspond to letters on dimensional drawings.

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.
No partial CSA orders accepted

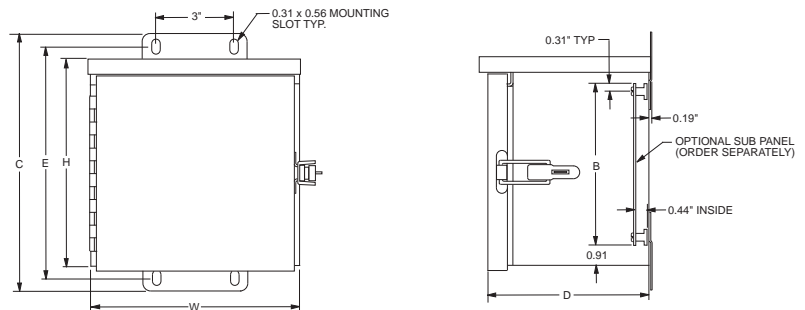

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	<--->
Field grounding kit includes necessary parts to properly ground enclosure		

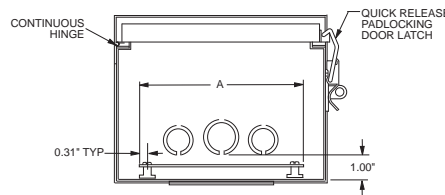

KNOCKOUT PATTERN (PATTERNS ARE CENTERED IN WIDTH)

