

NEMA 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 1-Point Handle (Ultimate Series)



Construction

- Bodies and doors fabricated from 14 gauge type 304 or 316L stainless steel
- Print pocket is provided
- Doors are sealed with poured-in-place polyurethane gasket
- Concealed hinges
- Increased tub openings to accommodate larger size [optional] subpanels
- Collar studs for mounting optional subpanels
- Grounding provisions provided
- Optional subpanels must be ordered separately
- Swing-out panel kits WAJCDFK and WANADFK will not work with these enclosures.
- Doors are interchangeable and easily removable [open to 90° to remove door]
- 1-point 316L stainless steel padlocking handle
- Mounting holes in rear of enclosure
- Optional N412MFKSS mounting foot kit required to maintain the NEMA Types 4X, 12 and 13 ratings]. Mounting foot kit must be ordered separately.
- **Uses WAL3 SS series handles**

Finish

- All exterior surfaces have a smooth grained finish
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized and stainless subpanels are a conductive finish [unpainted]

Listings

- UL 508, Types 4X, 12, and 13 [UL file E64791]
- CSA Certified, Types 12 and 13 [CSA file LL66078]
- Meets NEMA/EEMAC Types 4x, 12, and 13 requirements
- Wall mounting brackets required to maintain UL/CSA external mounting requirements.



FOR CURRENT LISTINGS,
PLEASE SEE WWW.AUTOMATIONDIRECT.COM

Application

The Hubbell/Wiegmann N412-SS stainless steel series, with its streamlined design, is a perfect fit for mounting electrical or high-tech electronic equipment in a variety of indoor and outdoor settings. It is typically used in the following areas where corrosion-resistant protection is needed: food processing plants, pharmaceutical manufacturing facilities, petrochemical plants, pulp and paper processing, and waste water treatment facilities.

Enclosure Shipping Schedule

Same day	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.

NEMA 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 1-Point Handle (Ultimate Series)


304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	C	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Swing-Out Panel
N412121206SS1PTC	\$627.00	N412121206SSA1PTC	\$826.00	12.00 x 12.00 x 6.92 [305 x 305 x 176]	6 [152]	NP1212C	-	NP1212CG	HFWNSP1212C
N412161206SS1PTC	\$675.00	N412161206SSA1PTC	\$863.00	16.00 x 12.00 x 6.92 [406 x 305 x 176]	6 [152]	NP1612C	NP1612SSC	NP1612CG	HFWNSP1612C
N412161208SS1PTC	\$704.00	N412161208SSA1PTC	\$993.00	16.00 x 12.00 x 8.92 [406 x 305 x 227]	8 [203]	NP1612C	NP1612SSC	NP1612CG	HFWNSP1612C
N412161606SS1PTC	\$733.00	N412161606SSA1PTC	\$1,021.00	16.00 x 16.00 x 6.92 [406 x 406 x 176]	8 [203]	NP1616C	NP1616SSC	NP1616CG	HFWNSP1616C
N412161608SS1PTC	\$782.00	N412161608SSA1PTC	\$1,178.00	16.00 x 16.00 x 8.92 [406 x 406 x 227]	8 [203]	NP1616C	NP1616SSC	NP1616CG	HFWNSP1616C
N412162008SS1PTC	\$858.00	N412162008SSA1PTC	\$1,087.00	16.00 x 20.00 x 8.92 [406 x 508 x 227]	8 [203]	NP2016C	NP2016SSC	NP2016CG	HFWNSP1620C
N412201606SS1PTC	\$810.00	N412201606SSA1PTC	\$964.00	20.00 x 16.00 x 6.92 [508 x 406 x 176]	10 [254]	NP2016C	NP2016SSC	NP2016CG	HFWNSP2016C
N412201608SS1PTC	\$839.00	N412201608SSA1PTC	\$1,087.00	20.00 x 16.00 x 8.92 [508 x 406 x 227]	10 [254]	NP2016C	NP2016SSC	NP2016CG	HFWNSP2016C
N412202006SS1PTC	\$880.00	N412202006SSA1PTC	\$1,020.00	20.00 x 20.00 x 6.92 [508 x 508 x 176]	10 [254]	NP2020C	NP2020SSC	NP2020CG	HFWNSP2020C
N412202008SS1PTC	\$912.00	N412202008SSA1PTC	\$1,244.00	20.00 x 20.00 x 8.92 [508 x 508 x 227]	10 [254]	NP2020C	NP2020SSC	NP2020CG	HFWNSP2020C
N412202012SS1PTC	\$1,021.00	N412202012SSA1PTC	\$1,447.00	20.00 x 20.00 x 12.92 [508 x 508 x 328]	10 [254]	NP2020C	NP2020SSC	NP2020CG	HFWNSP2020C

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

NEMA 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 1-Point Handle (Ultimate Series)

Dimensions

in [mm]

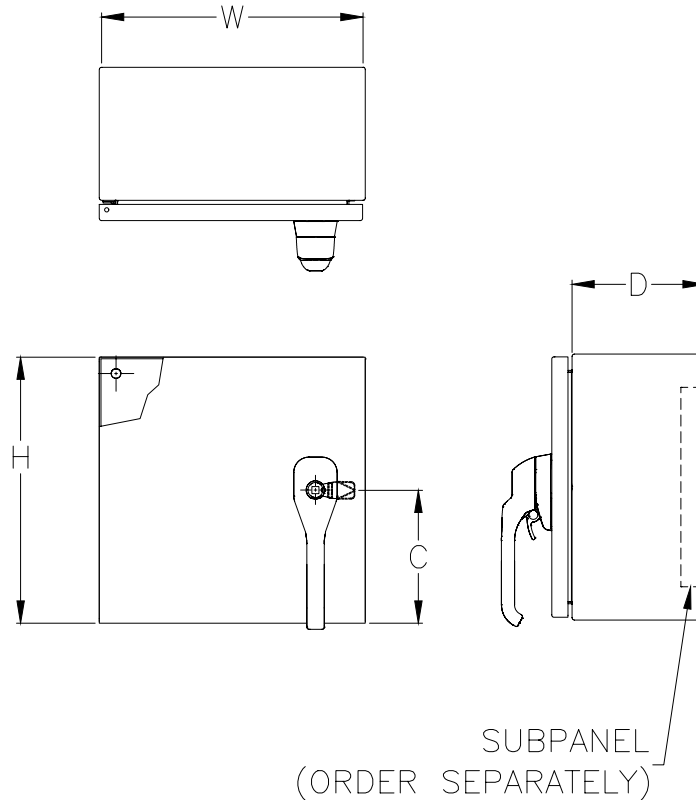

NOTE:

1. LARGE PRINT POCKET [8x10] IS FURNISHED IF $H=20''$ OR MORE AND $W=20''$ OR MORE. OTHERWISE SMALL [6x6] PRINT POCKET IS PROVIDED.

2. TWO HINGES PROVIDED WHEN $H=36''$. THREE HINGES PROVIDED WHEN $H=36''$ OR GREATER. FOUR HINGES PROVIDED WHEN $H=48''$ OR GREATER.

See our website: www.AutomationDirect.com for complete engineering drawings.

Enclosure Subpanels




Subpanels for Ultimate Series Wall Mount Enclosures


- 12 gauge steel
- Subpanels with dimensions 30" x 30" and larger are flanged on all sides. Smaller subpanels are flanged on two sides
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)

Panels listed fit all styles of N412 Ultimate Series wall mount enclosures, including slope top and disconnect enclosures.

NOTE: NPxxxxC subpanels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Subpanel NP1212C will not fit enclosures N412121206 or N412121206SS.

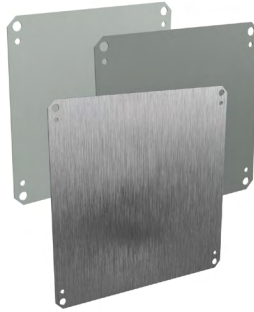

Dimensions in [mm]

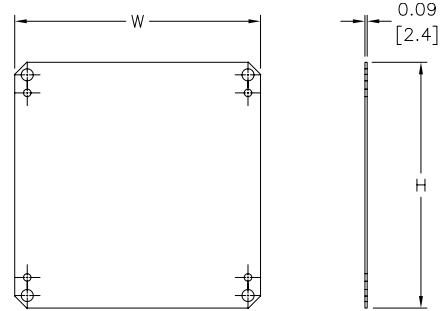


Enclosure Shipping Schedule				
Same day	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Subpanels for Ultimate Series Wall Mount Enclosures							
Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size AxB
NP1212C	\$16.50	NP1212CG	\$16.50	—		12 x 12	10.20 x 10.20 [259 x 259]
NP1612C	\$20.00	NP1612CG	\$20.00	NP1612SSC	\$103.00	16 x 12	14.20 x 10.20 [361 x 259]
NP1616C	\$26.50	NP1616CG	\$26.50	NP1616SSC	\$71.00	16 x 16	14.20 x 14.20 [361 x 361]
NP2016C	\$26.50	NP2016CG	\$26.50	NP2016SSC	\$71.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
NP2020C	\$33.50	NP2020CG	\$33.50	NP2020SSC	\$94.00	20 x 20	18.20 x 18.20 [462 x 462]
NP2416C	\$37.50	NP2416CG	\$37.50	NP2416SSC	\$107.00	24 x 16	22.20 x 14.20 [564 x 361]
NP2420C	\$45.50	NP2420CG	\$45.50	NP2420SSC	\$121.00	24 x 20	22.20 x 18.20 [564 x 462]
NP2424C	\$48.00	NP2424CG	\$48.00	NP2424SSC	\$130.00	24 x 24	22.20 x 22.20 [564 x 564]
NP3020C	\$60.00	NP3020CG	\$60.00	—		30 x 20	28.20 x 18.20 [716 x 462]
NP3024C	\$57.00	NP3024CG	\$57.00	NP3024SSC	\$157.00	30 x 24	28.20 x 22.20 [716 x 564]
NP3030C	\$98.00	NP3030CG	\$98.00	NP3030SSC	\$280.00	30 x 30	28.20 x 28.20 [716 x 716]
NP3624C	\$76.00	NP3624CG	\$76.00	NP3624SSC	\$216.00	36 x 24	34.20 x 22.20 [869 x 564]
NP3630C	\$100.00	NP3630CG	\$100.00	NP3630SSC	\$267.00	36 x 30	34.20 x 28.20 [869 x 716]
NP3636C	\$119.00	NP3636CG	\$119.00	NP3636SSC	\$323.00	36 x 36	34.20 x 34.20 [869 x 869]
NP4024C	\$100.00	NP4024CG	\$100.00	—		40 x 24	38.20 x 22.20 [970 x 564]
NP4230C	\$128.00	—		—		42 x 32	40.20 x 28.20 [1021 x 716]
NP4236C	\$150.00	NP4236CG	\$150.00	NP4236SSC	\$417.00	42 x 36	40.20 x 34.20 [1021 x 869]
NP4824C	\$109.00	NP4824CG	\$109.00	—		48 x 24	46.20 x 22.20 [1173 x 564]
NP4836C	\$170.00	NP4836CG	\$170.00	NP4836SSC	\$452.00	48 x 36	46.20 x 34.20 [1173 x 869]
NP6036C	\$191.00	NP6036CG	\$191.00	NP6036SSC	\$543.00	60 x 36	58.20 x 34.20 [1478 x 869]

Notes: Dimensions in inches [millimeters].
 Letters in table correspond to letters on dimensional drawing.
 *Disconnect enclosures will be up to 2 inches [51mm] wider than width dimensions in this table.

Swing-Out Panels for Ultimate Series Enclosures

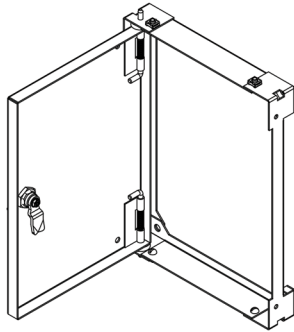

For N412 Ultimate Series Wall Mount Enclosures except N412-1PTC, -3PTC, -SS1PTC, -SS3PTC, -SSA1PTC, and -SSA3PTC

- Maximum swing 107 degrees
- Convenient access to sub enclosure is provided via 1/4 turn pull-tab
- On solid doors, the clearance from the swing panel face to the interior door face is 1-1/4", and 1" on window doors (when the door is closed)
- The kit includes the swing panel, brackets and hardware necessary for a tub flange install. Swing out panels meet Type 1 with enclosure door open
- Painted steel subpanels are painted white polyester powder over phosphated surfaces
- Fabricated from 14 gauge steel
- Mounting hardware is furnished with each panel

Enclosure Shipping Schedule

Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
----------	------------	-------------	-------------	-------------

Color indicates shipping lead time in business days.

Notes: HFWNSPxxxxC swing-out panels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Swing-out panel HFWNSP1212C will not fit enclosures N41212126 or N412121206SS.



Swing-Out Panels for Ultimate Series Enclosures

Part Number	Price	Panel Size CxE	Overall Dimensions HxW	Nominal Enclosure Nominal Size
HFWNSP1212C	\$86.00	9.75 x 9.75 [248 x 248]	10.50 x 10.62 [267 x 270]	12 x 12
HFWNSP1612C	\$90.00	13.75 x 9.75 [349 x 248]	14.50 x 10.62 [368 x 270]	16 x 12
HFWNSP1616C	\$94.00	13.75 x 13.75 [349 x 349]	14.50 x 14.62 [368 x 37]	16 x 16
HFWNSP1620C	\$99.00	13.75 x 17.75 [349 x 451]	14.50 x 18.62 [368 x 473]	16 x 20
HFWNSP2016C	\$99.00	17.75 x 13.75 [451 x 349]	18.50 x 14.62 [470 x 371]	20 x 16
HFWNSP2020C	\$106.00	17.75 x 17.75 [451 x 451]	18.50 x 18.62 [470 x 473]	20 x 20
HFWNSP2024C	\$112.00	17.75 x 21.75 [451 x 552]	18.50 x 22.62 [470 x 575]	20 x 24
HFWNSP2416C	\$105.00	21.75 x 13.75 [552 x 349]	22.50 x 14.62 [572 x 371]	24 x 16
HFWNSP2420C	\$112.00	21.75 x 17.75 [552 x 451]	22.50 x 18.62 [572 x 473]	24 x 20
HFWNSP2424C	\$119.00	21.75 x 21.75 [552 x 552]	22.50 x 22.62 [572 x 575]	24 x 24
HFWNSP3020C	\$121.00	27.75 x 17.75 [705 x 451]	28.50 x 18.62 [724 x 473]	30 x 20
HFWNSP3024C	\$130.00	27.75 x 21.75 [705 x 552]	28.50 x 22.62 [724 x 575]	30 x 24
HFWNSP3030C	\$144.00	27.75 x 27.75 [705 x 705]	28.50 x 28.62 [724 x 727]	30 x 30
HFWNSP3624C	\$141.00	33.75 x 21.75 [857 x 552]	34.50 x 22.62 [876 x 575]	36 x 24
HFWNSP3630C	\$157.00	33.75 x 27.75 [857 x 705]	34.50 x 28.62 [876 x 727]	36 x 30
HFWNSP3636C	\$173.00	33.75 x 33.75 [857 x 857]	34.50 x 34.62 [876 x 879]	36 x 36

Notes: Dimensions in inches [millimeters].
 Letters in table correspond to letters on dimensional drawings.
 If used in a two-door enclosure, a center panel support must be ordered.

Dimensions

in [mm]

See our website: www.AutomationDirect.com for complete engineering drawings.

