

# NEMA 4X, 12 & 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle (Ultimate Series)



## Construction

- Bodies and doors fabricated from 14 or 16 gauge 304 and 316L stainless steel
- Plasma welded seams
- Poured-in-place polyurethane gasket
- Collar studs provided for mounting optional subpanels
- Grounding provisions provided
- Concealed hinges
- Increased tub openings to accommodate larger size [optional] subpanels
- Optional subpanels must be ordered separately
- Swing-out panel kits WAJCDFK and WANADFK will not work with these enclosures
- Doors are interchangeable and easily removable [open to 90° to remove door]
- 3-point 316L stainless steel keylocking/padlocking combo handle
- Mounting holes in rear of enclosure
- Optional N412MFKSS mounting foot kit required to maintain the NEMA Types 4X, 12 and 13 ratings]. Mounting foot kit must be ordered separately

## Finish

- All exterior surfaces have a smooth grained finish
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized and stainless subpanels are a conductive finish [unpainted]

## Listings

- UL 508, Types 4X, 12 and 13 [UL file E64791]
- CSA Certified, Types 12 and 13 [CSA file LL66078]
- Meets NEMA/EEMAC Types 4X, 12 and 13 requirements
- Wall mounting brackets required to maintain UL/CSA external mounting requirements.

## Application

The Hubbell/Wiegmann N412-SS stainless steel series, with its streamlined design, is a perfect fit for mounting electrical or high-tech electronic equipment in a variety of indoor and outdoor settings. It is typically used in the following areas where corrosion-resistant protection is needed: food processing plants, pharmaceutical manufacturing facilities, petrochemical plants, pulp and paper processing, and waste water treatment facilities.



FOR CURRENT LISTINGS,  
PLEASE SEE WWW.AUTOMATIONDIRECT.COM

Enclosure Shipping Schedule		
Same day	1 - 7 days	1 - 10 days
Color indicates shipping lead time in business days.		

NEMA 4X, 12 & 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle (Ultimate Series)								
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel
<b>N412241608SS3PTC</b>	\$888.00	<b>N412241608SSA3PTC</b>	\$1,192.00	24x16x8 [610x406x203]	16	<b>NP2416C</b>	<b>NP2416SSC</b>	<b>NP2416CG</b>
<b>N412242008SS3PTC</b>	\$971.00	<b>N412242008SSA3PTC</b>	\$1,268.00	24x20x8 [610x508x203]	16	<b>NP2420C</b>	<b>NP2420SSC</b>	<b>NP2420CG</b>
<b>N412242408SS3PTC</b>	\$1,076.00	<b>N412242408SSA3PTC</b>	\$1,408.00	24x24x8 [610x610x203]	14	<b>NP2424C</b>	<b>NP2424SSC</b>	<b>NP2424CG</b>
<b>N412242412SS3PTC</b>	\$1,255.00	<b>N412242412SSA3PTC</b>	\$1,672.00	24x24x12 [610x610x305]	14	<b>NP2424C</b>	<b>NP2424SSC</b>	<b>NP2424CG</b>
<b>N412302408SS3PTC</b>	\$1,204.00	<b>N412302408SSA3PTC</b>	\$1,579.00	30x24x8 [762x610x203]	14	<b>NP3024C</b>	<b>NP3024SSC</b>	<b>NP3024CG</b>
<b>N412302412SS3PTC</b>	\$1,357.00	<b>N412302412SSA3PTC</b>	\$1,773.00	30x24x12 [762x610x305]	14	<b>NP3024C</b>	<b>NP3024SSC</b>	<b>NP3024CG</b>
<b>N412303008SS3PTC</b>	\$1,390.00	<b>N412303008SSA3PTC</b>	\$1,889.00	30x30x8 [762x762x203]	14	<b>NP3030C</b>	<b>NP3030SSC</b>	<b>NP3030CG</b>
<b>N412362408SS3PTC</b>	\$1,365.00	<b>N412362408SSA3PTC</b>	\$1,839.00	36x24x8 [914x610x203]	14	<b>NP3624C</b>	<b>NP3624SSC</b>	<b>NP3624CG</b>
<b>N412362412SS3PTC</b>	\$1,474.00	<b>N412362412SSA3PTC</b>	\$1,889.00	36x24x12 [914x610x305]	14	<b>NP3624C</b>	<b>NP3624SSC</b>	<b>NP3624CG</b>
<b>N412363008SS3PTC</b>	\$1,545.00	<b>N412363008SSA3PTC</b>	\$1,988.00	36x30x8 [914x762x203]	14	<b>NP3630C</b>	<b>NP3630SSC</b>	<b>NP3630CG</b>


**Note: Subpanels must be ordered separately. Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.**

# NEMA 4X, 12 & 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle (Ultimate Series)

NEMA 4X, 12 & 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle (Ultimate Series) – [cont.]								
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel
<b>N412363012SS3PTC</b>	\$1,735.00	<b>N412363012SSA3PTC</b>	\$2,222.00	36x30x12 [914x762x305]	14	<b>NP3630C</b>	<b>NP3630SSC</b>	<b>NP3630CG</b>
<b>N412363612SS3PTC</b>	\$1,871.00	<b>N412363612SSA3PTC</b>	\$2,630.00	36x36x12 [914x914x305]	14	<b>NP3636C</b>	<b>NP3636SSC</b>	<b>NP3636CG</b>
<b>N412423612SS3PTC</b>	\$2,061.00	<b>N412423612SSA3PTC</b>	\$2,899.00	42x36x12 [1067x914x305]	14	<b>NP4236C</b>	<b>NP4236SSC</b>	<b>NP4236CG</b>
<b>N412483612SS3PTC</b>	\$2,253.00	<b>N412483612SSA3PTC</b>	\$3,179.00	48x36x12 [1219x914x305]	14	<b>NP4836C</b>	<b>NP4836SSC</b>	<b>NP4836CG</b>
<b>N412603612SS3PTC</b>	\$2,531.00	<b>N412603612SSA3PTC</b>	\$3,727.00	60x36x12 [1524x914x305]	14	<b>NP6036C</b>	<b>NP6036SSC</b>	<b>NP6036CG</b>

**Note:** Subpanels must be ordered separately. Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.

## Dimensions in [mm]

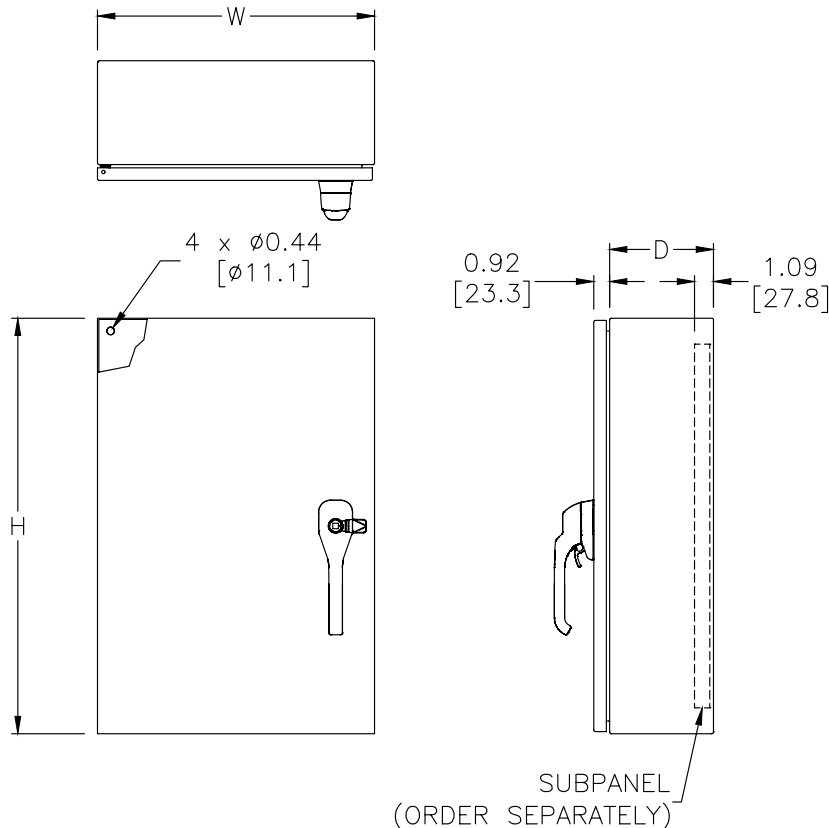

**NOTE:**  
TWO HINGES PROVIDED WHEN H=36". THREE HINGES PROVIDED WHEN H=36" OR GREATER. FOUR HINGES PROVIDED WHEN H=48" OR GREATER.

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Enclosure Subpanels




## Subpanels for Ultimate Series Wall Mount Enclosures

- 12 gauge steel
- Subpanels with dimensions 30" x 30" and larger are flanged on all sides. Smaller subpanels are flanged on two sides
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)



### Dimensions in [mm]

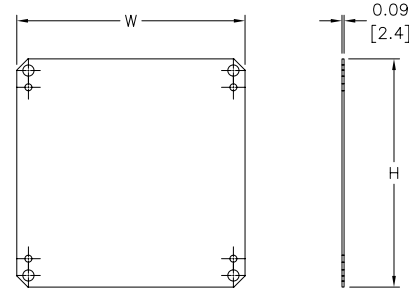

Panels listed fit all styles of N412 Ultimate Series wall mount enclosures, including slope top and disconnect enclosures.


**NOTE:** NPxxxxC subpanels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Subpanel NP1212C will not fit enclosures N412121206 or N412121206SS.

Enclosure Shipping Schedule	
Same day	1 - 7 days
Color indicates shipping lead time in business days.	

Subpanels for Ultimate Series Wall Mount Enclosures							
Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size AxB
NP1212C	\$16.00	NP1212CG	\$16.00	—		12 x 12	10.20 x 10.20 [259 x 259]
NP1612C	\$19.50	NP1612CG	\$19.50	NP1612SSC	\$101.00	16 x 12	14.20 x 10.20 [361 x 259]
NP1616C	\$26.50	NP1616CG	\$26.50	NP1616SSC	\$70.00	16 x 16	14.20 x 14.20 [361 x 361]
NP2016C	\$26.50	NP2016CG	\$26.50	NP2016SSC	\$70.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
NP2020C	\$33.00	NP2020CG	\$33.00	NP2020SSC	\$93.00	20 x 20	18.20 x 18.20 [462 x 462]
NP2416C	\$37.00	NP2416CG	\$37.00	NP2416SSC	\$105.00	24 x 16	22.20 x 14.20 [564 x 361]
NP2420C	\$45.00	NP2420CG	\$45.00	NP2420SSC	\$119.00	24 x 20	22.20 x 18.20 [564 x 462]
NP2424C	\$47.50	NP2424CG	\$47.50	NP2424SSC	\$128.00	24 x 24	22.20 x 22.20 [564 x 564]
NP3020C	\$60.00	NP3020CG	\$60.00	—		30 x 20	28.20 x 18.20 [716 x 462]
NP3024C	\$57.00	NP3024CG	\$57.00	NP3024SSC	\$155.00	30 x 24	28.20 x 22.20 [716 x 564]
NP3030C	\$97.00	NP3030CG	\$97.00	NP3030SSC	\$276.00	30 x 30	28.20 x 28.20 [716 x 716]
NP3624C	\$75.00	NP3624CG	\$75.00	NP3624SSC	\$213.00	36 x 24	34.20 x 22.20 [869 x 564]
NP3630C	\$99.00	NP3630CG	\$99.00	NP3630SSC	\$263.00	36 x 30	34.20 x 28.20 [869 x 716]
NP3636C	\$117.00	NP3636CG	\$117.00	NP3636SSC	\$318.00	36 x 36	34.20 x 34.20 [869 x 869]
NP4024C	\$99.00	NP4024CG	\$99.00	—		40 x 24	38.20 x 22.20 [970 x 564]
NP4230C	\$126.00	—		—		42 x 32	40.20 x 28.20 [1021 x 716]
NP4236C	\$148.00	NP4236CG	\$148.00	NP4236SSC	\$411.00	42 x 36	40.20 x 34.20 [1021 x 869]
NP4824C	\$107.00	NP4824CG	\$107.00	—		48 x 24	46.20 x 22.20 [1173 x 564]
NP4836C	\$168.00	NP4836CG	\$168.00	NP4836SSC	\$446.00	48 x 36	46.20 x 34.20 [1173 x 869]
NP6036C	\$188.00	NP6036CG	\$188.00	NP6036SSC	\$535.00	60 x 36	58.20 x 34.20 [1478 x 869]

**Notes:** Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawing.  
 \*Disconnect enclosures will be up to 2 inches [51mm] wider than width dimensions in this table.

# Swing-Out Panels for Ultimate Series Enclosures

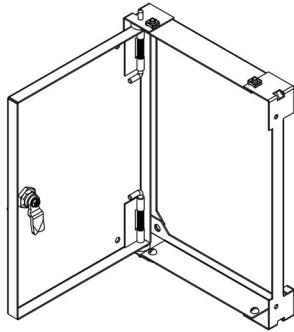

For N412 Ultimate Series Wall Mount Enclosures except N412-1PTC, -3PTC, -SS1PTC, -SS3PTC, -SSA1PTC, and -SSA3PTC

- Maximum swing 107 degrees
- Convenient access to sub enclosure is provided via 1/4 turn pull-tab
- On solid doors, the clearance from the swing panel face to the interior door face is 1-1/4", and 1" on window doors (when the door is closed)
- The kit includes the swing panel, brackets and hardware necessary for a tub flange install. Swing out panels meet Type 1 with enclosure door open
- Painted steel subpanels are painted white polyester powder over phosphated surfaces
- Fabricated from 14 gauge steel
- Mounting hardware is furnished with each panel

Enclosure Shipping Schedule
1 -10 days
Color indicates shipping lead time in business days.

**NOTE:** HFWNSPxxxC swing-out panels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Swing-out panel HFWNSP1212C will not fit enclosures N41212126 or N412121206SS.



Swing-Out Panels for Ultimate Series Enclosures				
Part Number	Price	Panel Size CxE	Overall Dimensions HxW	Nominal Enclosure Nominal Size
HFWNSP1212C	\$85.00	9.75 x 9.75 [248 x 248]	10.50 x 10.62 [267 x 270]	12 x 12
HFWNSP1612C	\$89.00	13.75 x 9.75 [349 x 248]	14.50 x 10.62 [368 x 270]	16 x 12
HFWNSP1616C	\$93.00	13.75 x 13.75 [349 x 349]	14.50 x 14.62 [368 x 37]	16 x 16
HFWNSP1620C	\$98.00	13.75 x 17.75 [349 x 451]	14.50 x 18.62 [368 x 473]	16 x 20
HFWNSP2016C	\$98.00	17.75 x 13.75 [451 x 349]	18.50 x 14.62 [470 x 371]	20 x 16
HFWNSP2020C	\$104.00	17.75 x 17.75 [451 x 451]	18.50 x 18.62 [470 x 473]	20 x 20
HFWNSP2024C	\$110.00	17.75 x 21.75 [451 x 552]	18.50 x 22.62 [470 x 575]	20 x 24
HFWNSP2416C	\$103.00	21.75 x 13.75 [552 x 349]	22.50 x 14.62 [572 x 371]	24 x 16
HFWNSP2420C	\$110.00	21.75 x 17.75 [552 x 451]	22.50 x 18.62 [572 x 473]	24 x 20
HFWNSP2424C	\$117.00	21.75 x 21.75 [552 x 552]	22.50 x 22.62 [572 x 575]	24 x 24
HFWNSP3020C	\$119.00	27.75 x 17.75 [705 x 451]	28.50 x 18.62 [724 x 473]	30 x 20
HFWNSP3024C	\$128.00	27.75 x 21.75 [705 x 552]	28.50 x 22.62 [724 x 575]	30 x 24
HFWNSP3030C	\$141.00	27.75 x 27.75 [705 x 705]	28.50 x 28.62 [724 x 727]	30 x 30
HFWNSP3624C	\$139.00	33.75 x 21.75 [857 x 552]	34.50 x 22.62 [876 x 575]	36 x 24
HFWNSP3630C	\$155.00	33.75 x 27.75 [857 x 705]	34.50 x 28.62 [876 x 727]	36 x 30
HFWNSP3636C	\$171.00	33.75 x 33.75 [857 x 857]	34.50 x 34.62 [876 x 879]	36 x 36

**Notes:** Dimensions in inches [millimeters]. Letters in table correspond to letters on dimensional drawings. If used in a two-door enclosure, a center panel support must be ordered.

## Dimensions

in [mm]

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

