

# Ultimate Series NEMA 4X, 12 & 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle



## Applications

The Wiegmann N412-SS stainless steel series, with its streamlined design, is a perfect fit for mounting electrical or high-tech electronic equipment in a variety of indoor and outdoor settings. It is typically used in the following areas where corrosion-resistant protection is needed: food processing plants, pharmaceutical manufacturing facilities, petrochemical plants, pulp and paper processing, and waste water treatment facilities.



## Construction

- Bodies and doors fabricated from 14 or 16 gauge 304 and 316L stainless steel
- Plasma welded seams
- Poured-in-place polyurethane gasket
- Collar studs provided for mounting optional subpanels
- Grounding provisions provided
- Concealed hinges
- Increased tub openings to accommodate larger size [optional] subpanels
- Optional subpanels must be ordered separately
- Swing-out panel kits WAJCDFK and WANADFK will not work with these enclosures
- Doors are interchangeable and easily removable [open to 90° to remove door]
- 3-point 316L stainless steel padlocking handle
- Mounting holes in rear of enclosure
- Optional N412MFKSS mounting foot kit required to maintain the NEMA Types 4X, 12 and 13 ratings]. Mounting foot kit must be ordered separately
- **Uses WAL3 SS series handles**

## Finish

- All exterior surfaces have a smooth grained finish
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized and stainless subpanels are a conductive finish [unpainted]

## Listings

- UL 508, Types 4X, 12 and 13 [UL file E64791]
- Meets NEMA/EEMAC Types 4X, 12 and 13 requirements
- Wall mounting brackets required to maintain UL/CSA external mounting requirements.



FOR CURRENT LISTINGS, PLEASE SEE [WWW.AUTOMATIONDIRECT.COM](http://WWW.AUTOMATIONDIRECT.COM)

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.					

Ultimate Series NEMA 4X, 12 & 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle								
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel
N412241608SS3PTC	\$1,050.00	N412241608SSA3PTC	\$1,409.00	24.00 x 16.00 x 8.92 [610 x 406 x 227]	16	NP2416C	NP2416SSC	NP2416CG
N412242008SS3PTC	\$1,148.00	N412242008SSA3PTC	\$1,499.00	24.00 x 20.00 x 8.92 [610 x 508 x 227]	16	NP2420C	NP2420SSC	NP2420CG
N412242408SS3PTC	\$1,247.00	N412242408SSA3PTC	\$1,632.00	24.00 x 24.00 x 8.92 [610 x 610 x 227]	14	NP2424C	NP2424SSC	NP2424CG
N412242412SS3PTC	\$1,455.00	N412242412SSA3PTC	\$1,938.00	24.00 x 24.00 x 12.92 [610 x 610 x 328]	14	NP2424C	NP2424SSC	NP2424CG
N412302408SS3PTC	\$1,396.00	N412302408SSA3PTC	\$1,831.00	30.00 x 24.00 x 8.92 [762 x 610 x 227]	14	NP3024C	NP3024SSC	NP3024CG
N412302412SS3PTC	\$1,574.00	N412302412SSA3PTC	\$2,056.00	30.00 x 24.00 x 12.92 [762 x 610 x 328]	14	NP3024C	NP3024SSC	NP3024CG
N412303008SS3PTC	\$1,612.00	N412303008SSA3PTC	\$2,190.00	30.00 x 30.00 x 8.92 [762 x 762 x 227]	14	NP3030C	NP3030SSC	NP3030CG
N412362408SS3PTC	\$1,583.00	N412362408SSA3PTC	\$2,133.00	36.00 x 24.00 x 8.92 [914 x 610 x 227]	14	NP3624C	NP3624SSC	NP3624CG
N412362412SS3PTC	\$1,709.00	N412362412SSA3PTC	\$2,190.00	36.00 x 24.00 x 12.92 [914 x 610 x 328]	14	NP3624C	NP3624SSC	NP3624CG

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters]  
Letters in table correspond to letters on dimensional drawings.

# Ultimate Series NEMA 4X, 12 & 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle




Enclosure Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days
Color indicates shipping lead time in business days.				

Ultimate Series NEMA 4X, 12 & 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle – [cont.]								
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel
<b>N412363008SS3PTC</b>	\$1,792.00	<b>N412363008SSA3PTC</b>	\$2,305.00	36.00 x 30.00 x 8.92 [914 x 762 x 227]	14	<b>NP3630C</b>	<b>NP3630SSC</b>	<b>NP3630CG</b>
<b>N412363012SS3PTC</b>	\$2,012.00	<b>N412363012SSA3PTC</b>	\$2,577.00	36.00 x 30.00 x 12.92 [914 x 762 x 328]	14	<b>NP3630C</b>	<b>NP3630SSC</b>	<b>NP3630CG</b>
<b>N412363612SS3PTC</b>	\$2,170.00	<b>N412363612SSA3PTC</b>	\$3,050.00	36.00 x 36.00 x 12.92 [914 x 914 x 328]	14	<b>NP3636C</b>	<b>NP3636SSC</b>	<b>NP3636CG</b>
<b>N412423612SS3PTC</b>	\$2,390.00	<b>N412423612SSA3PTC</b>	\$3,362.00	42.00 x 36.00 x 12.92 [1067 x 914 x 328]	14	<b>NP4236C</b>	<b>NP4236SSC</b>	<b>NP4236CG</b>
<b>N412483612SS3PTC</b>	\$2,612.00	<b>N412483612SSA3PTC</b>	\$3,686.00	48.00 x 36.00 x 12.92 [1219 x 914 x 328]	14	<b>NP4836C</b>	<b>NP4836SSC</b>	<b>NP4836CG</b>
<b>N412603612SS3PTC</b>	\$2,936.00	<b>N412603612SSA3PTC</b>	\$4,322.00	60.00 x 36.00 x 12.92 [1524 x 914 x 328]	14	<b>NP6036C</b>	<b>NP6036SSC</b>	<b>NP6036CG</b>

*Notes: Subpanels must be ordered separately.  
Dimensions in inches (millimeters)  
Letters in table correspond to letters on dimensional drawings.*

## Dimensions

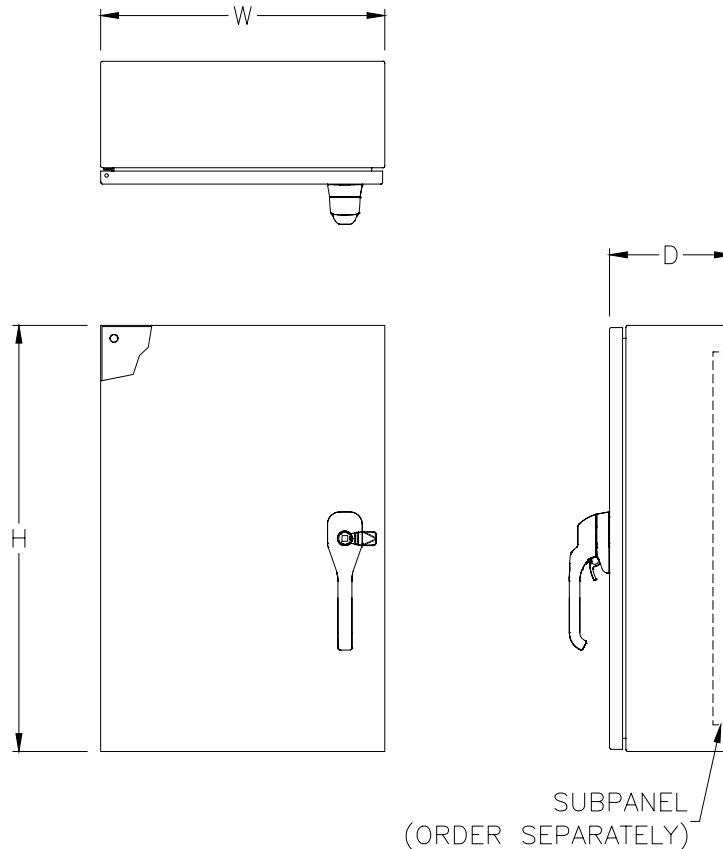

**NOTE:**  
TWO HINGES PROVIDED WHEN H=36". THREE HINGES PROVIDED WHEN H=36" OR GREATER. FOUR HINGES PROVIDED WHEN H=48" OR GREATER.

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Enclosure Subpanels



## Subpanels for Ultimate Series Wall Mount Enclosures


Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Subpanels for Ultimate Series Wall Mount Enclosures							
Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size HxW
NP1212C	\$12.50	NP1212CG	\$10.50	–	–	12 x 12	10.20 x 10.20 [259 x 259]
NP1612C	\$13.50	NP1612CG	\$13.50	NP1612SSC	\$70.00	16 x 12	14.20 x 10.20 [361 x 259]
NP1616C	\$32.50	NP1616CG	\$32.50	NP1616SSC	\$85.00	16 x 16	14.20 x 14.20 [361 x 361]
NP2016C	\$39.00	NP2016CG	\$39.00	NP2016SSC	\$103.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
NP2020C	\$47.00	NP2020CG	\$47.00	NP2020SSC	\$133.00	20 x 20	18.20 x 18.20 [462 x 462]
NP2416C	\$45.00	NP2416CG	\$45.00	NP2416SSC	\$128.00	24 x 16	22.20 x 14.20 [564 x 361]
NP2420C	\$45.00	NP2420CG	\$61.00	NP2420SSC	\$162.00	24 x 20	22.20 x 18.20 [564 x 462]
NP2424C	\$70.00	NP2424CG	\$70.00	NP2424SSC	\$188.00	24 x 24	22.20 x 22.20 [564 x 564]
NP3020C	\$73.00	NP3020CG	\$73.00	–	–	30 x 20	28.20 x 18.20 [716 x 462]
NP3024C	\$84.00	NP3024CG	\$73.00	NP3024SSC	\$228.00	30 x 24	28.20 x 22.20 [716 x 564]
NP3030C	\$119.00	NP3030CG	\$119.00	NP3030SSC	\$337.00	30 x 30	28.20 x 28.20 [716 x 716]
NP3624C	\$101.00	NP3624CG	\$101.00	NP3624SSC	\$288.00	24 x 36 36 x 24	34.20 x 22.20 [869 x 564]
NP3630C	\$135.00	NP3630CG	\$135.00	NP3630SSC	\$357.00	36 x 30	34.20 x 28.20 [869 x 716]
NP3636C	\$158.00	NP3636CG	\$158.00	NP3636SSC	\$431.00	36 x 36	34.20 x 34.20 [869 x 869]
NP4224C	\$116.00	–	–	–	–	24 x 42	40.20  in x 22.20  in [1021 x 564]
NP4024C	\$121.00	NP4024CG	\$121.00	–	–	40 x 24	38.20 x 22.20 [970 x 564]
NP4242C	\$215.00	–	–	–	–	42 x 42	40.20  in x 40.20  in [1021 x 1021]
NP4230C	\$181.00	–	–	–	–	30 x 42 42 x 32	40.20 x 28.20 [1021 x 716]
NP4236C	\$181.00	NP4236CG	\$181.00	NP4236SSC	\$503.00	36 x 42 42 x 36	40.20 x 34.20 [1021 x 869]
NP4824C	\$131.00	NP4824CG	\$131.00	–	–	24 x 48 48 x 24	46.20 x 22.20 [1173 x 564]
NP4830C	\$173.00	–	–	–	–	30 x 48	46.20  in x 28.20  in [1173 x 716]
NP4842C	\$289.00	–	–	–	–	42 x 48	46.20  in x 40.20  in [1173 x 1021]
NP4836C	\$205.00	NP4836CG	\$205.00	NP4836SSC	\$545.00	36 x 48 48 x 36	46.20 x 34.20 [1173 x 869]
NP4848C	\$322.00	–	–	–	–	48 x 48	46.20  in x 46.20  in [1173 x 1173]
NP6030C	\$212.00	–	–	–	–	30 x 60	58.20  in x 28.20  in [1478 x 716]
NP6036C	\$252.00	NP6036CG	\$252.00	NP6036SSC	\$719.00	36 x 30 60 x 36	58.20 x 34.20 [1478 x 869]
NP6042C	\$299.00	–	–	–	–	42 x 60	58.20  in x 40.20  in [1478 x 1021]

Notes: Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawing.  
Disconnect enclosures will be up to 2 inches [51mm] wider than width dimensions in this table.

# Swing-Out Panels for Ultimate Series Enclosures

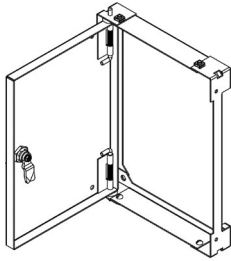

For N412 Ultimate Series Wall Mount Enclosures except N412-1PTC, -3PTC, -SS1PTC, -SS3PTC, -SSA1PTC, and -SSA3PTC

- Maximum swing 107 degrees
- Convenient access to sub enclosure is provided via 1/4 turn pull-tab
- On solid doors, the clearance from the swing panel face to the interior door face is 1-1/4", and 1" on window doors (when the door is closed)
- The kit includes the swing panel, brackets and hardware necessary for a tub flange install. Swing out panels meet Type 1 with enclosure door open
- Painted steel subpanels are painted white polyester powder over phosphated surfaces
- Fabricated from 1/4 gauge steel
- Mounting hardware is furnished with each panel

Notes: HFWNSPxxxxC swing-out panels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Swing-out panel HFWNSP1212C will not fit enclosures N41212126 or N412121206SS.

Enclosure Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.


Swing-Out Panels for Ultimate Series Enclosures				
Part Number	Price	Panel Size CxE	Overall Dimensions HxW	Enclosure Nominal Size
HFWNSP1212C	\$103.00	9.75 x 9.75 [248 x 248]	10.50 x 10.62 [267 x 270]	12 x 12
HFWNSP1612C	\$107.00	13.75 x 9.75 [349 x 248]	14.50 x 10.62 [368 x 270]	16 x 12
HFWNSP1616C	\$113.00	13.75 x 13.75 [349 x 349]	14.50 x 14.62 [368 x 37]	16 x 16
HFWNSP1620C	\$119.00	13.75 x 17.75 [349 x 451]	14.50 x 18.62 [368 x 473]	16 x 20
HFWNSP2016C	\$119.00	17.75 x 13.75 [451 x 349]	18.50 x 14.62 [470 x 371]	20 x 16
HFWNSP2020C	\$126.00	17.75 x 17.75 [451 x 451]	18.50 x 18.62 [470 x 473]	20 x 20
HFWNSP2024C	\$133.00	17.75 x 21.75 [451 x 552]	18.50 x 22.62 [470 x 575]	20 x 24
HFWNSP2416C	\$125.00	21.75 x 13.75 [552 x 349]	22.50 x 14.62 [572 x 371]	24 x 16
HFWNSP2420C	\$133.00	21.75 x 17.75 [552 x 451]	22.50 x 18.62 [572 x 473]	24 x 20
HFWNSP2424C	\$142.00	21.75 x 21.75 [552 x 552]	22.50 x 22.62 [572 x 575]	24 x 24
HFWNSP3020C	\$144.00	27.75 x 17.75 [705 x 451]	28.50 x 18.62 [724 x 473]	30 x 20
HFWNSP3024C	\$155.00	27.75 x 21.75 [705 x 552]	28.50 x 22.62 [724 x 575]	30 x 24
HFWNSP3030C	\$171.00	27.75 x 27.75 [705 x 705]	28.50 x 28.62 [724 x 727]	30 x 30
HFWNSP3624C	\$168.00	33.75 x 21.75 [857 x 552]	34.50 x 22.62 [876 x 575]	36 x 24
HFWNSP3630C	\$187.00	33.75 x 27.75 [857 x 705]	34.50 x 28.62 [876 x 727]	36 x 30
HFWNSP3636C	\$206.00	33.75 x 33.75 [857 x 857]	34.50 x 34.62 [876 x 879]	36 x 36

Notes: Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.  
 If used in a two-door enclosure, a center panel support must be ordered.

## Dimensions

in [mm]

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

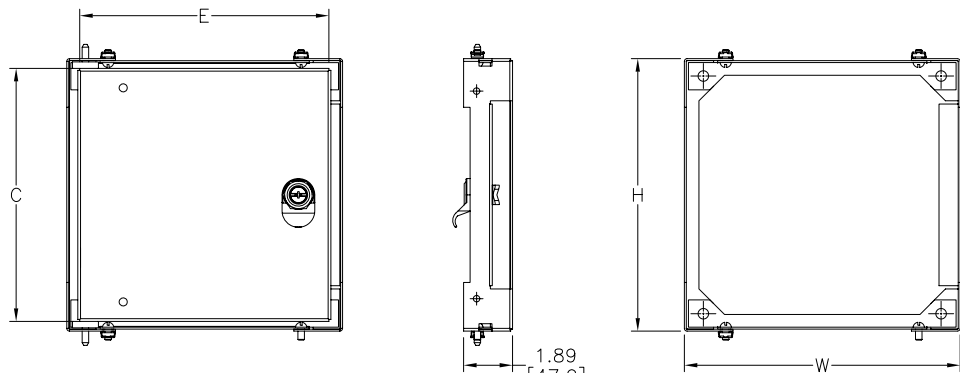

DOOR REMOVED

Enclosure Subpanels tENC-332