



Hose-Proof Hood for Stego Fans




Features

- Stainless steel hood
- Food-safe silicone seal
- Increase of protection class to UL Type 4X
- Easy to clean
- Filter mat change from outside
- Impact-resistant
- Optional security feature to restrict unauthorized access (M6x1 security screw included)
- Weather resistant
- Versatile
- Protective grid
- Mounting screws provided

Standards

- UL 4/4X when used with STEGO Filter Fan Plus and Filter Fans
- UL Recognized File No. E234324
- RoHS 2 compliant
- IP56

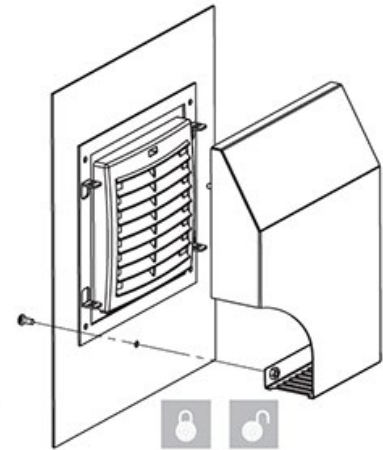


Hose-Proof Hood Locking Mechanism

Applications

- Designed to increase the protection class and serve as a protective cover to filter fans, intake and exit filters.
- Used for protection against water projected by a hose and extreme climatic influences if located outdoors in industrial applications with harsh environmental conditions.
- Hood removes easily for cleaning and filter change without opening the enclosure.

| Hose-Proof Hood for Stego Fans | | | | | | |
|--------------------------------|----------|---|------------------------------|--|---------------------------|-------------|
| Part Number | Price | Stego Filter Fan Plus FPI/FPO Cutout Size | Stego Filter Fan Cutout Size | Dimensions (H x W x D) | Max. Covered Area (X x Y) | Weight (lb) |
| 086700-00 | \$130.00 | 3.62 x 3.62 [92 x 92] | 3.82 x 3.82 [97 x 97] | 8.42 x 7.67 x 1.88 [214 x 195 x 48] | 5.27 x 5.63 [134 x 143] | 1.76 |
| 086710-00 | \$158.00 | 4.88 x 4.88 [124 x 124] | 4.92 x 4.92 [125 x 125] | 11.00 x 8.92 x 2.39 [280 x 226 x 61] | 6.39 x 6.75 [162 x 171] | 2.64 |
| 086720-00 | \$178.00 | 6.93 x 6.93 [176 x 176] | 6.93 x 6.93 [176 x 176] | 14.01 x 11.44 x 2.68 [356 x 291 x 68] | 9.19 x 9.19 [233 x 233] | 4.40 |
| 086730-00 | \$224.00 | 8.78 x 8.78 [223 x 223] | 9.84 x 9.84 [250 x 250] | 16.19 x 14.5 x 3.07 [411 x 388 x 78] | 11.69 x 11.31 [297 x 287] | 6.17 |
| 086740-00 | \$281.00 | 11.46 x 11.46 [291 x 291] | N/A | 18.94 x 15.96 x 4.05 [481 x 405 x 103] | 13.25 x 13.31 [337 x 338] | 8.15 |

Notes: Dimensions in inches [millimeters].
 None of the above models fit 018210-04 and 018210-02 outdoor filter fans.

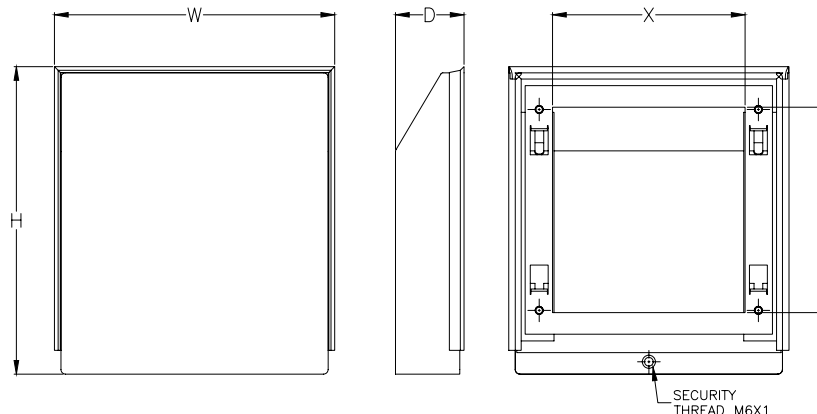

Please see our website www.AutomationDirect.com for complete engineering drawings.