

HAND VALVE



TAC operator
(For P type)




Specification


Model	MVHA-2*, 3*
Bore No.	M5
Port size	M5×0.8
No. of port	2 or 3
No. of position	2
Medium	Air
Operating pressure range	0~0.9 MPa
Effective orifice	1.8 mm ²
Ambient temperature	-5~+60°C (No freezing)
Weight	30 g

Order example

MVHA – 2V

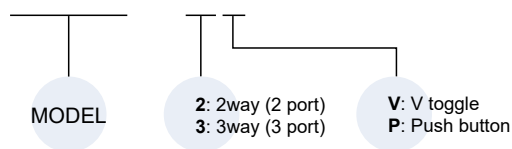

MVHA-2V/3V

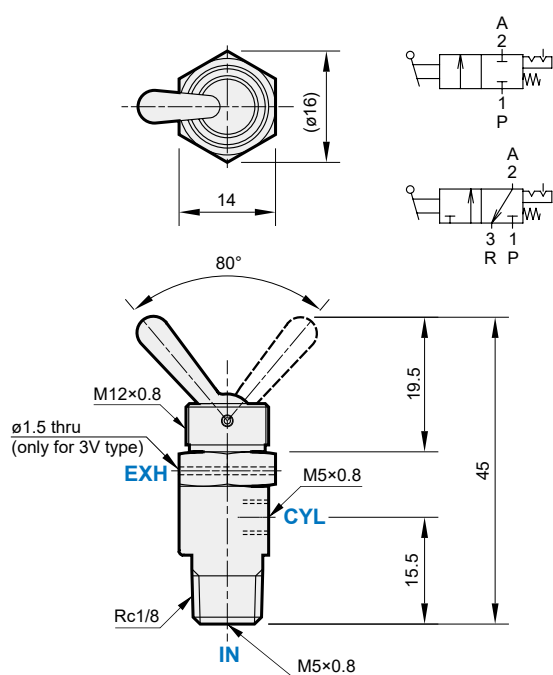

MVHA-2P/3P

