

MVHA-4* series

HAND



TAC operator
(For P* type)



Specification

Model	MVHA-4V	MVHA-4P	MVHA-4PP
Bore No.	M5		
Port size	M5×0.8		
No. of port	5		
No. of position	2		
Medium	Air		
Operating pressure range	0~0.9 MPa		
Effective orifice	1.9 mm ²		
Ambient temperature	-5~+60°C (No freezing)		
Weight	62 g	61 g	66 g

Order example


MVHA — 4V

MODEL


4: 4way (5 port)

V: V toggle
P: Push button
PP: Double push button

MVHA-4V

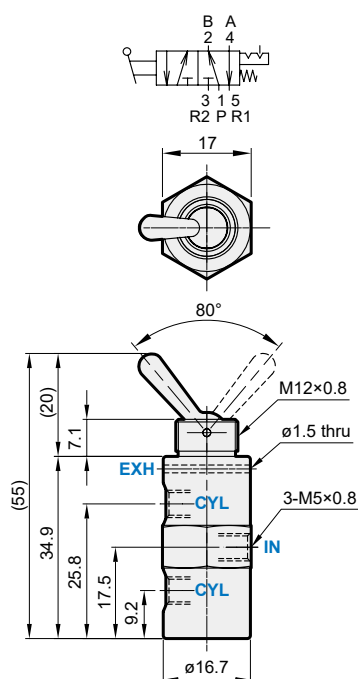

MVHA-4P

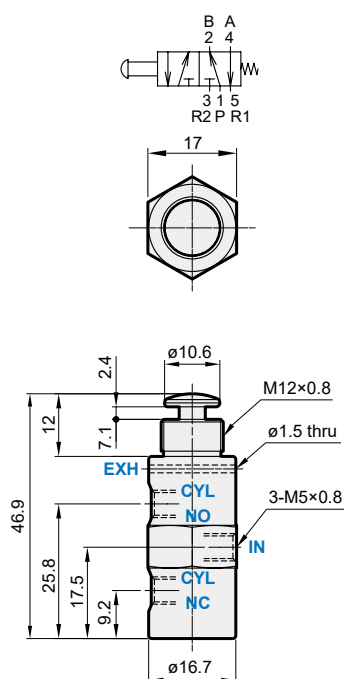

MVHA-4PP

