


# MVHA-41\* series

HAND VALVE

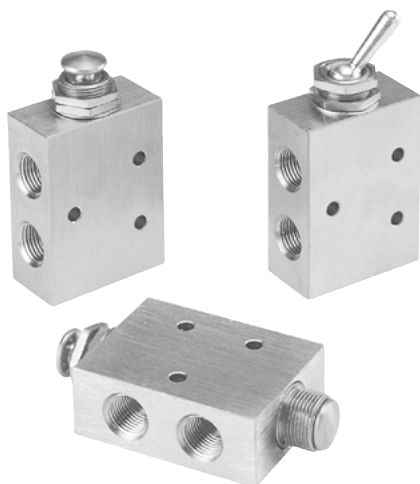

TAC operator  
(For P\* type)



## Specification

| Model                    | MVHA-41V               | MVHA-41P | MVHA-41PP |
|--------------------------|------------------------|----------|-----------|
| Bore No.                 | 6A                     |          |           |
| Port size                | 1/8                    |          |           |
| No. of port              | 5                      |          |           |
| No. of position          | 2                      |          |           |
| Medium                   | Air                    |          |           |
| Operating pressure range | 0~0.9 MPa              |          |           |
| Effective orifice        | 5.5 mm <sup>2</sup>    |          |           |
| Ambient temperature      | -5~+60°C (No freezing) |          |           |
| Weight                   | 64 g                   | 58 g     | 76 g      |

## Order example

**MVHA-41V-G**




MODEL

4: 4way (5 port)



V: V toggle  
P: Push button  
PP: Double push button

PORT THREAD  
Blank: Rc thread  
G: G thread  
NPT: NPT thread

## MVHA-41V

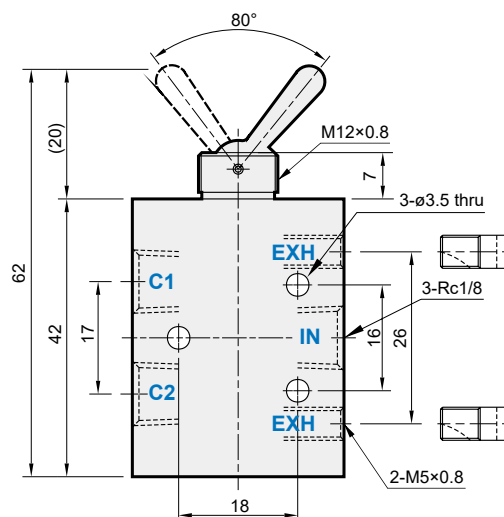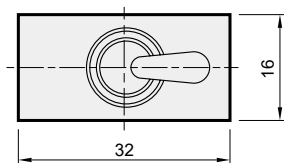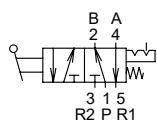

## MVHA-41P

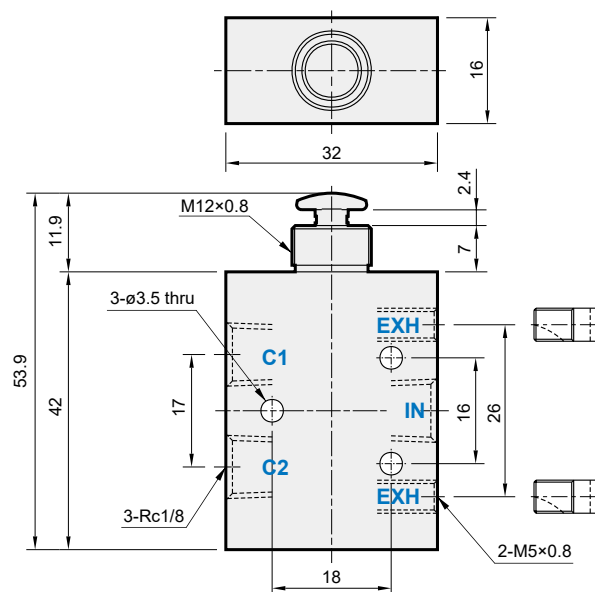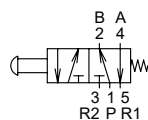

## MVHA-41 PP

