

MVHS series

HAND SLIDE VALVE



Technical data



Caution for safety
(Read before installing)



Specification

Model	MVHS			
Bore No.	8A	10A	15A	20A
Port size	1/4	3/8	1/2	3/4
Medium	Air			
Operating pressure range	0.05~1 MPa			
Effective orifice (mm ²)	P→A	30.4	32.3	63.5
	A→R	34.1	36.8	71.7
Ambient temperature	-5~+60°C (No freezing)			
Weight	40 g	54 g	132 g	148 g

Order example


 
MVHS — 8A — G

MODEL

8A: 1/4
10A: 3/8
15A: 1/2
20A: 3/4

PORT THREAD
Blank: Rc thread
G: G thread
NPT: NPT thread

MVHS-*A

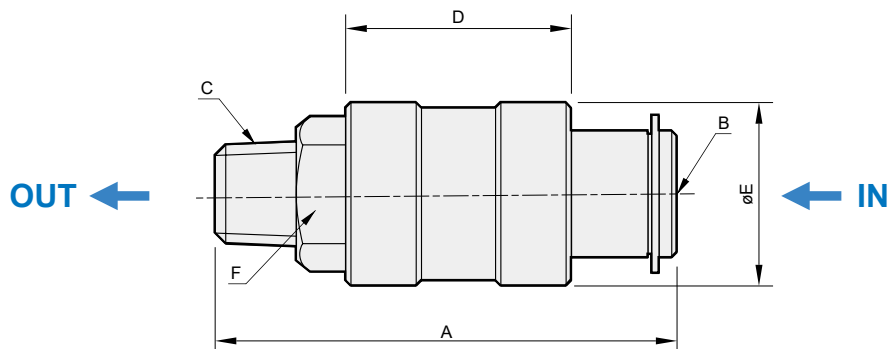

Code Model	A	B	C	D	E	F
MVHS-8A	58	Rc1/4	R1/4	32	25.5	⌀19
MVHS-10A	57	Rc3/8	R3/8	32	31.5	⌀22
MVHS-15A	91	Rc1/2	R1/2	49	38.5	⌀27
MVHS-20A	91	Rc3/4	R3/4	49	42	⌀35