



## Zyklop Speed Ratchet



### Small return angle

The fine 72 tooth ratchet mechanism has a low return angle of 5°. This short stroke allows fast and precise work in small spaces.



### Swivel ratchet head


The ratchet head pivots freely and locks at 0°, 15° and 90°, making it possible to work in confined spaces with ample hand clearance.



### Simple direction change

Rotating the large thumbwheel quickly changes rotation from clockwise to counterclockwise from any position of the ratchet head.

Wera Speed Ratchets		
Part Number	Description	Price
<u><a href="#">05003500055</a></u>	Wera Zyklop Speed ratchet, 1/4 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003500.	
<u><a href="#">05003550055</a></u>	Wera Zyklop Speed ratchet, 3/8 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003550.	
<u><a href="#">05003600055</a></u>	Wera Zyklop Speed ratchet, 1/2 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003600.	

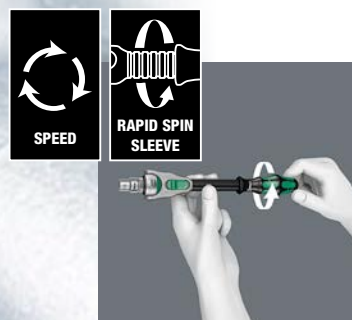

### Unbelievably fast


The gyrating mass design along with the Kraftform handle and free-turning sleeve allow for rapid rotation when used as a screwdriver.



# Zyklop Speed Ratchet and Socket Sets



## 3/8 inch Drive Ratchet Set

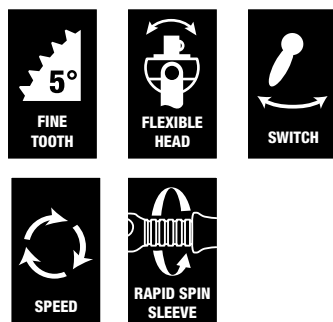

### 3/8 inch Drive Ratchet Sets

Part Number	Description	Price Each
<b>05003594055</b>	Wera driver bit and socket set with Zyklop Speed ratchet, 3/8 inch drive, metric. 43 pieces. Sturdy metal case included. Manufacturer part number 003594.	Retired

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect.



Wera driver bit and socket set with Zyklop Speed ratchet, 3/8 inch drive, SAE, 38 pieces. Includes the pieces listed in the table below.

05003594055 Contents		
	3/8 Zyklop Speed ratchet	
	Sliding T-handle	3/8 x 165
	6-point socket	6 x 29, 7 x 29, 8 x 29, 9 x 29, 10 x 29, 11 x 29, 12 x 29, 13 x 29, 14 x 29, 15 x 29, 16 x 30, 17 x 30, 18 x 30, 19 x 30, 20 x 30, 21 x 30, 22 x 30, 24 x 30
	Wobble extension	3/8 x 76
	Universal joint	3/8 x 50
	Lockable extension	3/8 x 200, 3/8 x 125
	Bit adaptor	1/4 x 3/8 x 44
	Slotted bit	1.0 x 5.5 x 25
	Hex-Plus bit, 25mm long	3, 4, 5, 6, 8, 10
	Phillips bit, 25mm long	PH2, PH3
	Posidriv® bit, 25mm long	PZ2, PZ3
	Torx® bit 25mm long	TX10, TX15, TX20, TX25, TX27, TX30, TX40

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.