

# Optical Signal Devices



## 57/58 mm Panel Mount Beacons

### 57/58 mm Beacon Features

- Available in permanent Incandescent or LED, and Xenon flashing models
- 360° visibility
- For use in 22.5 mm standard control panel holes
- Connection by 6.3mm x 0.8mm spades
- Finger-proof when used with insulated spades
- Changeable bulb for incandescent models not included
- Lock nut and rubber seal included
- 2 year warranty



206, 207 and 208 Series 57/58 mm Beacons Technical Specifications												
Description	Voltage	Part Number	Price	Lamp Color	Current	Starting Current	Operating Temp /Protection	Life Duration	Housing Material	Weight	Connection	Agency Approvals
<b>22.5 mm Panel Mount</b>												
Incandescent Permanent Light	max. 48V	20610000	\$28.50	Red	Depends on bulb selection. (bulb sold separately)	-	-4°F to 122°F [-20°C to 50°C] IP65	Depends on bulb selection. (bulb sold separately)	Polycarbonate cap	39g [1.38 oz]	22.5 mm Panel Mount 6.3 mm spade connector	cULus file E164155, RoHS
		20620000	\$28.50	Green					Polyamide fiberglass Black base			
		20630000	\$28.50	Yellow								
		20640000	\$34.50	Clear								
		20650000	\$34.50	Blue								
LED Permanent Light	24V AC/DC	20710075	\$64.00	Red	< 45mA	≤ 0.5 A	-4°F to 122°F [-20°C to 50°C] IP65	up to 100,000h	Polycarbonate cap	56g [1.98 oz]	22.5 mm Panel Mount 6.3 mm spade connector	cULus file E164155, CE, RoHS
		20720075	\$64.00	Green					Polyamide fiberglass Black base			
		20730075	\$64.00	Yellow								
		20740075	\$107.00	Clear								
		20750075	\$107.00	Blue								
	115VAC	20710067	\$74.00	Red	< 25mA	-	-4°F to 122°F [-20°C to 50°C] IP65	up to 100,000h	Polycarbonate cap	56g [1.98 oz]	6.3 mm spade connector	
		20720067	\$70.00	Green					Polyamide fiberglass Black base			
		20730067	\$70.00	Yellow								
		20740067	\$117.00	Clear								
		20750067	\$117.00	Blue								
Xenon Flashing Light (0.75 Hz flash frequency)	24VDC	20810055	\$98.00	Red	< 100mA	≤ 0.5 A	-4°F to 122°F [-20°C to 50°C] IP65	4 x 10 <sup>6</sup> flashes	Polycarbonate cap	74g [2.61 oz]	22.5 mm Panel Mount 6.3 mm spade connector	cULus file E164155, CE, RoHS
		20820055	\$100.00	Green					Polyamide fiberglass Black base			
		20830055	\$98.00	Yellow								
		20840055	\$100.00	Clear								
		20850055	\$100.00	Blue								
	115VAC	20810067	\$98.00	Red	< 25mA	-	-4°F to 122°F [-20°C to 50°C] IP65	4 x 10 <sup>6</sup> flashes	Polycarbonate cap	74g [2.61 oz]	6.3 mm spade connector	
		20820067	\$100.00	Green					Polyamide fiberglass Black base			
		20830067	\$98.00	Yellow								
		20840067	\$100.00	Clear								
		20850067	\$100.00	Blue								


To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page at [www.AutomationDirect.com](http://www.AutomationDirect.com)

Bulbs for Incandescent Permanent Optical Element					
Part Number	Price	Description	Wattage	Voltage	Life Duration
95584035	\$7.50	Bulb for Incandescent Light BA15d Bayonet Socket	5W	24VDC	up to 5,000h




### Dimensions mm [in]

#### 206 series

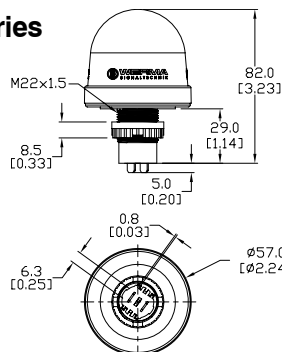

#### 207 and 208 series

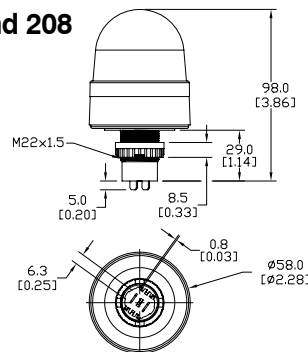

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.