

Optical Signal Devices



57/58 mm Panel Mount Beacons

57/58 mm Beacon Features

- Available in permanent Incandescent or LED, and Xenon flashing models
- 360° visibility
- For use in 22.5 mm standard control panel holes
- Connection by 6.3mm x 0.8mm spades
- Finger-proof when used with insulated spades
- Changeable bulb for incandescent models not included
- Lock nut and rubber seal included
- 2 year warranty



206, 207 and 208 Series 57/58 mm Beacons Technical Specifications												
Description	Voltage	Part Number	Price	Lamp Color	Current	Starting Current	Operating Temp /Protection	Life Duration	Housing Material	Weight	Connection	Agency Approvals
22.5 mm Panel Mount												
Incandescent Permanent Light	max. 48V	20610000	\$28.50	Red	Depends on bulb selection. (bulb sold separately)	-	-4°F to 122°F [-20°C to 50°C] IP65	Depends on bulb selection. (bulb sold separately)	Polycarbonate cap	39g [1.38 oz]	22.5 mm Panel Mount 6.3 mm spade connector	cULus file E164155, RoHS
		20620000	\$28.50	Green					Polyamide fiberglass Black base			
		20630000	\$28.50	Yellow								
		20640000	\$34.00	Clear								
		20650000	\$34.00	Blue								
LED Permanent Light	24V AC/DC	20710075	\$63.50	Red	< 45mA	≤ 0.5 A	-4°F to 122°F [-20°C to 50°C] IP65	up to 100,000h	Polycarbonate cap	56g [1.98 oz]	22.5 mm Panel Mount 6.3 mm spade connector	cULus file E164155, CE, RoHS
		20720075	\$63.50	Green					Polyamide fiberglass Black base			
		20730075	\$63.50	Yellow								
		20740075	\$105.50	Clear								
		20750075	\$105.50	Blue								
	115VAC	20710067	\$73.00	Red	< 25mA	-	-4°F to 122°F [-20°C to 50°C] IP65	up to 100,000h	Polycarbonate cap	56g [1.98 oz]	6.3 mm spade connector	
		20720067	\$69.00	Green					Polyamide fiberglass Black base			
		20730067	\$69.00	Yellow								
		20740067	\$115.00	Clear								
		20750067	\$115.00	Blue								
Xenon Flashing Light (0.75 Hz flash frequency)	24VDC	20810055	\$97.00	Red	< 100mA	≤ 0.5 A	-4°F to 122°F [-20°C to 50°C] IP65	4 x 10 ⁶ flashes	Polycarbonate cap	74g [2.61 oz]	22.5 mm Panel Mount 6.3 mm spade connector	cULus file E164155, CE, RoHS
		20820055	\$99.00	Green					Polyamide fiberglass Black base			
		20830055	\$97.00	Yellow								
		20840055	\$99.00	Clear								
		20850055	\$99.00	Blue								
	115VAC	20810067	\$97.00	Red	< 25mA	-	-4°F to 122°F [-20°C to 50°C] IP65	4 x 10 ⁶ flashes	Polycarbonate cap	74g [2.61 oz]	6.3 mm spade connector	
		20820067	\$99.00	Green					Polyamide fiberglass Black base			
		20830067	\$97.00	Yellow								
		20840067	\$99.00	Clear								
		20850067	\$99.00	Blue								


To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page at www.AutomationDirect.com

Bulbs for Incandescent Permanent Optical Element					
Part Number	Price	Description	Wattage	Voltage	Life Duration
95584035	\$7.25	Bulb for Incandescent Light BA15d Bayonet Socket	5W	24VDC	up to 5,000h




Dimensions mm [in]

206 series

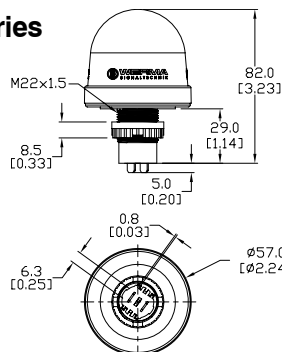

207 and 208 series

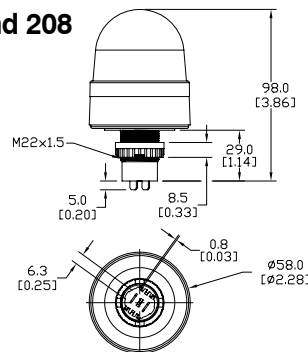

Please see our website www.AutomationDirect.com for complete engineering drawings.