



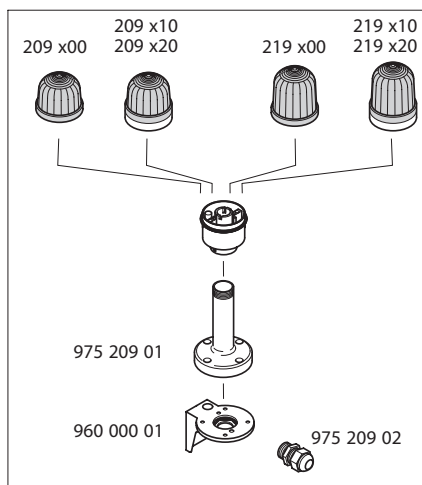

Optical Signal Devices

Beacon Accessories

WERMA Beacons Accessories						
Part Number	Price	Drawing Link	Description	Operating Temp.	Material	Weight
Installation Beacon Accessories						
97581201	\$14.50	PDF	Tube adapter for beacons with 37mm (PG29) mounting installation. Find tube adapter accessories in WERMA Stack light catalog section.	-4 to 122°F [-20 to 50°C]	Polyamide / Fiberglass	1.13 g [0.04 oz]
97581202	\$14.00	PDF	Surface mounting base for beacons with 37mm (PG29) mounting installation		Polyamide / Fiberglass with rubber seal	2.83 g [0.1 oz]
97581503	\$44.00	PDF	Surface mounting enclosure for 1 beacon with 37mm (PG29) mounting installation		Polycarbonate/ ABS blend	8.5 g [0.3 oz]
97581507	\$61.00	PDF	Surface mounting enclosure for 2 beacons with 37mm (PG29) mounting installation			14.17 g [0.5 oz]
97581508	\$80.00	PDF	Surface mounting enclosure for 3 beacons with 37mm (PG29) mounting installation			17g [0.6 oz]
97581522	\$5.75	PDF	Anti-twist washer for beacons with 37mm (PG29) mounting installation		304 Stainless steel	0.57 g [0.02 oz]
Freestanding Beacon Accessories						
96000001	\$17.00	PDF	Bracket for tube mounting - for use with for use with 219 and 209 series industrial signal beacons.	-4 to 122°F [-20 to 50°C]	Polyamide	57g [2.01 oz]
97520901	\$20.50	PDF	Plastic Base with integrated tube for WERMA industrial signal beacons- for use with 209 and 219 series beacons		Polyamide	0.1 lbs [1.6 oz]
97520902	\$5.75	PDF	Cable gland for WERMA industrial signal beacons: M25x1.5, plastic - for use with 209 and 219 series industrial signal beacons		Nylon	0.1 lbs [1.6 oz]
97582603	\$43.00	PDF	Galvanized Wire Guard for WERMA industrial signal beacons - for use with 826, 827, 828 and 829 series industrial signal beacons		Wire D 3mm, chromed	140g [4.93 oz]
97582605	\$10.00	PDF	Plastic Bracket for wall mounting for use with WERMA signal beacons - for use with 826, 827, 828 and 829 series industrial signal beacons		Polycarbonate/ ABS blend	62g [2.19 oz]

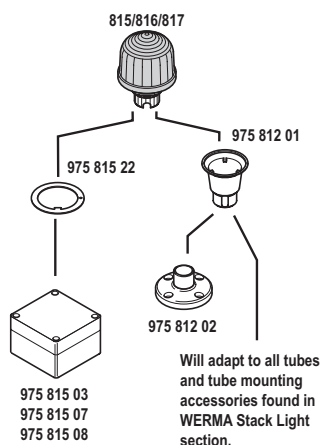

WERMA SIGNALTECHNIK Optical Signal Devices

98mm Base Mount Beacons

Features

- Choose from permanent incandescent, permanent LED, flashing Xenon, EVS (Enhanced Visibility System) flashing LED, and rotating models
- Base mount installation
- 98mm diameter
- Light-intensive Xenon flash in flash models
- Bulb not included with 826 incandescent models
- 25W bulb included with 827 incandescent models
- Various mounting accessories available
- 2-year warranty



826, 827, and 828 Series Beacons Technical Specifications													
Part Number	Price	Color	Drawing link	Description	Voltage	Current	Starting Current	Operating Temp /Protection	Life Duration	Housing Material	Weight g [oz]	Connection	Agency Approvals
74mm Base Mount													
82610000	\$39.50	Red	PDF	Incandescent Permanent Light 98mm	12-240V AC/DC max (depends on bulb selection; bulb sold separately)	Depends on bulb selection. (bulb sold separately)	-				180 [6.35]		
82620000	\$43.00	Green	PDF										
82630000	\$39.50	Yellow	PDF										
82640000	\$43.00	Clear	PDF										
82650000	\$43.00	Blue	PDF										
82710075	\$101.00	Red	PDF	Incandescent Blinking Light (1.5 Hz blinking frequency, 5Ws flash energy) 98mm	24V AC/DC	max. 3.0 A		-4 to 122°F [-20 to 50°C]	Up to 5,000h	Polycarbonate cap Polycarbonate/ABS base	207 [7.30]	Terminal screws Max 2.5 mm ² AWG 16-14 Cable diameter 5-8 mm	cULus file E164155, CE, RoHS
82720075	\$109.00	Green	PDF										
82730075	\$101.00	Yellow	PDF										
82740075	\$109.00	Clear	PDF										
82750075	\$109.00	Blue	PDF										
82710077	\$101.00	Red	PDF		115V AC/DC	max. 500mA	≤ 3.0 A	IP65 when mounted		4,000,000 flashes	220 [7.76]		
82720077	\$109.00	Green	PDF										
82730077	\$101.00	Yellow	PDF										
82740077	\$109.00	Clear	PDF										
82750077	\$109.00	Blue	PDF										
82810055	\$122.00	Red	PDF	Xenon Flashing Light (1Hz flash frequency, 1W flash energy) 98mm	24VDC	300mA							
82820055	\$129.00	Green	PDF										
82830055	\$122.00	Yellow	PDF										
82840055	\$129.00	Clear	PDF										
82850055	\$207.00	Blue	PDF										
82810067	\$122.00	Red	PDF		115VAC	65mA 50-60 Hz							
82820067	\$129.00	Green	PDF										
82830067	\$122.00	Yellow	PDF										
82840067	\$129.00	Clear	PDF										
82850067	\$207.00	Blue	PDF										

To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.

Bulbs



[95582635](#)

Bulbs						
Part Number	Price	Description	Wattage	Voltage	For Use With	Life Duration
95582635	\$8.25	Bulb for incandescent light BA15d bayonet socket	15W	24V AC/DC	826xxxxx	up to 5,000h
95582637	\$8.25			115VAC		
95582638	\$8.25			230VAC		
95582735	\$8.00	Bulb for blinking incandescent light B15d bayonet socket	25W	24V AC/DC	827xxxxx	up to 2,000h
95582737	\$8.00			115VAC		
95588524	\$11.50	Halogen bulb G6.35	20W	12V	885xxx78	
95588525	\$11.50			24V	885xxx75	



[95582735](#)



[95588524](#)