





Optical Signal Devices

Beacon Accessories



WERMA Beacons Accessories						
Part Number	Price	Drawing Link	Description	Operating Temp.	Material	Weight
Installation Beacon Accessories						
97581201	\$14.50	PDF	Tube adapter for beacons with 37mm (PG29) mounting installation. Find tube adapter accessories in WERMA Stack light catalog section.	-4 to 122°F [-20 to 50°C]	Polyamide / Fiberglass	1.13 g [0.04 oz]
97581202	\$14.00	PDF	Surface mounting base for beacons with 37mm (PG29) mounting installation		Polyamide / Fiberglass with rubber seal	2.83 g [0.1 oz]
97581503	\$44.00	PDF	Surface mounting enclosure for 1 beacon with 37mm (PG29) mounting installation		Polycarbonate/ ABS blend	8.5 g [0.3 oz]
97581507	\$61.00	PDF	Surface mounting enclosure for 2 beacons with 37mm (PG29) mounting installation			14.17 g [0.5 oz]
97581508	\$80.00	PDF	Surface mounting enclosure for 3 beacons with 37mm (PG29) mounting installation			17g [0.6 oz]
97581522	\$5.75	PDF	Anti-twist washer for beacons with 37mm (PG29) mounting installation		304 Stainless steel	0.57 g [0.02 oz]
Freestanding Beacon Accessories						
96000001	\$17.00	PDF	Bracket for tube mounting - for use with for use with 219 and 209 series industrial signal beacons.	-4 to 122°F [-20 to 50°C]	Polyamide	57g [2.01 oz]
97520901	\$20.50	PDF	Plastic Base with integrated tube for WERMA industrial signal beacons- for use with 209 and 219 series beacons		Polyamide	0.1 lbs [1.6 oz]
97520902	\$5.75	PDF	Cable gland for WERMA industrial signal beacons: M25x1.5, plastic - for use with 209 and 219 series industrial signal beacons		Nylon	0.1 lbs [1.6 oz]
97582603	\$43.00	PDF	Galvanized Wire Guard for WERMA industrial signal beacons - for use with 826, 827, 828 and 829 series industrial signal beacons		Wire D 3mm, chromed	140g [4.93 oz]
97582605	\$10.00	PDF	Plastic Bracket for wall mounting for use with WERMA signal beacons - for use with 826, 827, 828 and 829 series industrial signal beacons		Polycarbonate/ ABS blend	62g [2.19 oz]

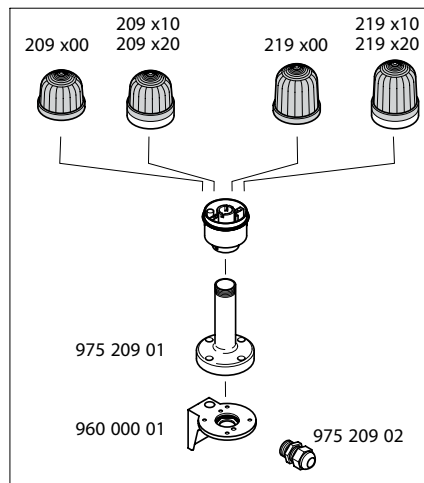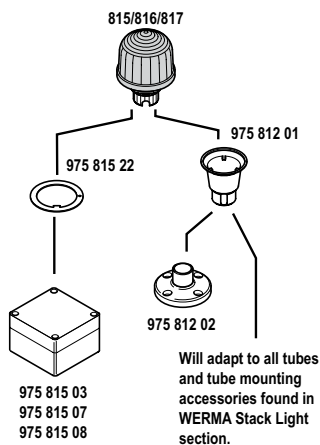

WERMA SIGNALTECHNIK Optical Signal Devices

98mm Base Mount Beacons

Features

- Choose from permanent incandescent, permanent LED, flashing Xenon, EVS (Enhanced Visibility System) flashing LED, and rotating models
- Base mount installation
- 98mm diameter
- Light-intensive Xenon flash in flash models
- Bulb not included with 826 incandescent models
- 25W bulb included with 827 incandescent models
- Various mounting accessories available
- 2-year warranty



826, 827, and 828 Series Beacons Technical Specifications

Part Number	Price	Color	Drawing link	Description	Voltage	Current	Starting Current	Operating Temp /Protection	Life Duration	Housing Material	Weight g [oz]	Connection	Agency Approvals
74mm Base Mount													
82610000	\$39.50	Red	PDF	Incandescent Permanent Light 98mm	12-240V AC/DC max (depends on bulb selection; bulb sold separately)	Depends on bulb selection. (bulb sold separately)	-				180 [6.35]		
82620000	\$43.00	Green	PDF										
82630000	\$39.50	Yellow	PDF										
82640000	\$43.00	Clear	PDF										
82650000	\$43.00	Blue	PDF										
82710075	\$101.00	Red	PDF	Incandescent Blinking Light (1.5 Hz blinking frequency, 5Ws flash energy) 98mm	24V AC/DC	max. 3.0 A		-4 to 122°F [-20 to 50°C]	Up to 5,000h	Polycarbonate cap Polycarbonate/ABS base	207 [7.30]	Terminal screws Max 2.5 mm ² AWG 16-14 Cable diameter 5-8 mm	cULus file E164155, CE, RoHS
82720075	\$109.00	Green	PDF										
82730075	\$101.00	Yellow	PDF										
82740075	\$109.00	Clear	PDF										
82750075	\$109.00	Blue	PDF										
82710077	\$101.00	Red	PDF		115V AC/DC	max. 500mA	≤ 3.0 A	IP65 when mounted					
82720077	\$109.00	Green	PDF										
82730077	\$101.00	Yellow	PDF										
82740077	\$109.00	Clear	PDF										
82750077	\$109.00	Blue	PDF										
82810055	\$122.00	Red	PDF	Xenon Flashing Light (1Hz flash frequency, 1W flash energy) 98mm	24VDC	300mA			4,000,000 flashes		220 [7.76]		
82820055	\$129.00	Green	PDF										
82830055	\$122.00	Yellow	PDF										
82840055	\$129.00	Clear	PDF										
82850055	\$207.00	Blue	PDF										
82810067	\$122.00	Red	PDF		115VAC	65mA 50-60 Hz							
82820067	\$129.00	Green	PDF										
82830067	\$122.00	Yellow	PDF										
82840067	\$129.00	Clear	PDF										
82850067	\$207.00	Blue	PDF										

To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.

Bulbs

Bulbs						
Part Number	Price	Description	Wattage	Voltage	For Use With	Life Duration
95582635	\$8.25	Bulb for incandescent light BA15d bayonet socket	15W	24V AC/DC	826xxxx	up to 5,000h
95582637	\$8.25			115VAC		
95582638	\$8.25			230VAC		
95582735	\$8.00	Bulb for blinking incandescent light B15d bayonet socket	25W	24V AC/DC	827xxxx	up to 2,000h
95582737	\$8.00			115VAC		
95588524	\$11.50	Halogen bulb G6.35	20W	12V	885xxx78	
95588525	\$11.50			24V	885xxx75	



[95582635](#)



[95582735](#)



[95588524](#)