

# wiha Tool Sets

Tools that work for you

## Electrician's Tool Set

The Wiha 80-Piece Master Electrician's tool set will give electricians the comfort of knowing they are equipped with every tool they need to get the job done. All of the tools come conveniently stored in large heavy-duty rolling case. The tools are stored in removable insert trays, keeping the tools organized and secure during transport. This case will make transporting tools from each job site much easier and faster. The case is equipped with a large storage space which offers ample space for more equipment. Every single Wiha insulated tool is individually tested to 10,000 volts AC and rated to 1,000 volts AC (1,500 volts DC) for safety and peace of mind in energized applications. Wiha's Master Electrician's tool set not only equips you with an extensive array of must-have tools but also provides an exceptional storage solution.

## Features

- Individually tested to 10,000 volts AC and rated to 1,000 volts AC for safety and peace of mind
- Tool steel undergoes rigorous heat-treatment process for maximum strength
- Lockable rolling watertight case that will ensure your tools are safe and secure
- Trays have custom-fit compartments with finger-recesses for easy tool retrieval
- Drivers have SoftFinish ergonomic grip for more turning power, comfort, and control




# wiha Tool Sets

Tools that work for you

1



2

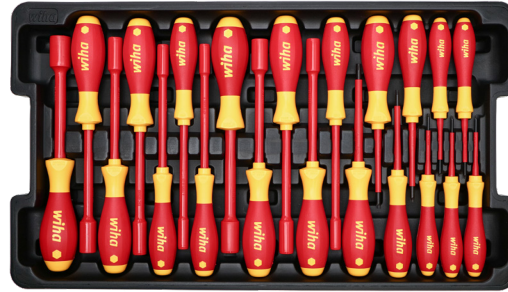


3



4



## Electrician's Tool Set

<b>Part Number</b>	WT32800	<b>Tray 1 Includes</b>	(2) insulated long nose pliers (6.3 in, 8.0 in) (1) 6.3 in insulated diagonal cutters (1) 8.0 in insulated high leverage cutters (1) 6.3 in insulated bent nose pliers (1) 6.3 in insulated cable cutters (1) 6.3 in insulated long flat nose pliers (1) 6.3 in insulated stripping pliers (1) 9.0 in insulated linesman's pliers (1) 8.0 in insulated adjustable wrench (1) insulated 2 meter folding ruler (1) insulated electricians cable knife
<b>Price</b>	\$1,960.00		
<b>Description</b>	Wiha electricians set, 80 pieces, imperial and metric, hard case.	<b>Tray 2 Includes</b>	(12) SoftFinish insulated nutdrivers (imperial (7/32 in, 1/4 in, 5/16 in, 3/8 in, 7/16 in), metric (5 mm, 5.5 mm, 6 mm, 7 mm, 8 mm, 10 mm, 13 mm)) (9) SoftFinish insulated Torx screwdrivers (T6, T7, T8, T9, T10, T15, T20, T25, T30)
<b>Case</b>	(1) Lockable rolling watertight case for easy transportation	<b>Tray 3 Includes</b>	(10) insulated external hex T-Handles (imperial (5/32 in, 3/16 in, 7/32 in, 1/4 in, 5/16 in, 3/8 in), metric (4 mm, 5 mm, 6 mm, 8 mm)) (2) insulated external hex L-keys (10 mm, 1/2 in) (14) insulated sockets (imperial (1/2 in, 9/16 in, 5/8 in, 11/16 in, 3/4 in, 13/16 in, 7/8 in), metric (13 mm, 14 mm, 15 mm, 17 mm, 19 mm, 20 mm, 22 mm)) (1) insulated 3/8 in drive ratchet (1) 4.9 in extension 3/8 in drive
		<b>Tray 4 Includes</b>	(18) SoftFinish insulated screwdrivers (slotted (2.5 mm, 3 mm, 3.5 mm, 4 mm, 4.5 mm, 5.5 mm, 6 mm, 6.5 mm, 8 mm, 10 mm), Phillips (#0, #1, #2, #3), square (#1, #2), slotted/Phillips (#1, #2)) (1) category IV voltage detector