


# Enclosure Accessories - Window Kits

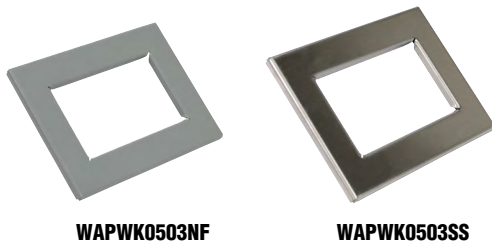

## Construction

- Steel has Ansi 61 gray powder coat finish
- 304 Stainless steel has grained finish
- Makrolon polycarbonate window
- Integral closed-cell gasket and mounting hardware
- Steel windows for indoor use with NEMA 12
- Stainless steel windows for indoor use with NEMA 12 and 13 enclosures

## Applications

Window kits are easily installed by making a cutout in the enclosure and attaching the window and frame in place. All necessary hardware is included. Kits are fully gasketed to maintain a NEMA 12/ NEMA 13 oil-tight seal.

Enclosure Shipping Schedule
1 -10 days
Color indicates shipping lead time in business days.

Ansi 61 Gray Steel	Price	304 Stainless Steel	Price	Wt. [lb]	Window Size in [mm]	Frame Size in [mm]	Required Cutout Size in [mm]
<b>WAPWK0503NF</b>	\$117.00	<b>WAPWK0503SS</b>	\$188.00	2.2	5.00 x 3.00 [127 x 76]	7.50 x 5.50 [191 x 140]	6.69 x 4.69 [170 x 119]
<b>WAPWK0905NF</b>	\$141.00	<b>WAPWK0905SS</b>	\$227.00		9.00 x 5.50 [229 x 140]	11.50 x 8.00 [292 x 203]	10.69 x 7.19 [272 x 183]
<b>WAPWK1308NF</b>	\$177.00	<b>WAPWK1308SS</b>	\$287.00	3.1	13.00 x 8.00 [330 x 203]	15.50 x 10.50 [394 x 267]	14.69 x 9.69 [373 x 170]
<b>WAPWK1705NF</b>	\$159.00	—	—	4.4	17.00 x 5.50 [432 x 140]	19.50 x 8.00 [495 x 203]	18.69 x 7.19 [475 x 183]
<b>WAPWK1711NF</b>	\$245.00	<b>WAPWK1711SS</b>	\$378.00	6.8	17.00 x 11.00 [432 x 279]	19.50 x 13.50 [495 x 343]	18.69 x 12.69 [475 x 322]
<b>WAPWK2315NF</b>	\$302.00	<b>WAPWK2315SS</b>	\$488.00	8.2	23.00 x 15.00 [584 x 381]	25.50 x 17.50 [648 x 445]	24.69 x 16.69 [627 x 424]
<b>WAPWK2919NF</b>	\$449.00	—	—	10.9	29.00 x 19.00 [737 x 483]	31.50 x 21.50 [800 x 546]	30.69 x 20.69 [780 x 526]
<b>WAPWK3523NF</b>	\$593.00				35.00 x 23.00 [889 x 584]	37.50 x 25.50 [953 x 648]	36.69 x 24.69 [932 x 627]