


# Enclosure Accessories - Window Kits



## Window Kits

Window kits are easily installed by making a cutout in the enclosure and attaching the window and frame in place. All necessary hardware is included. Kits are fully gasketed to maintain a NEMA 12/ NEMA 13 oil-tight seal.

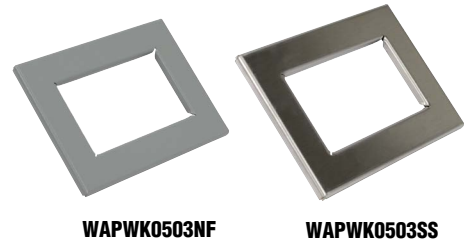

Enclosure Shipping Schedule
1 -10 days
Color indicates shipping lead time in business days.

Window Kit	Price	Description	Material	Window Size in [mm]	Frame Size in [mm]	Required Cutout Size in [mm]	Wt. [lb]
<b>WAPWK0503NF</b>	\$115.00	Hubbell-Wiegmann enclosure window kit, 5 x 3 inch Makrolon polycarbonate window, 7.5 x 5.5 inch frame, ANSI 61 gray powder coat finish. For indoor use on NEMA 12 enclosures. Includes integral closed-cell gasket and mounting hardware.	Steel	5.00x3.00 [127x76]	7.50x5.50 [191x140]	6.69x4.69 [170x119]	2.2
<b>WAPWK0503SS</b>	\$185.00	Hubbell-Wiegmann enclosure window kit, 5 x 3 inch Makrolon polycarbonate window, 7.5 x 5.5 inch frame, 304 stainless steel with grained finish. For indoor use on NEMA 12 and NEMA 13 enclosures. Includes integral closed-cell gasket and mounting hardware.	Stainless Steel				
<b>WAPWK0905NF</b>	\$139.00	Hubbell-Wiegmann enclosure window kit, 9 x 5.5 inch Makrolon polycarbonate window, 11.5 x 8 inch frame, ANSI 61 gray powder coat finish. For indoor use on NEMA 12 enclosures. Includes integral closed-cell gasket and mounting hardware.	Steel	9.00x5.50 [229x140]	11.50x8.00 [292x203]	10.69x7.19 [272x183]	3.1
<b>WAPWK0905SS</b>	\$223.00	Hubbell-Wiegmann enclosure window kit, 9 x 5.5 inch Makrolon polycarbonate window, 11.5 x 8 inch frame, 304 stainless steel with grained finish. For indoor use on NEMA 12 and NEMA 13 enclosures. Includes integral closed-cell gasket and mounting hardware.	Stainless Steel				
<b>WAPWK1308NF</b>	\$175.00	Hubbell-Wiegmann enclosure window kit, 13 x 8 inch Makrolon polycarbonate window, 15.5 x 10.5 inch frame, ANSI 61 gray powder coat finish. For indoor use on NEMA 12 enclosures. Includes integral closed-cell gasket and mounting hardware.	Steel	13.00x8.00 [330x203]	15.50x10.50 [394x267]	14.69x9.69 [373x170]	4.4
<b>WAPWK1308SS</b>	\$283.00	Hubbell-Wiegmann enclosure window kit, 13 x 8 inch Makrolon polycarbonate window, 15.5 x 10.5 inch frame, 304 stainless steel with grained finish. For indoor use on NEMA 12 and NEMA 13 enclosures. Includes integral closed-cell gasket and mounting hardware.	Stainless Steel				
<b>WAPWK1705NF</b>	\$157.00	Hubbell-Wiegmann enclosure window kit, 17 x 5.5 inch Makrolon polycarbonate window, 19.5 x 8 inch frame, ANSI 61 gray powder coat finish. For indoor use on NEMA 12 enclosures. Includes integral closed-cell gasket and mounting hardware.	Steel	17.00x5.50 [432x140]	19.50x8.00 [495x203]	18.69x7.19 [475x183]	6.8
<b>WAPWK1711NF</b>	\$241.00	Hubbell-Wiegmann enclosure window kit, 17 x 11 inch Makrolon polycarbonate window, 19.5 x 13.5 inch frame, ANSI 61 gray powder coat finish. For indoor use on NEMA 12 enclosures. Includes integral closed-cell gasket and mounting hardware.	Steel	17.00x11.00 [432x279]	19.50x13.50 [495x343]	18.69x12.69 [475x322]	
<b>WAPWK1711SS</b>	\$373.00	Hubbell-Wiegmann enclosure window kit, 17 x 11 inch Makrolon polycarbonate window, 19.5 x 13.5 inch frame, 304 stainless steel with grained finish. For indoor use on NEMA 12 and NEMA 13 enclosures. Includes integral closed-cell gasket and mounting hardware.	Stainless Steel				8.2
<b>WAPWK2315NF</b>	\$298.00	Hubbell-Wiegmann enclosure window kit, 23 x 15 inch Makrolon polycarbonate window, 25.5 x 17.5 inch frame, ANSI 61 gray powder coat finish. For indoor use on NEMA 12 enclosures. Includes integral closed-cell gasket and mounting hardware.	Steel	23.00x15.00 [584x381]	25.50x17.50 [648x445]	24.69x16.69 [627x424]	
<b>WAPWK2315SS</b>	\$481.00	Hubbell-Wiegmann enclosure window kit, 23 x 15 inch Makrolon polycarbonate window, 25.5 x 17.5 inch frame, 304 stainless steel with grained finish. For indoor use on NEMA 12 and NEMA 13 enclosures. Includes integral closed-cell gasket and mounting hardware.	Stainless Steel				10.9
<b>WAPWK2919NF</b>	\$443.00	Hubbell-Wiegmann enclosure window kit, 29 x 19 inch Makrolon polycarbonate window, 31.5 x 21.5 inch frame, ANSI 61 gray powder coat finish. For indoor use on NEMA 12 enclosures. Includes integral closed-cell gasket and mounting hardware.	Steel	29.00x19.00 [737x483]	31.50x21.50 [800x546]	30.69x20.69 [780x526]	
<b>WAPWK3523NF</b>	\$584.00	Hubbell-Wiegmann enclosure window kit, 35 x 23 inch Makrolon polycarbonate window, 37.5 x 25.5 inch frame, ANSI 61 gray powder coat finish. For indoor use on NEMA 12 enclosures. Includes integral closed-cell gasket and mounting hardware.	Steel	35.00x23.00 [889x584]	37.50x25.50 [953x648]	36.69x24.69 [932x627]	