



# Mini Cordsets and Receptacles Accessories

## Mini "T" Connectors Features and General Specifications

- Oil-resistant yellow PVC body
- Copper alloy/gold plating contacts
- Nickel-plated brass coupling nut
- Operating temperature range: -40°C to +105°C (-40°F to +221°F)
- IP67 protection when connected
- Approvals: UL File E328610
- Made in the USA




**Note:** To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.

Mini "T" Connectors						
Face View of Male	Face View of Female	# of Poles	Rating	Part Number	Wiring	Price
		3	300V 8A	<b>ZP-S1-3MFF-T</b>	1-1-1 2-2-2 3-3-3	\$25.00
		4	300V 8A	<b>ZP-S1-4MFF-T</b>	1-1-1 2-2-2 3-3-3 4-4-4	\$27.00
		5	300V 8A	<b>ZP-S1-5MFF-T</b>	1-1-1 2-2-2 3-3-3 4-4-4 5-5-5	\$28.00

## Dimensions

mm [in]

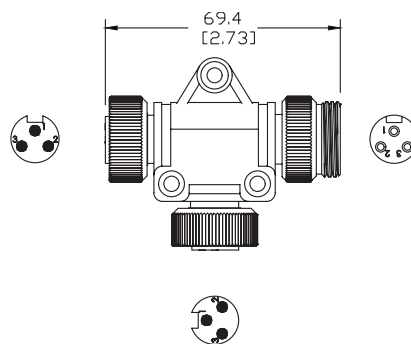

**Note:** Tightening torque 44 lb-in (5.0 N-m) coupling nut.

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete Engineering drawings.

## Caps and Adapters

Dimensions – mm [in]	Description	Part Number	Price
	Closure cap for covering receptacles and plugs with male threads. 0.17" diameter mounting hole for securing the chain. Clear anodized aluminum with nickel-plated brass chain and hardware.	<b>ZP-S1-CAP</b>	\$3.00
	Closure plug for covering receptacles and plugs with female threads. 0.17" diameter mounting hole for securing the chain. Clear anodized aluminum with nickel-plated brass chain and hardware.	<b>ZP-S1-PLUG</b>	\$5.00
	Adapter coupling for connecting male and female plugs with female couplings. Clear anodized aluminum.	<b>ZP-S1-XMP-AD</b>	\$3.00

